
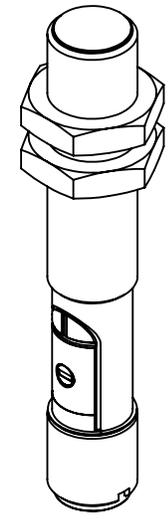


TECHNICAL INFORMATION

- 1.) SENSING SURFACE
- 2.) HOUSING
- 3.) COVER
- 4.) POTENTIOMETER
- 5.) LED POWER
- 6.) LED FUNCTION INDICATOR

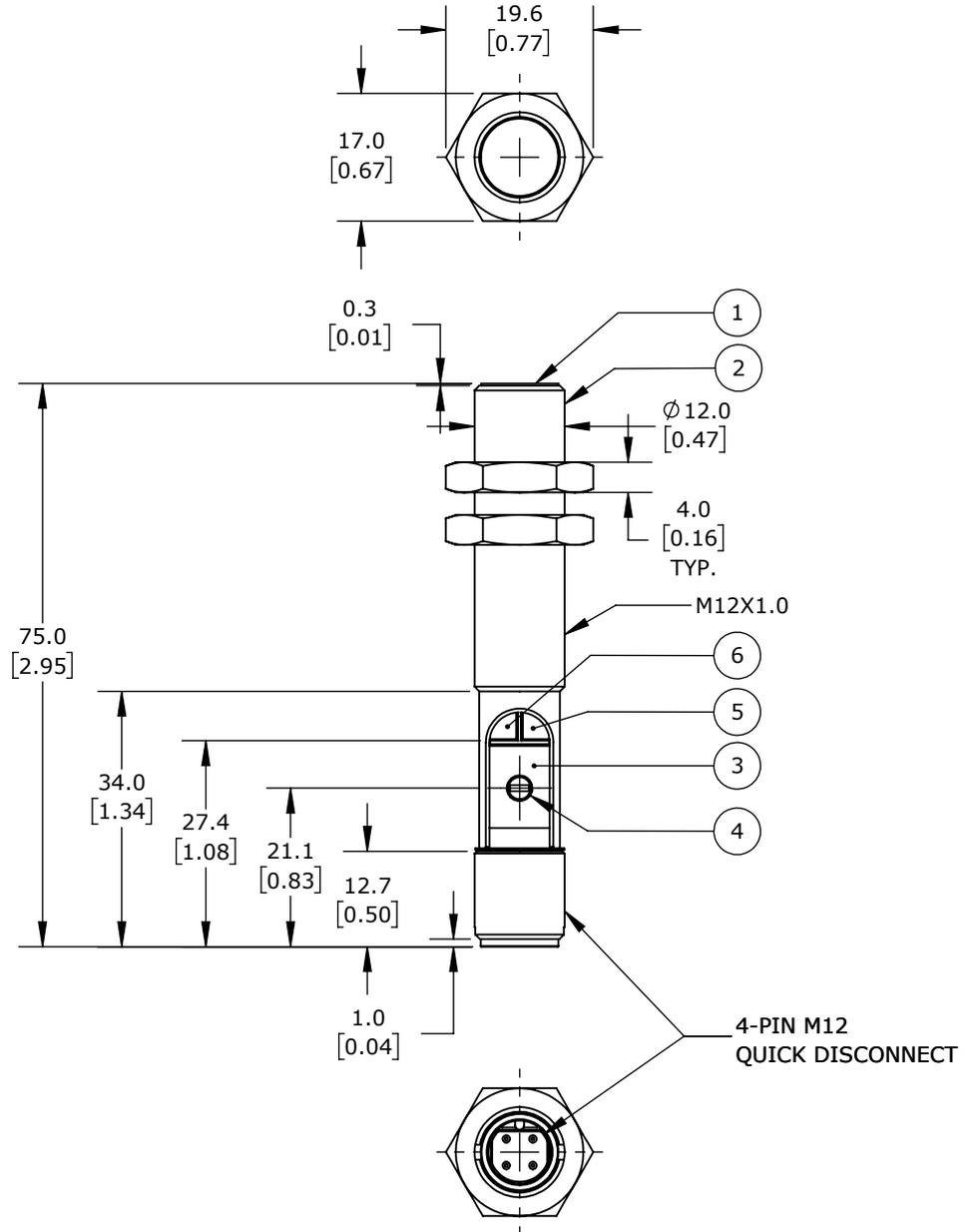

BALLUFF CAPACITIVE PROXIMITY SENSOR, TUBULAR, 12MM DIAMETER X 75MM BODY, STAINLESS STEEL HOUSING, PNP, N.O., 4MM SENSING DISTANCE, FLUSH, 100 HZ SWITCHING FREQUENCY, IP67, 4-PIN M12 QUICK-DISCONNECT.

BCS00P0

AutomationDirect.com
1-800-633-0405

	3rd ANGLE	NOT TO SCALE	PART DIMENSIONS MAY DIFFER SLIGHTLY DUE TO MANUFACTURER'S VARIANCES	METRIC UNITS USED FOR PART DESIGN	UNLESS OTHERWISE SPECIFIED UNITS ARE:	mm [inch]	LATEST VERSION 7/20/2023	SHEET 1 OF 1
--	--------------	-----------------	--	--------------------------------------	--	---------------------	-----------------------------	--------------