




TECHNICAL INFORMATION

- 1.) SENSING SURFACE
- 2.) POWER INDICATOR GREEN
- 3.) FUNCTION INDICATOR YELLOW
- 4.) POTENTIOMETER
- 5.) FASTENING: CABLE TIE
- 6.) FASTENING SCREW 3XM3

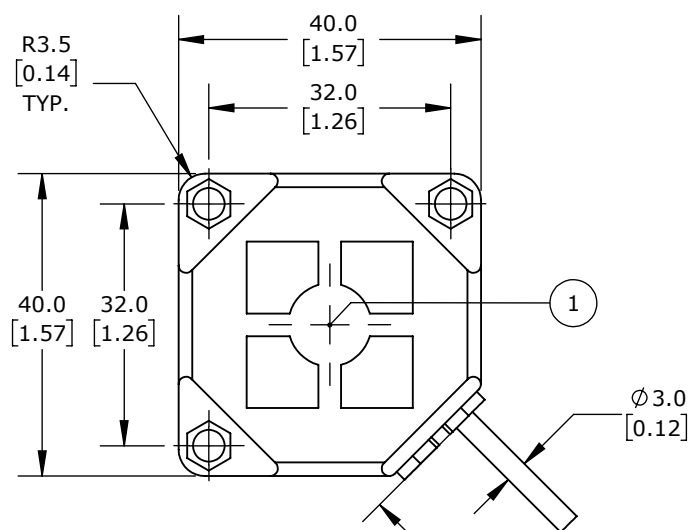


0.3M CABLE
LENGTH

 41.5MM MAX.
LENGTH

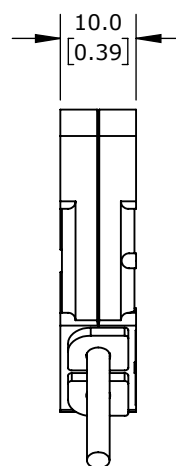

3-PIN M8
QUICK DISCONNECT

ISOMETRIC VIEW

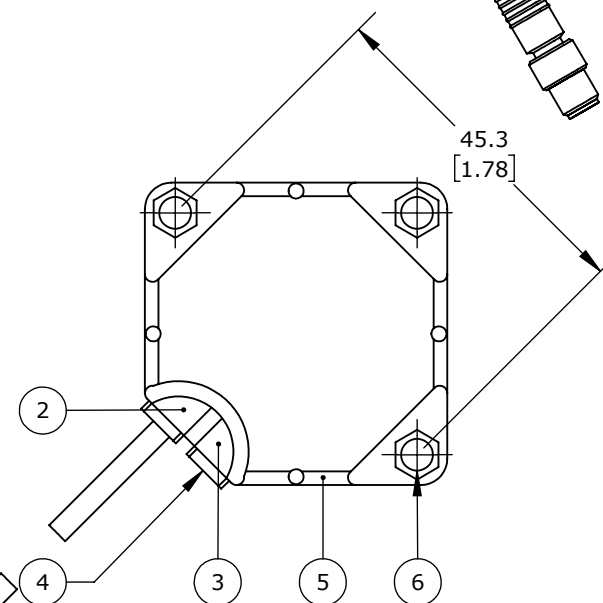

BALLUFF CAPACITIVE PROXIMITY SENSOR, RECTANGULAR, 40 X 40 X 10MM BODY, POLYBUTYLENE TEREPHTHALATE HOUSING, TOP SENSING, PNP, N.O., 20MM SENSING DISTANCE, FLUSH, 100 HZ SWITCHING FREQUENCY, IP67, 3-PIN M8 QUICK-DISCONNECT.

BCS00U6

AutomationDirect.com
1-800-633-0405



3rd
ANGLE

NOT TO
SCALE

PART DIMENSIONS MAY DIFFER SLIGHTLY
DUE TO MANUFACTURER'S VARIANCES

METRIC UNITS USED
FOR PART DESIGN

UNLESS OTHERWISE
SPECIFIED UNITS ARE:

mm
[inch]

LATEST VERSION
7/21/2023

SHEET 1 OF 1