


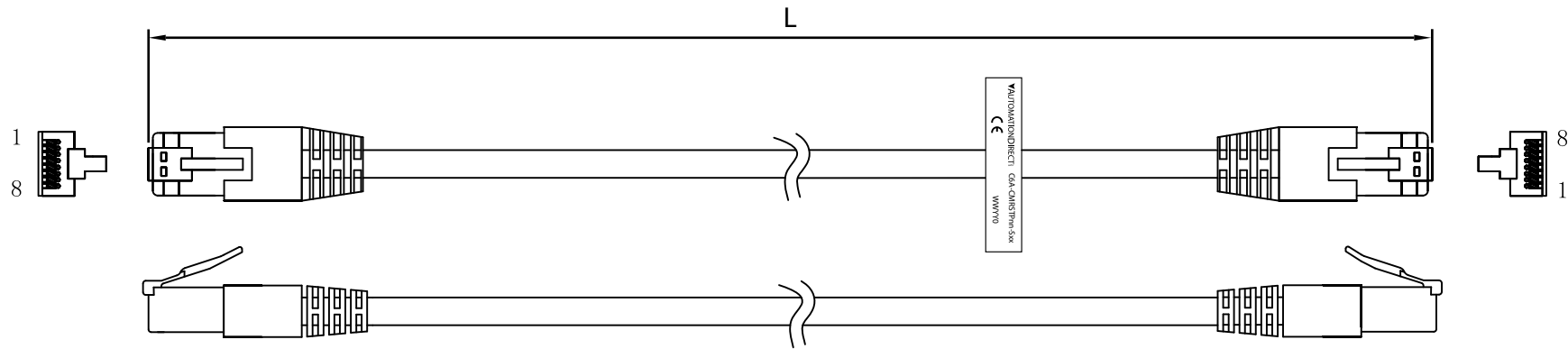

Stride®

▼AUTOMATIONDIRECT .com C6A-CMRSTPnn-Cxx
CE YYWW0

Color and Length Part Number Combinations

C6A-CMRSTPnn-Sxx

nn	Color	Sxx	Length	Tolerance
BL	Blue	S1	1FT	±9.84%
		S3	3FT	±3.28%
		S7	7FT	±1.87%
		S10	10FT	±1.64%
		S14	14FT	±1.17%
		S25	25FT	±0.66%
		S50	50FT	±0.66%

Notes:

1. CABLE - UL Type CMR, 23AWG*4P + AE, OD: 6.2MM±0.2MM, Rated 75°C
2. RJ45 8P8C Shielded Plug
3. Minimum Bending Radius: 60MM [2.44"]
4. Operating Temperature: 0-75°C [32-167°F]

C6A-CMRSTPnn-Sxx	
Rev: B	Date: 7/15/2026
Units: mm [inches]	
Scale: 1:1	
Cat 6A CMR Ethernet Patch Cable	
▼AUTOMATIONDIRECT .com	