


ISOMETRIC VIEW

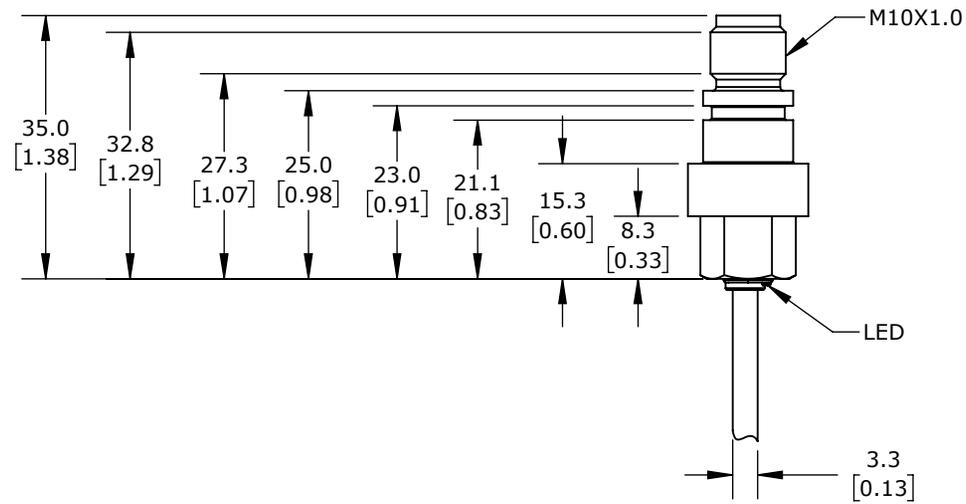

CONTRINEX INDUCTIVE PROXIMITY SENSOR, TUBULAR, 10MM DIAMETER X 35MM BODY, 304 STAINLESS STEEL HOUSING, PNP, N.O., 0.6MM SENSING DISTANCE, FLUSH, 2000 HZ SWITCHING FREQUENCY, IP68, PIGTAIL.

**DW-AD-603-M10E-637**

AutomationDirect.com  
1-800-633-0405

	3rd ANGLE	NOT TO SCALE	PART DIMENSIONS MAY DIFFER SLIGHTLY DUE TO MANUFACTURER'S VARIANCES	METRIC UNITS USED FOR PART DESIGN	UNLESS OTHERWISE SPECIFIED UNITS ARE:	<b>mm</b> [inch]	LATEST VERSION 10/6/2022	SHEET 1 OF 1
--	--------------	-----------------	--	--------------------------------------	--	---------------------	-----------------------------	--------------