
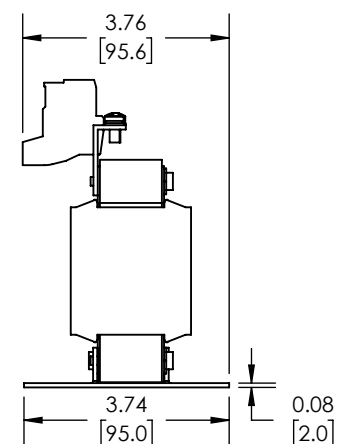
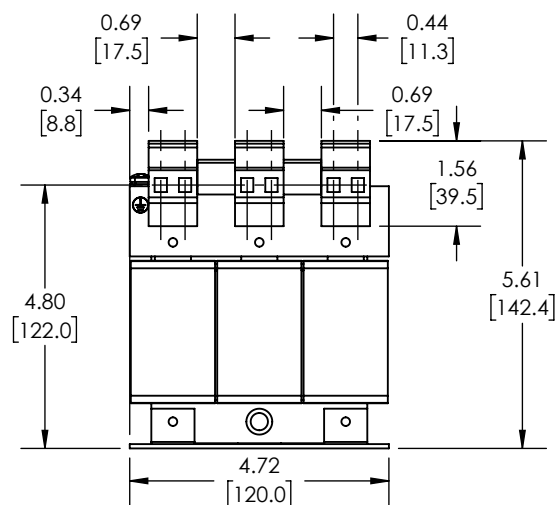
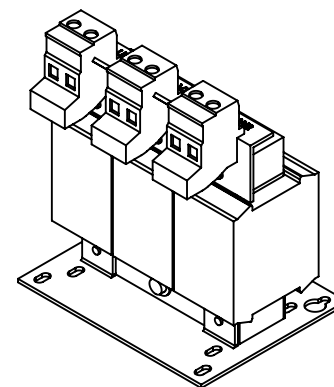


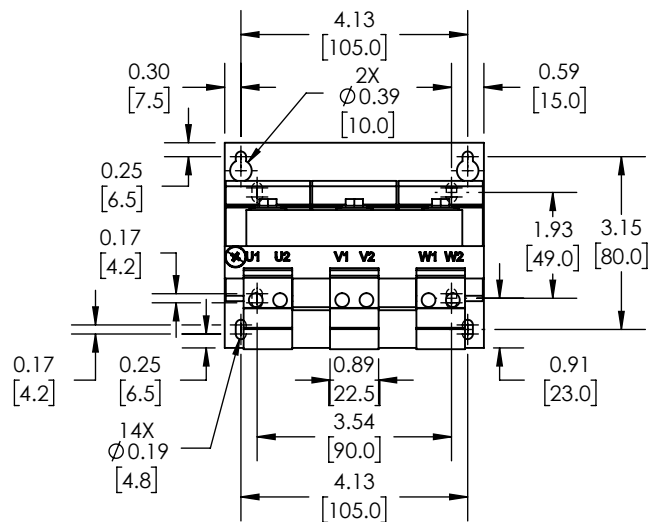

BLOCK MR3 SERIES LOAD REACTOR, 230/480 VAC, 10HP AT 230 VAC AND 20HP AT 480 VAC,  
3-PHASE, 24A, OUTPUT SIDE ONLY, FOR USE WITH MULTIPLE AC DRIVES

**MR3-480\_24**

AutomationDirect.com  
1-800-633-0405

|              |                 |                                                                        |                                      |                                                           |               |                             |              |
|--------------|-----------------|------------------------------------------------------------------------|--------------------------------------|-----------------------------------------------------------|---------------|-----------------------------|--------------|
| 3rd<br>ANGLE | NOT TO<br>SCALE | PART DIMENSIONS MAY DIFFER SLIGHTLY<br>DUE TO MANUFACTURER'S VARIANCES | METRIC UNITS USED<br>FOR PART DESIGN | UNLESS OTHERWISE SPECIFIED UNITS ARE: <b>inch</b><br>[mm] | MODEL<br>REV. | LATEST VERSION<br>7/20/2026 | SHEET 1 OF 1 |
|--------------|-----------------|------------------------------------------------------------------------|--------------------------------------|-----------------------------------------------------------|---------------|-----------------------------|--------------|