

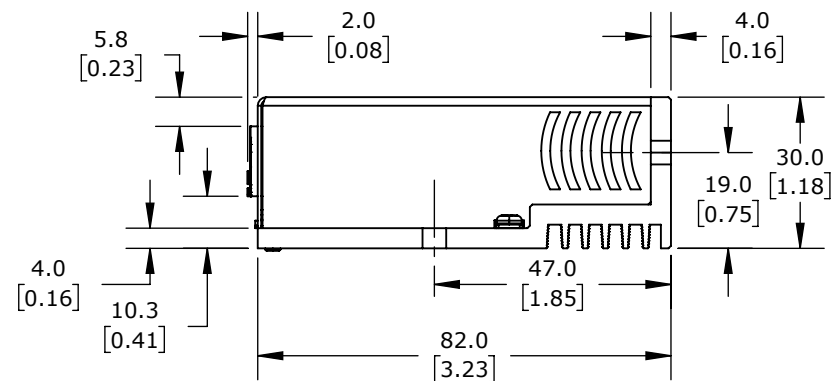
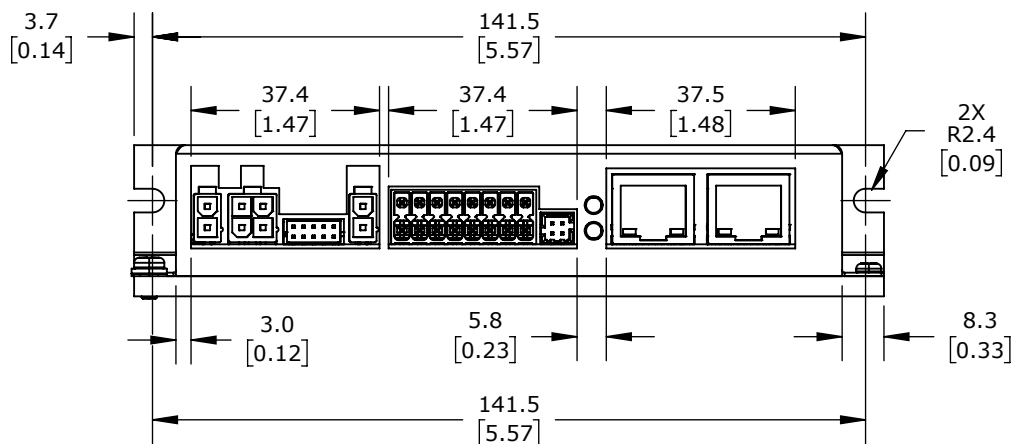


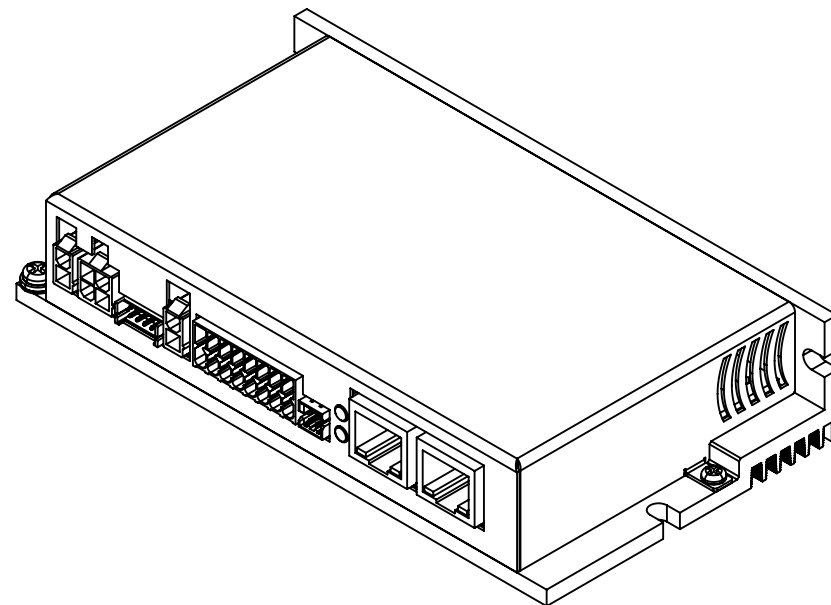

EVER MOTION SOLUTIONS AC/DC OPEN/CLOSED LOOP MICROSTEPPING STEPPER DRIVE, 7.1A PER PHASE, 2-PHASE OUTPUT, 18-56 VAC/24-80 VDC, BIPOLAR, TORQUE, VELOCITY AND POSITION MODE, 200 TO 65536 STEPS PER REVOLUTION, (2) ETHERNET 100BASE-TX (RJ45) AND (1) 4-PIN TERMINAL PORT(S)

SW4A3070H241-00C0680

AutomationDirect.com
1-800-633-0405

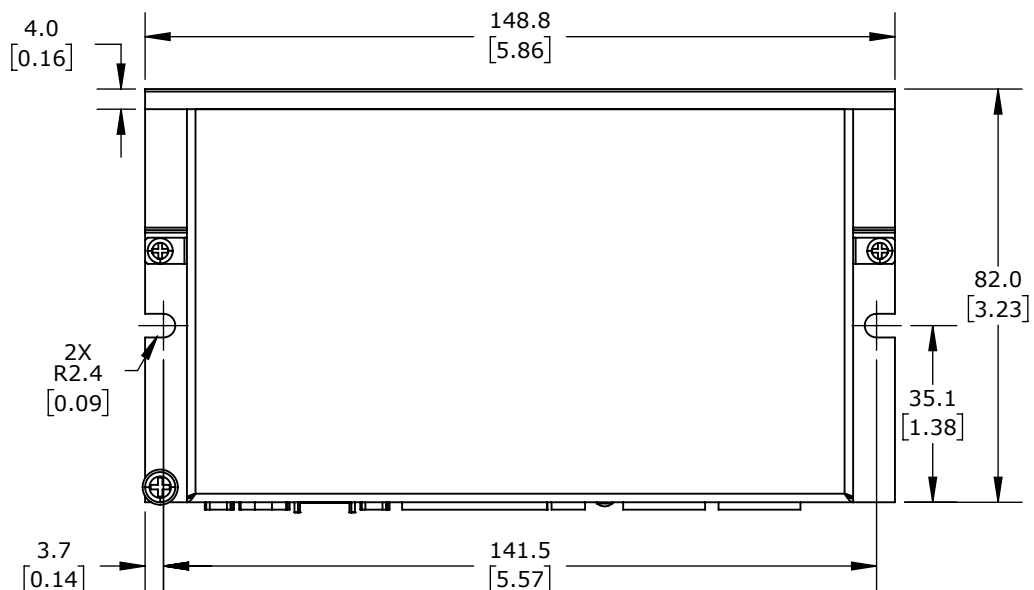

3rd
ANGLE

NOT TO
SCALE

PART DIMENSIONS MAY DIFFER SLIGHTLY
DUE TO MANUFACTURER'S VARIANCES

METRIC UNITS USED
FOR PART DESIGN

UNLESS OTHERWISE
SPECIFIED UNITS ARE:

mm
[inch]

LATEST VERSION
2/4/2025

SHEET 1 OF 1