



PNP NO

**IDDR-C23MP-NMS-A0**

**QTY 1**




For use in NFPA 79 Applications only

Sensing range **10...220 mm**

Housing **21.5 x 33 (C23)**

Operation range **10...200 mm**

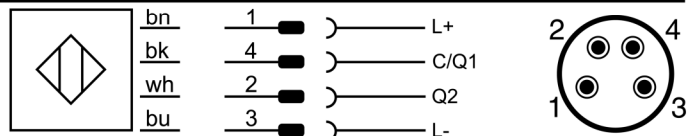

Ub: 10...30 VDC

IA ≤ 100 mA

For use in class 2 circuits

C/Q1: OSS1/IO-Link

Q2: OSS2/INPUT

Max ambient temperature (IEC 60947-5-2): 65°C

Adapters providing field wiring means are available from the manufacturer.

Refer to manufacturers information.

WARNING - HOT SURFACE - RISK OF BURN - AVERTISSEMENT - SURFACE CHAUDE - RISQUE DE BRÛLURE



**CONTRINEX AG** Industrial Electronics

Rte du Pâqui 3 - P.O. Box - CH-1720 Corminboeuf - Switzerland

Internet: [www.contrinex.com](http://www.contrinex.com)



Made in Switzerland

620-600-616

Operators of the products we supply are responsible for compliance with measures for the protection of persons. The use of our equipment in applications where the safety of persons might be at risk is only authorized if the operator observes and implements separate, appropriate and necessary measures for the protection of persons and machines.