



PNP NO Embeddable

IDWE-M8MP-NMS-A0

QTY 1




For use in NFPA 79 Applications only


Sensing range **0...4.4 mm**

Housing **M8**

Operation range **0...4 mm**

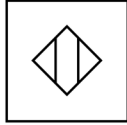

| | | | | |
|----|---|---|---|------|
| bn | 1 | ⎓ | ⎓ | L+ |
| bk | 4 | ⎓ | ⎓ | C/Q1 |
| wh | 2 | ⎓ | ⎓ | Q2 |
| bu | 3 | ⎓ | ⎓ | L- |

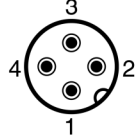

Ub: 18...30 VDC
C/Q1: OSS1/IO-Link
Q2: OSS2/INPUT

IA ≤ 200 mA

For use in class 2 circuits

Max ambient temperature (IEC 60947-5-2): 70°C



CONTRINEX AG Industrial Electronics
Rte du Pâqui 3 - P.O. Box - CH-1720 Corminboeuf - Switzerland
Internet: www.contrinex.com



Made in Sri Lanka

330-020-494

Operators of the products we supply are responsible for compliance with measures for the protection of persons. The use of our equipment in applications where the safety of persons might be at risk is only authorized if the operator observes and implements separate, appropriate and necessary measures for the protection of persons and machines.