



PNP LO

ISRR-M18MP-NMS-A0

QTY 1



For use in NFPA 79 Applications only


Sensing range **30...7700 mm**

(on LXR-0000-084)


Housing **M18**

Operation range **30...7000 mm**

(on LXR-0000-084)

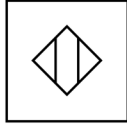

| | | | | |
|----|---|---|---|------|
| bn | 1 | ⎓ | ⎓ | L+ |
| bk | 4 | ⎓ | ⎓ | C/Q1 |
| wh | 2 | ⎓ | ⎓ | Q2 |
| bu | 3 | ⎓ | ⎓ | L- |

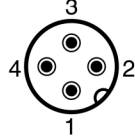

U_b: 10...30 VDC

I_A ≤ 200 mA

For use in class 2 circuits

C/Q1: OSS1/IO-Link

Q2: OSS2/INPUT

Max ambient temperature (IEC 60947-5-2): 65°C

Adapters providing field wiring means are available from the manufacturer.
Refer to manufacturers information.



CONTRINEX AG Industrial Electronics

Rte du Pâqui 3 - P.O. Box - CH-1720 Corminboeuf - Switzerland

Internet: www.contrinex.com



620-600-485

Made in Switzerland

Operators of the products we supply are responsible for compliance with measures for the protection of persons. The use of our equipment in applications where the safety of persons might be at risk is only authorized if the operator observes and implements separate, appropriate and necessary measures for the protection of persons and machines.