



PNP NO Embeddable

ISWE-M12MP-NSS-A0

QTY 1






For use in NFPA 79 Applications only

Sensing range **0...4.4 mm**

Housing **M12**

Operation range **0...4 mm**

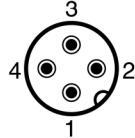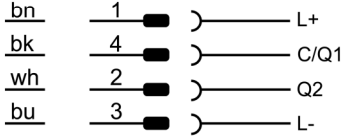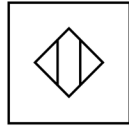

U_b: 18...30 VDC

I_A ≤ 200 mA

For use in class 2 circuits

C/Q1: OSS1/IO-Link

Q2: OSS2

Max ambient temperature (IEC 60947-5-2): 70°C

Adapters providing field wiring means are available from the manufacturer.
Refer to manufacturers information.



CONTRINEX AG Industrial Electronics

Rte du Pâqui 3 - P.O. Box - CH-1720 Corminboeuf - Switzerland

Internet: www.contrinex.com



330-020-535

Made in Sri Lanka

Operators of the products we supply are responsible for compliance with measures for the protection of persons. The use of our equipment in applications where the safety of persons might be at risk is only authorized if the operator observes and implements separate, appropriate and necessary measures for the protection of persons and machines.