

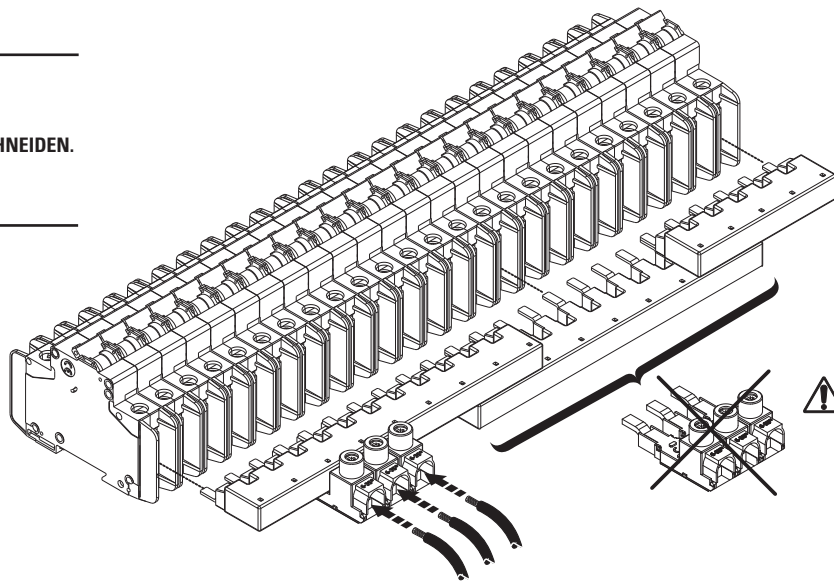
# FAZ-...-NA | Busbars

 


## Z-SV/UL-16 Busbars

 

 
- ⚠ ATTENTION:** MAXIMUM OF 3 COMMONING LINKS ALLOWED. ANY COMBINATION OF SAME POLE CONFIGURATION.
- ATTENTION:** 3 LIAISONS COMMUNES AUTORISÉES AU MAXIMUM. TOUTE COMBINAISON DE CONFIGURATIONS DE POLARITÉ IDENTIQUES.
- ACHTUNG:** MAXIMAL 3 SCHIENENBLÖCKE. BELIEBIGE KOMBINATION GLEICHPOLIGER KONFIGURATIONEN.
- ATTENZIONE:** SONO CONSENTITI AL MASSIMO 3 PETTINI DI COLLEGAMENTO IN QUALSIASI COMBINAZIONE DELLA STESSA CONFIGURAZIONE DI POLI.
- ATENCIÓN:** SE PERMITE UN MÁXIMO DE 3 ENLACES COMUNES. CUALQUIER COMBINACIÓN DEL MISMO TIPO DE CONFIGURACIÓN DE POLO.

 


- ⚠ ATTENTION:** DO NOT CUT.
- ATTENTION:** NE PAS COUPER.
- ACHTUNG:** NICHT DURCHSCHNEIDEN.
- ATTENZIONE:** NON TAGLIARE.
- ATENCIÓN:** NO CORTE.



	UL489		EN/IEC 00947-2
$U_e$	480 V AC	96 V DC	240/415 V AC
f	50/60 Hz	-----	50/60 Hz
$U_{imp}$	-----		9.5 kV
$I_e$	115 A @ 40°C		160 A @ 30°C
	#1-14 AWG 60/75°C Cu		1.5-50 mm <sup>2</sup> Cu
	0.56 in		14 mm

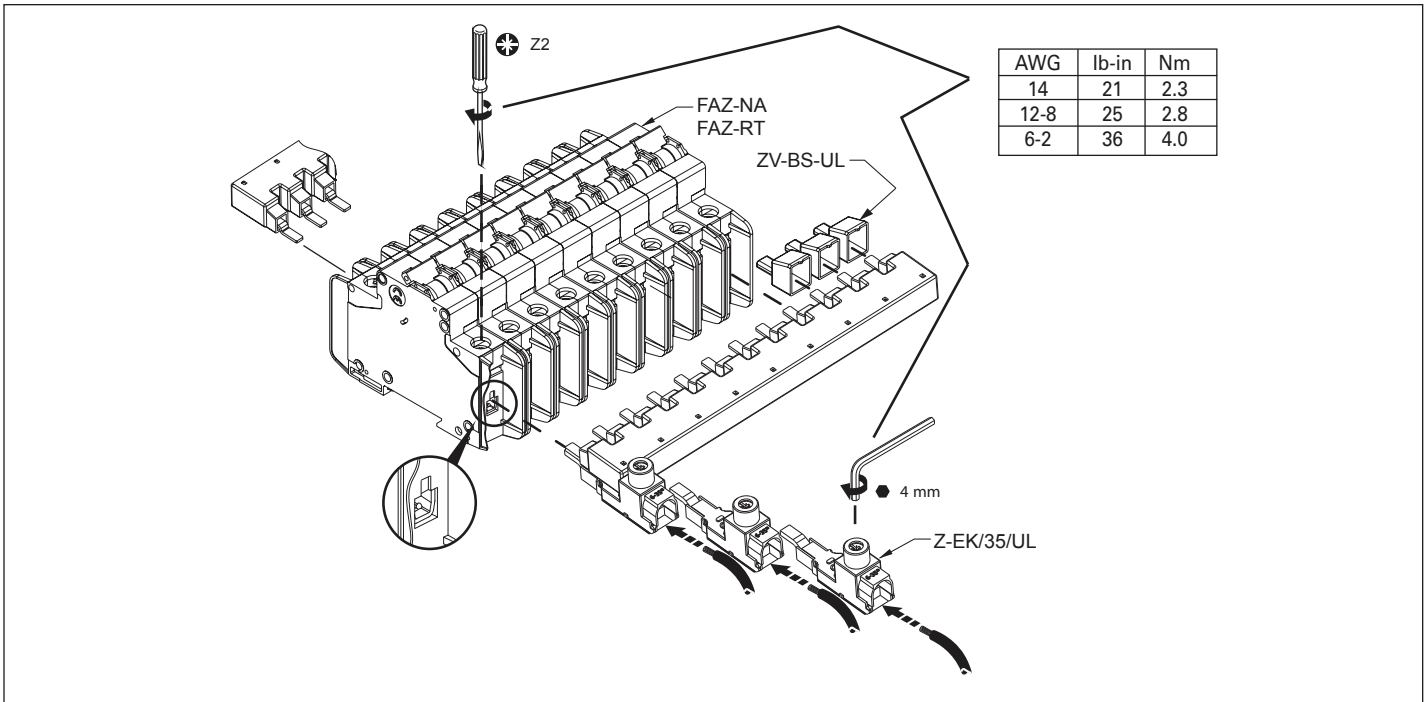
	UL489		EN/IEC 00947-2
$U_e$	480 V AC	96 V DC	240/415 V AC
f	50/60 Hz	-----	50/60 Hz
$U_{imp}$	-----		9.5 kV
$I_e$	80 A @ 40°C		80 A @ 30°C
	#2-14 AWG 60/75°C Cu		2.5-35 mm <sup>2</sup> Cu
	0.56 in		14 mm

	UL489		EN/IEC 00947-2
$U_e$	480 V AC	96 V DC	240/415 V AC
f	50/60 Hz	-----	50/60 Hz
$U_{imp}$	-----		9.5 kV
$I_e$	80 A @ 40°C		80 A @ 30°C
Cross section	-----		16 mm <sup>2</sup>


**EATON**

Powering Business Worldwide


**Z-SV/UL-16 Busbars**

 
 
 
 


**IEC/EN 60947-2 Icc**

	Ue VAC	Z-SV/UL Icc Amps
	240/415	15000

**UL SCCR**

	FAZ-NA FAZ-RT In Amps	Ue VAC	Z-SV/UL SCCR RMS Sym Amps
	0.5-32	480Y/277	10000
	35-40	240	10000

Article No.				
104892	Z-SV/UL-16/1P-1TE/6	6		
104893	Z-SV/UL-16/1P-1TE/12	12		
104894	Z-SV/UL-16/1P-1TE/18	18		
104895	Z-SV/UL-16/2P-2TE/6		3	
104896	Z-SV/UL-16/2P-2TE/12		6	
104897	Z-SV/UL-16/2P-2TE/18		9	
104898	Z-SV/UL-16/3P-3TE/6			2
104899	Z-SV/UL-16/3P-3TE/12			4
104900	Z-SV/UL-16/3P-3TE/18			6
104901	Z-EK/35/UL			
104902	Z-EB/50/UL			
104904	ZV-BS-UL			

**Eaton**  
 Electrical Sector  
 1000 Eaton Boulevard  
 Cleveland, Ohio 44122  
 United States  
 877-ETN-CARE (877-386-2273)  
 Eaton.com

© 2013 Eaton  
 All Rights Reserved  
 Printed in USA  
 Publication No. IB 70-8793 / TBG001093  
 June 2013