

INTEGRA ENCLOSURES

P/N: USOPK-G (Gray) / USOPK-B (Black) SWING OUT PANEL KIT


Installation Instructions:

The kit consists of the following components:

- Item A) Panel Mount Brackets – QTY (4)
- Item B) Hinge Swing Arms – QTY (2)
- Item C) Thumb Screws, #10-32 X 5/8" Long – QTY (4)
- Item D) Thumb Screws, #10-32 X 3/8" Long – QTY (2)

- Item E) Pan Head Screws, #8-32 X 3/8" Long – QTY (4)
- Item F) Nylon Retaining Washer – QTY (2)
- Item G) Pan Head Screws, #10-32 X 3/8" Long – QTY (2)

- 1) Install Panel Mount Brackets (A) onto the T-rail in the corner of the enclosure (x4).
- 2) On the Hinge Swing Arm side of the enclosure, install bracket T-rail slot to be 3/16" below the top of the T-rail (x2).
- 3) On the non-swing side of the enclosure, align bracket T-rail slot to be flush to the top of the enclosures' T-rail (x2).
- 4) Install and secure Thumb Screw (C) into the lower Panel Mount Bracket's threaded insert and rotate until hand tight (x4).
- 5) Attach Hinge Swing Arm (B) onto Panel Mount Bracket (A), install onto post in the vertical position and rotate to down position (x2).
- 6) Position Swing Panel (not included) over Hinge Swing Arm threaded inserts and loosely install Pan Head Screws (E) (x4).
- 7) Install Thumb Screw (D) on the free swinging side of the panel. Install Retaining Washers (F) on the back side to capivate the Thumb screws. Note: Optional Pan Head Screws (G) should be installed if high voltage is present behind panel.
- 8) Tighten the Thumb Screws (D), (or optional Pan Head Screws (G)) and align panel.
- 9) Fully tighten the Hinge Swing Arm Pan Head Screws (E), (x4) to 15 in-lbs. Max.

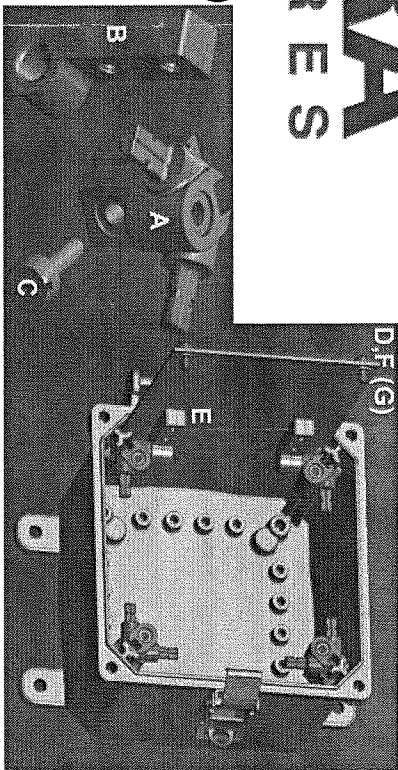

Integra Enclosures, Inc.

7750 Tyler Blvd / Mentor, OH 44060 / Voice 440-269-8155 / Fax 440-269-4977 / www.integraenclosures.com (INSTALL SHT-USOPK_RevA)