

OK SERIES EYEBOLT INSTALLATION GUIDE


| OK Eyebolt BOM | | |
|----------------|-----|------------------|
| Item | Qty | Part Description |
| 1 | 4 | Eyebolt (GLF) |

Tools Required: Driver or Screwdriver, 8mm Hex Bit or Allen Wrench.


Installation Instructions:

1. OKK Top Element Fastener Removal and Eyebolt Installation

- Remove Fasteners:
 - Using an 8mm hex bit or Allen wrench, remove the four M12x20 hex socket screws located at the corners of the top element (Figure 2).
- Install Eyebolts:
 - Thread one eyebolt (Item 1) into each corner of the top element.
 - Rotate until the base of each eyebolt is flush with the removable panel.
- Eyebolt Specifications:
 - GLF: Vertical pull 3330 N, 45° pull 2x1180 N.
 - GLP: Vertical pull 4900 N, 45° pull 2x1750 N.
- Important:** For enclosures with a width over 1600mm (63in) use more than four lifting points. See details below.

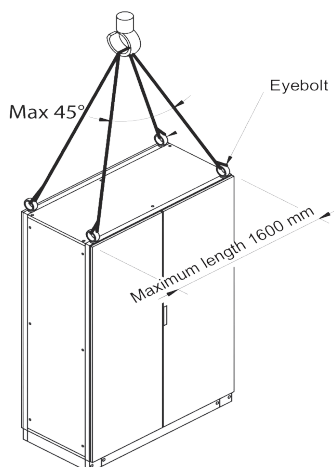

Detail A: Eyebolt (GLF)

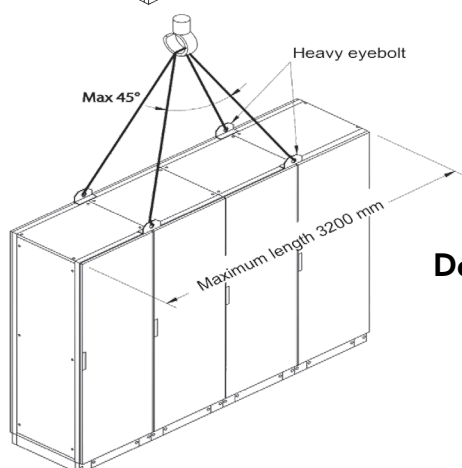

Detail B: Lifting Lug (GLP)

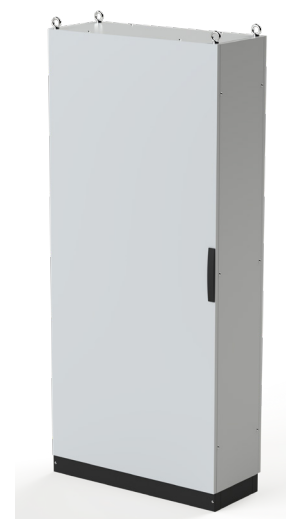


Figure 1

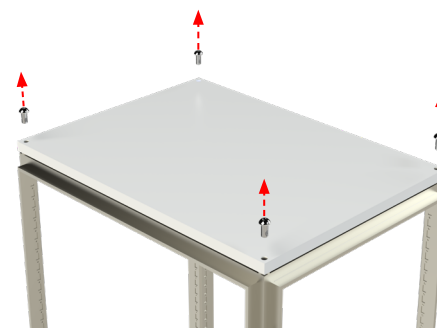


Figure 2

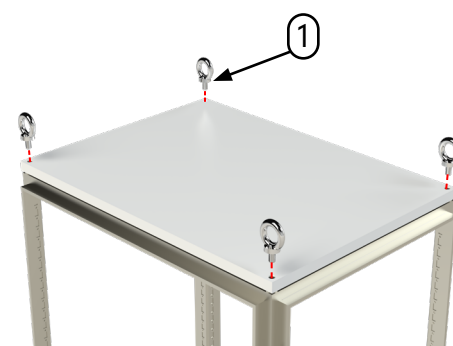


Figure 3



Your Enclosure Source®