


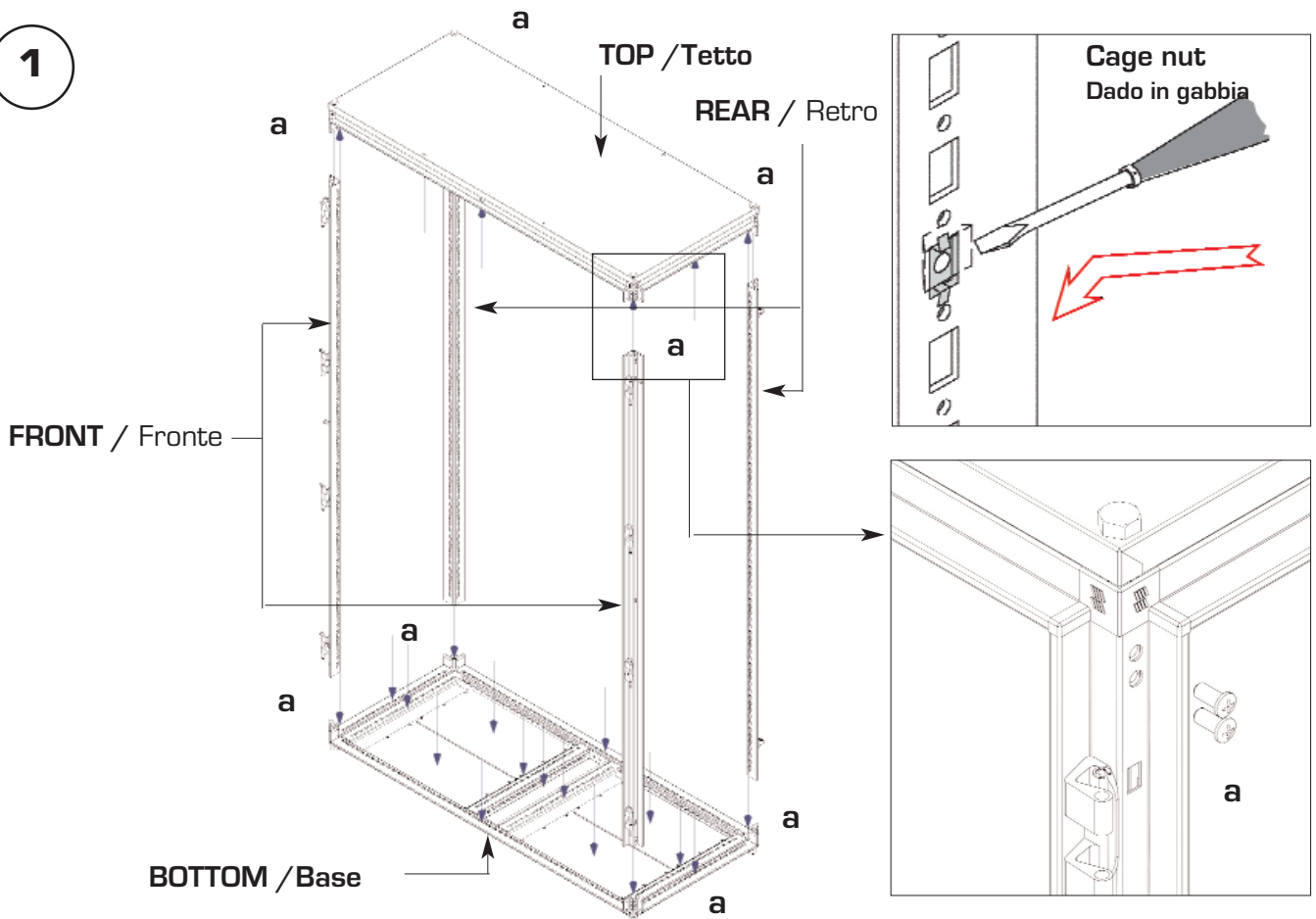
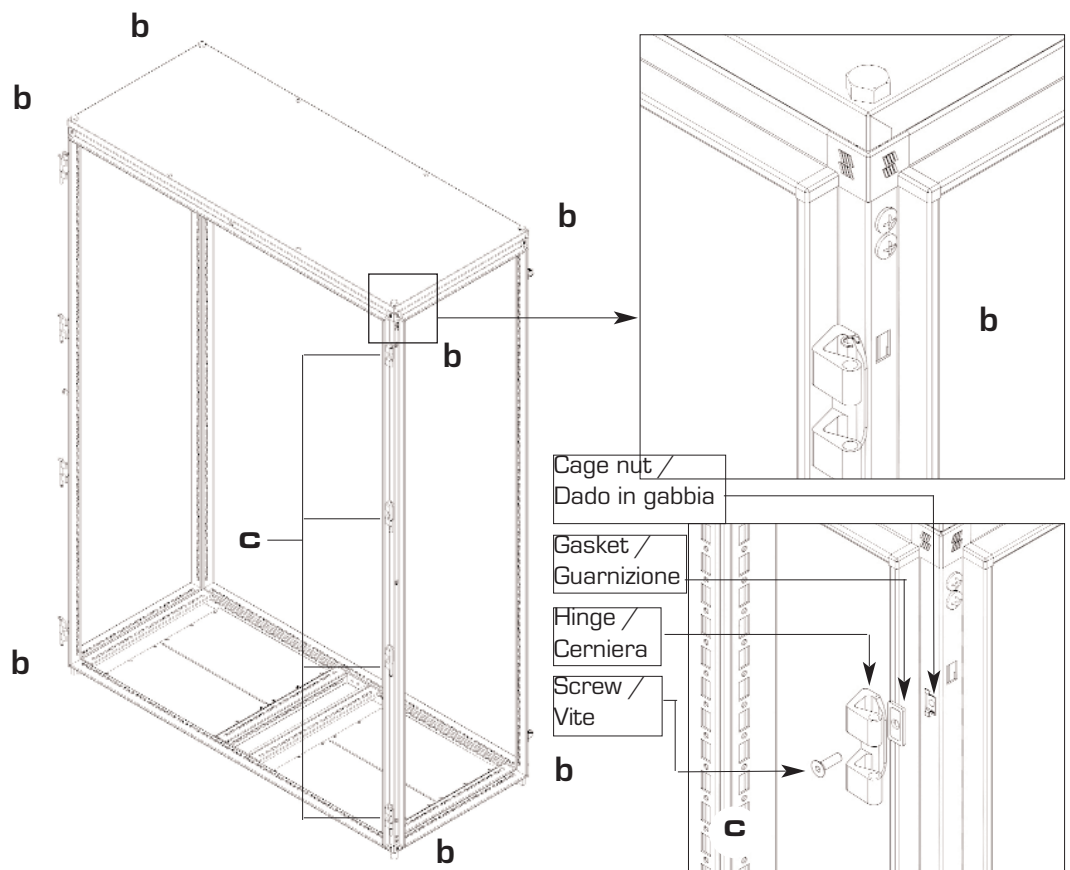
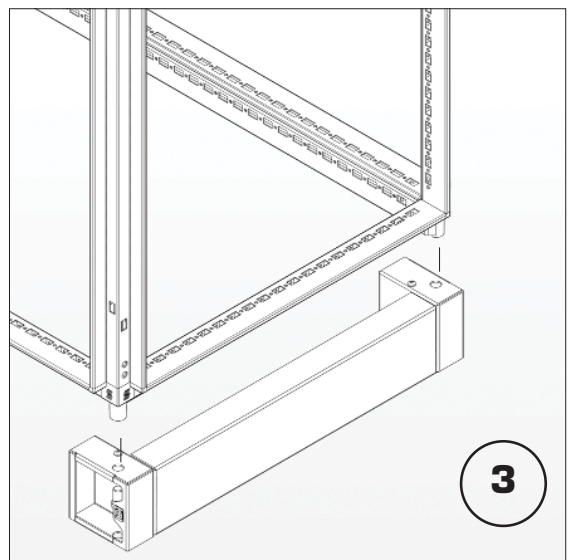
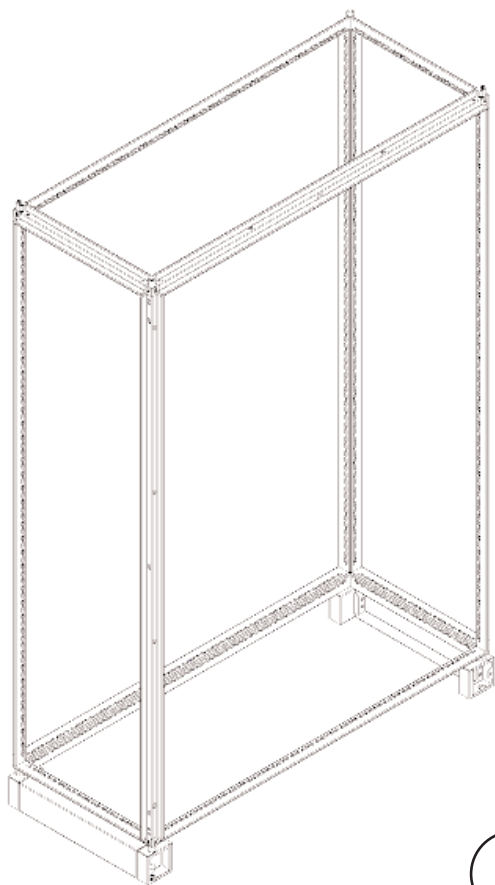


**1**


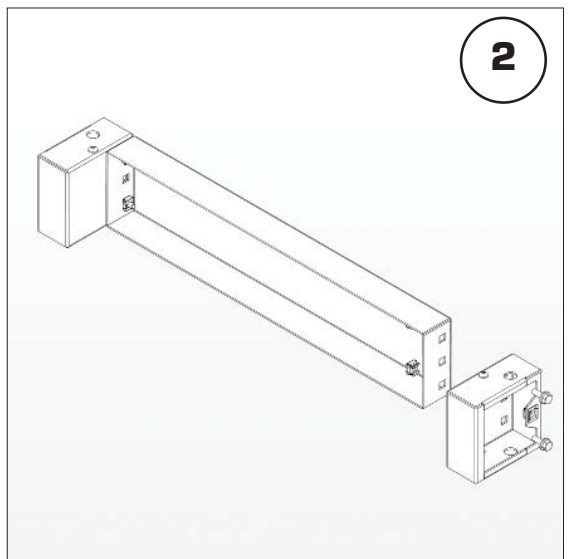



**2**

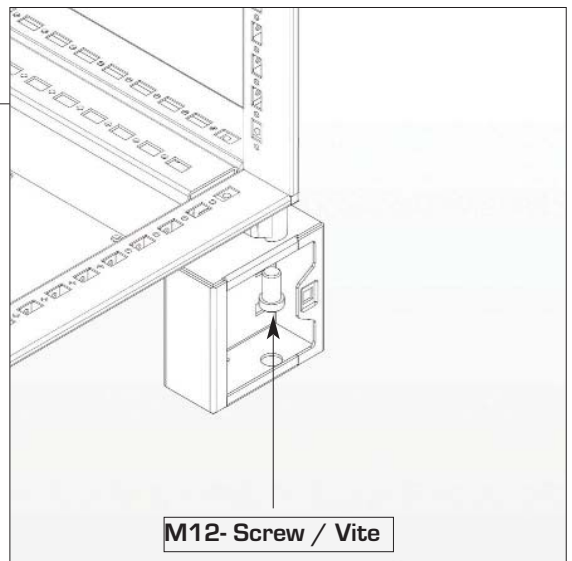


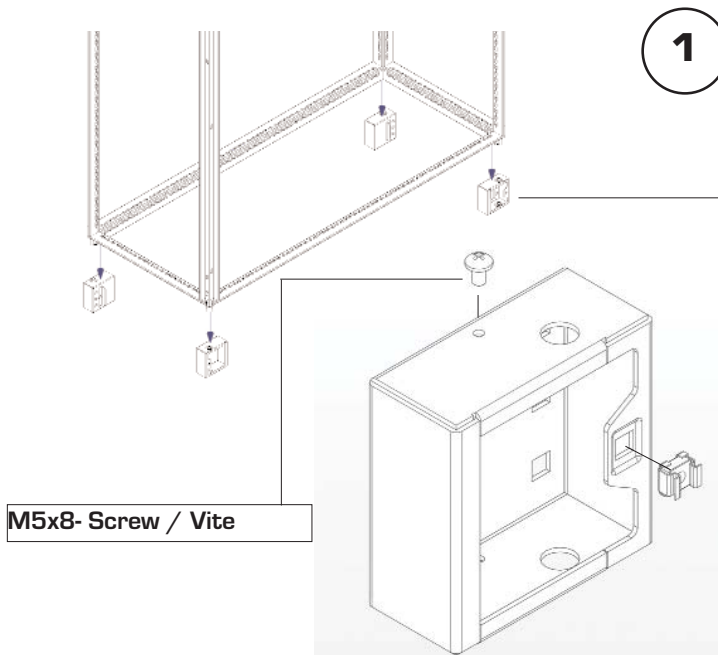


# OK K - FRONTAL PLINTH Basamento FRONTALE


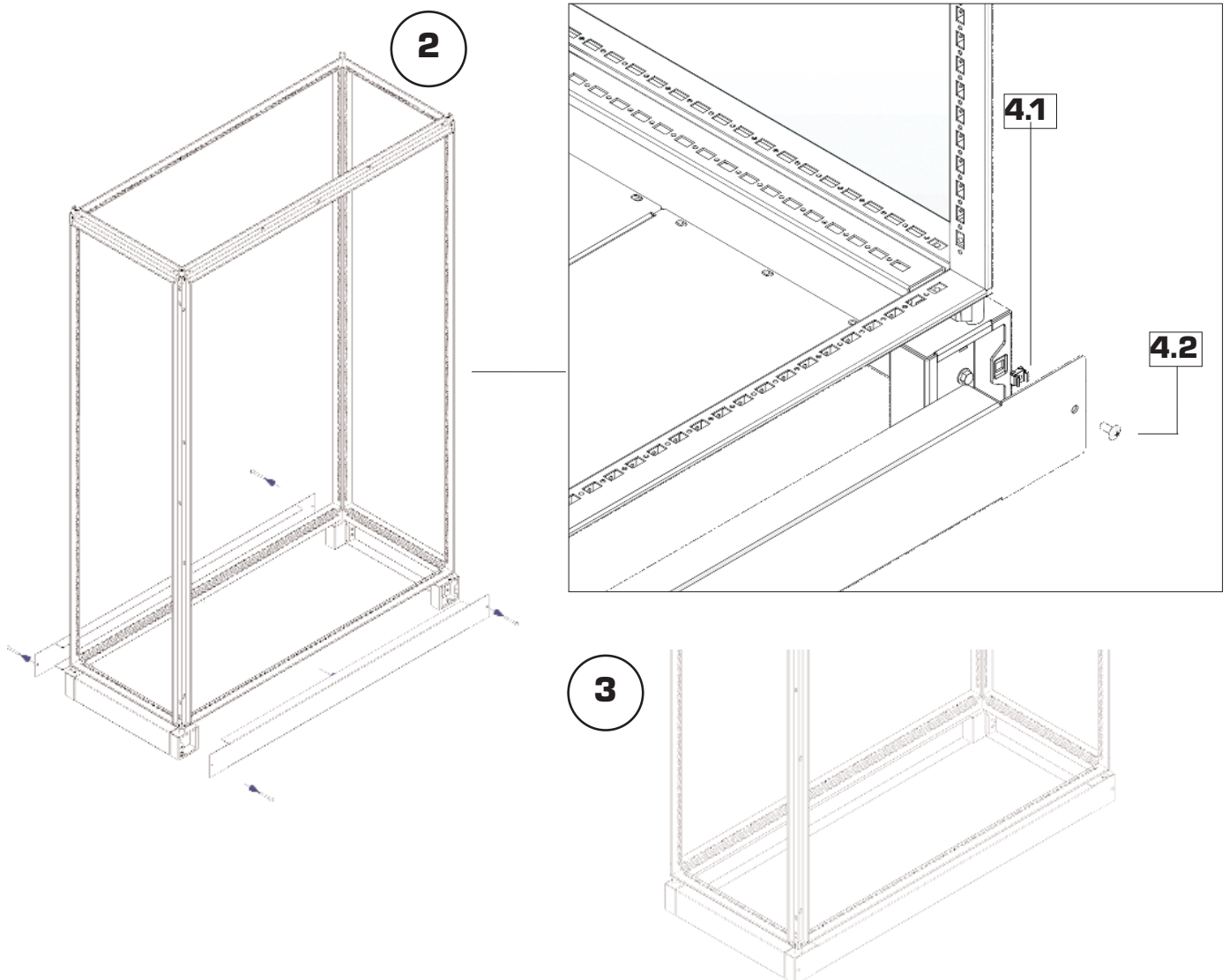
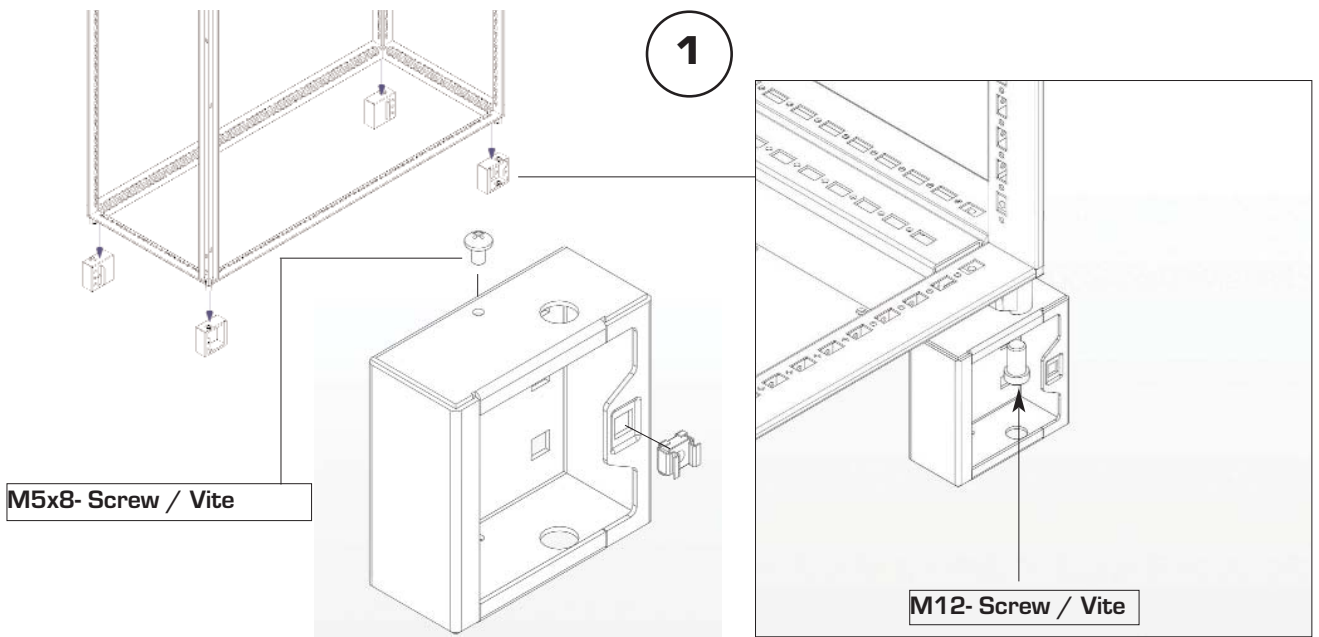


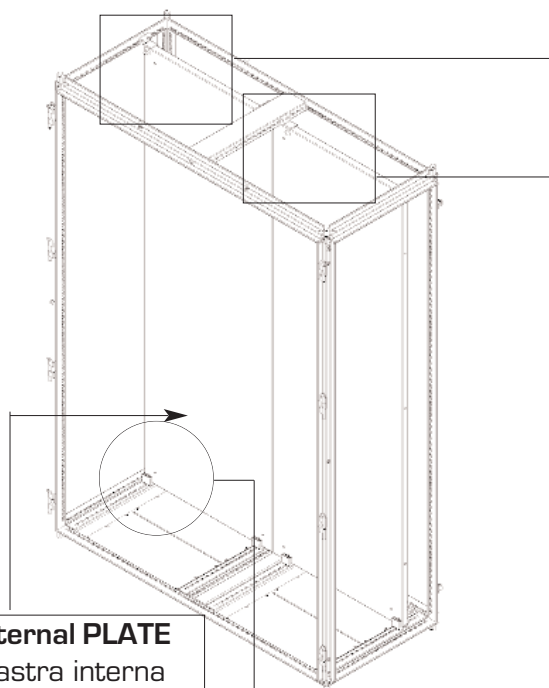




**Internal PLATE**  
Piastra interna

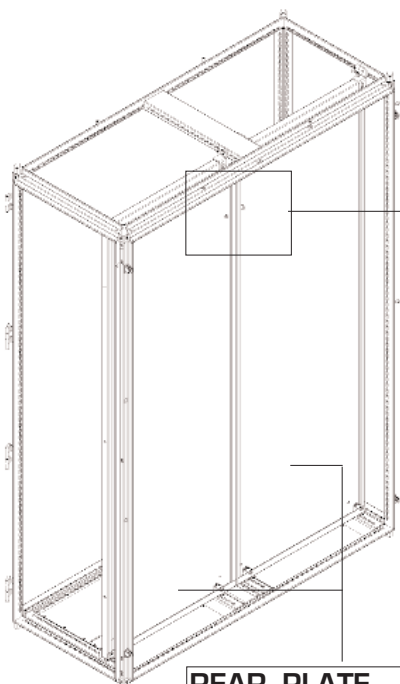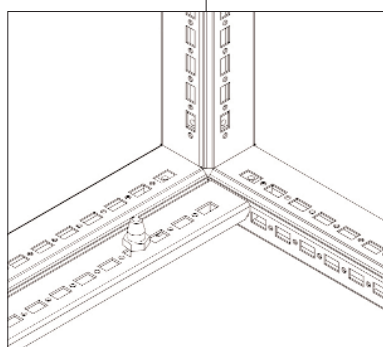

**REAR PLATE**  
Posteriore piastra

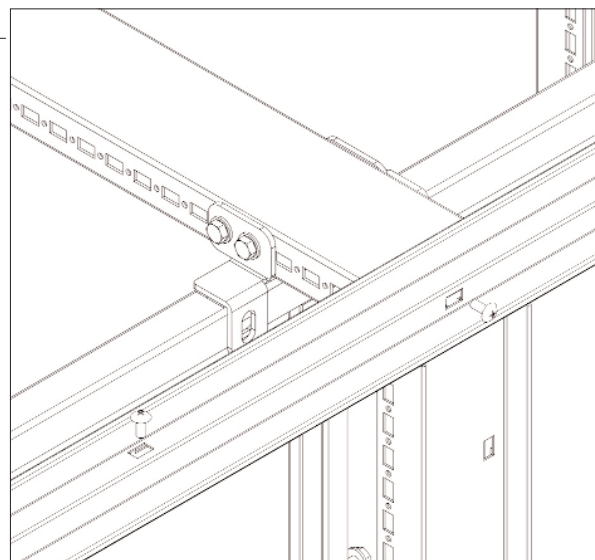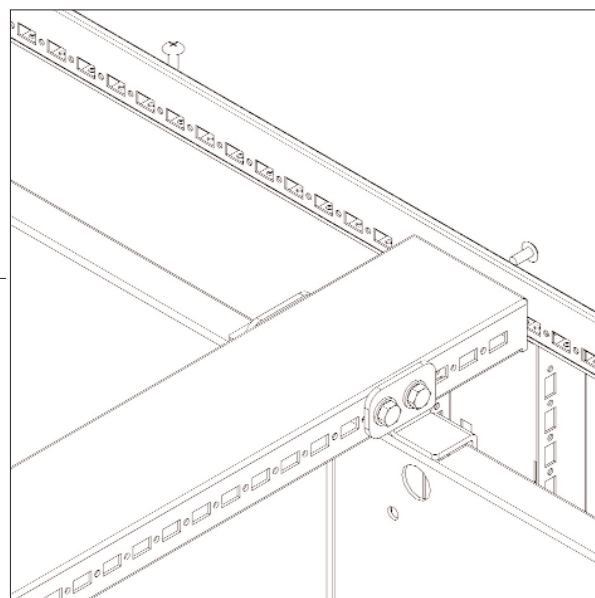
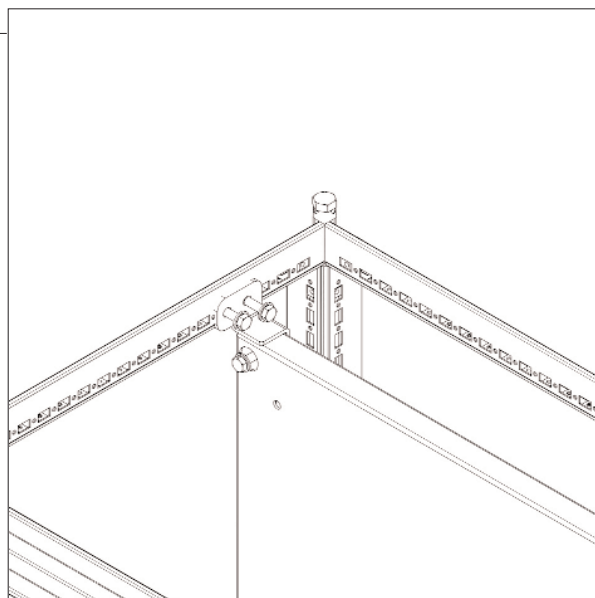


**OK K - SINGLE internal PLATE**  
**Piastra interna singola**

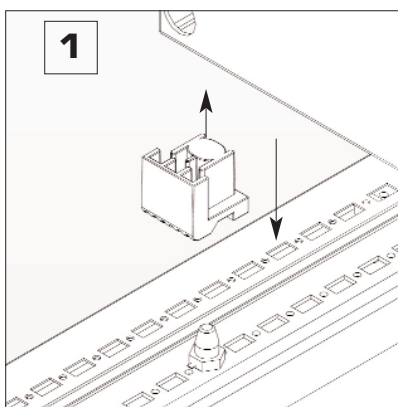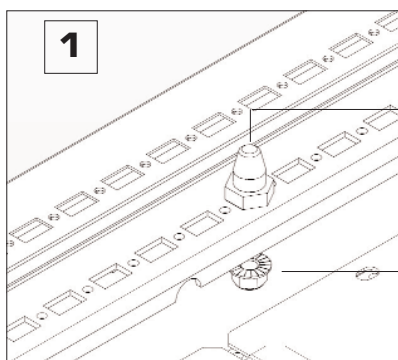
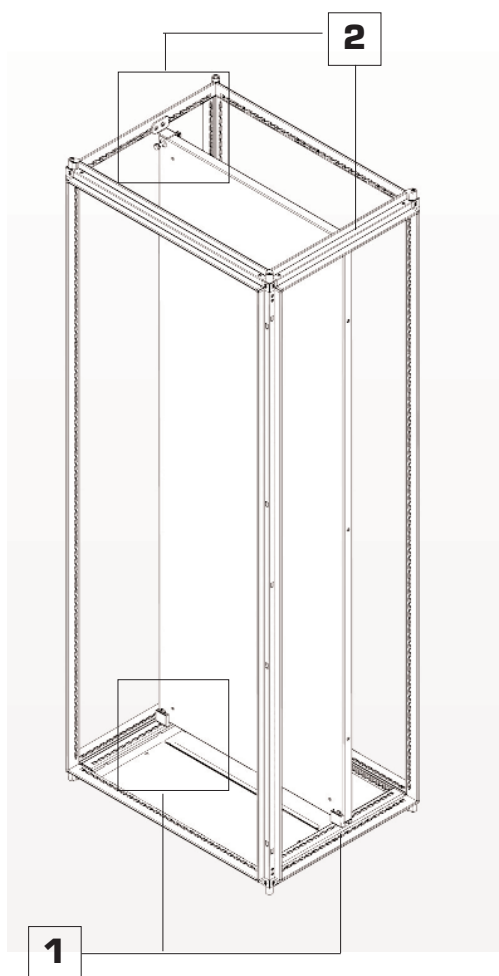


Conic pins  
Perno conico

Nut  
Dado


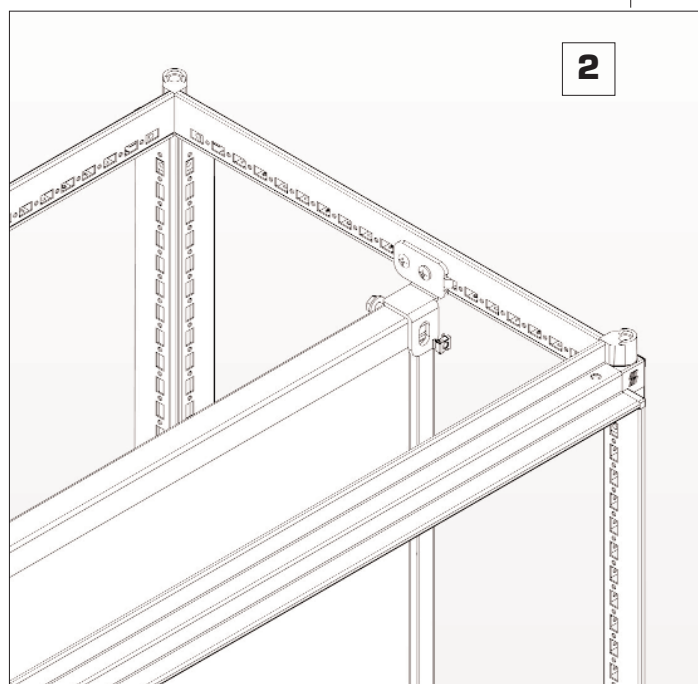
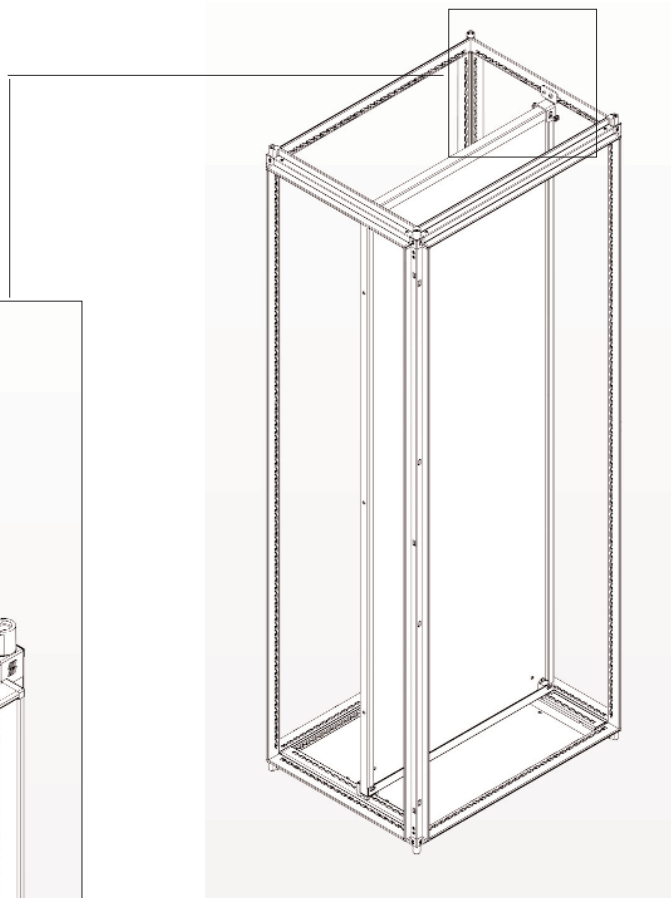




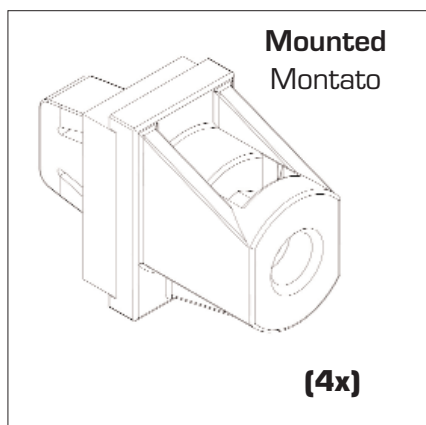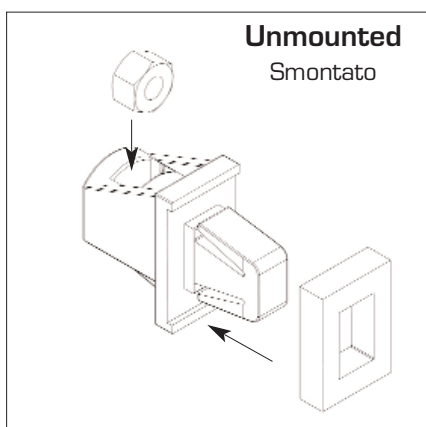


**Screws**  
Viti


**Single Rear panel**

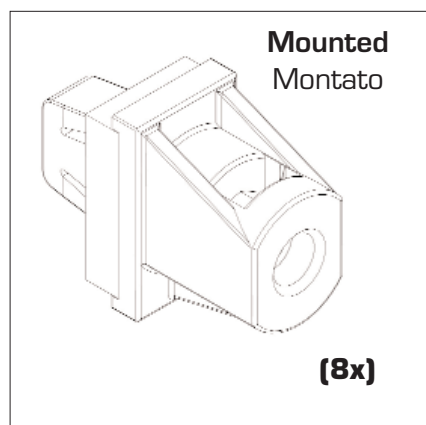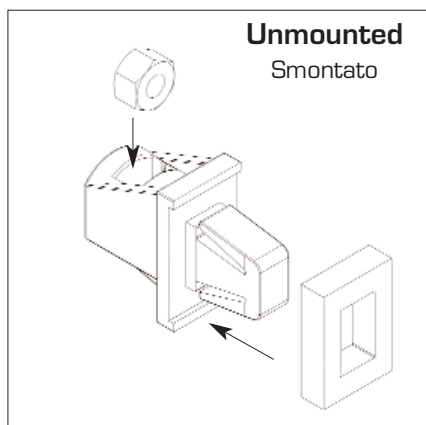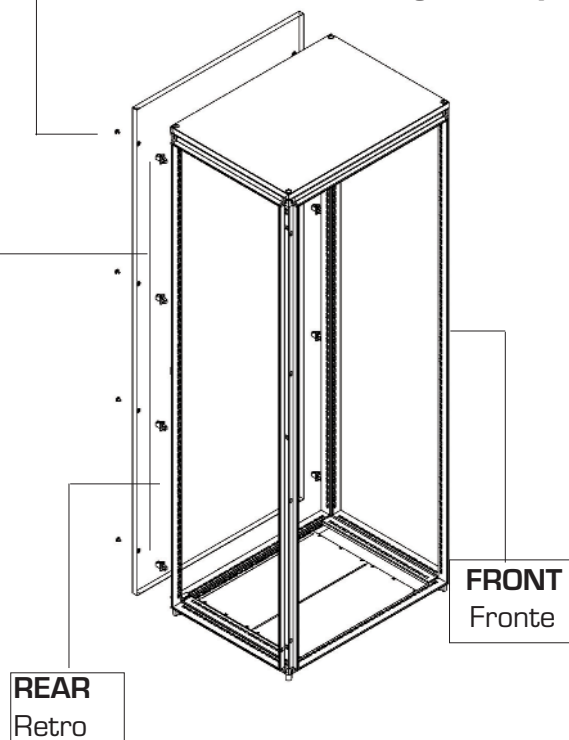


**Double Rear panel**

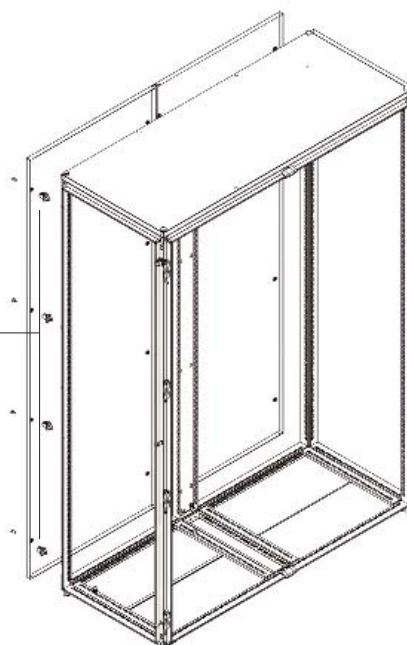


**OK K - CENTRAL REAR / Montante centrale  
UPRIGHT (DOUBLE DOOR)/ Doppia porta**

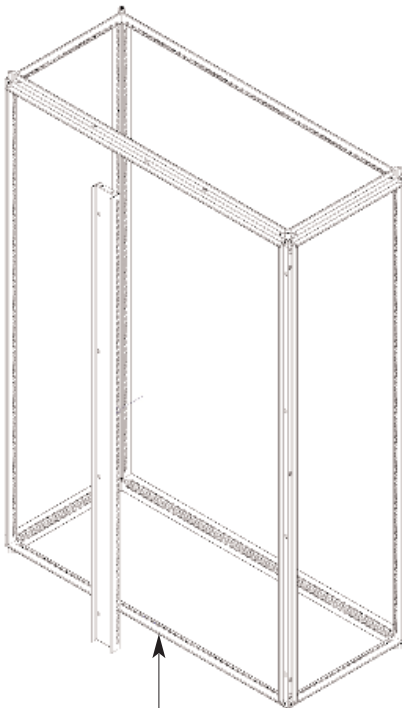





**1** REAR / Retro

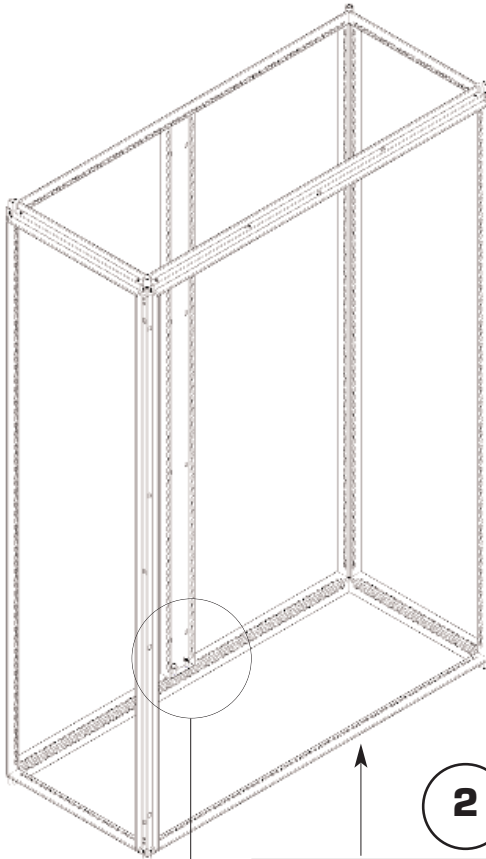

**2** FRONT / Fronte

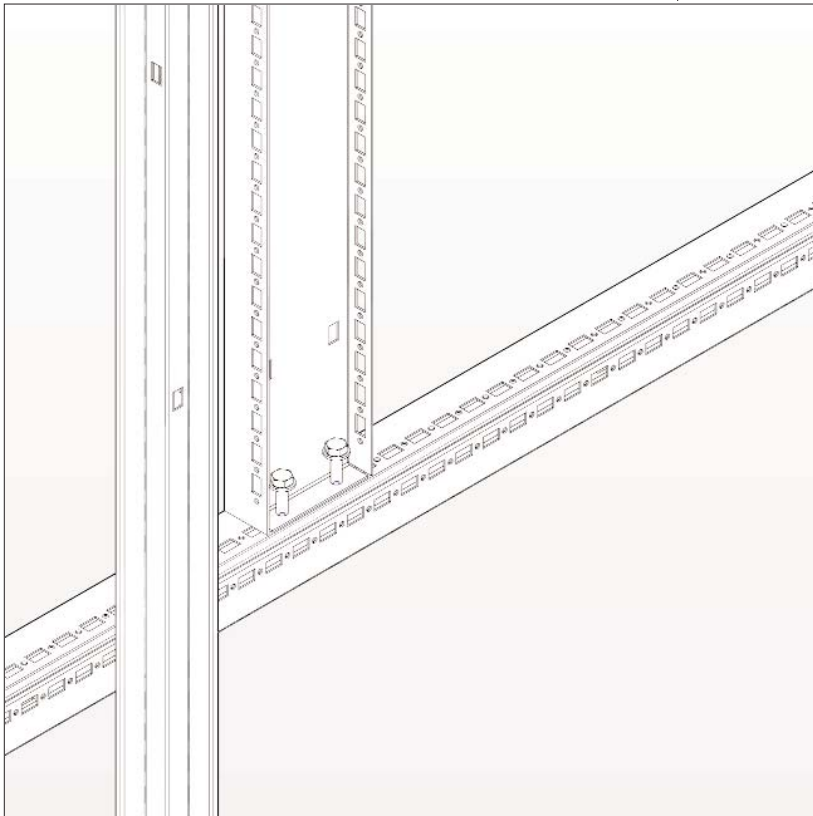



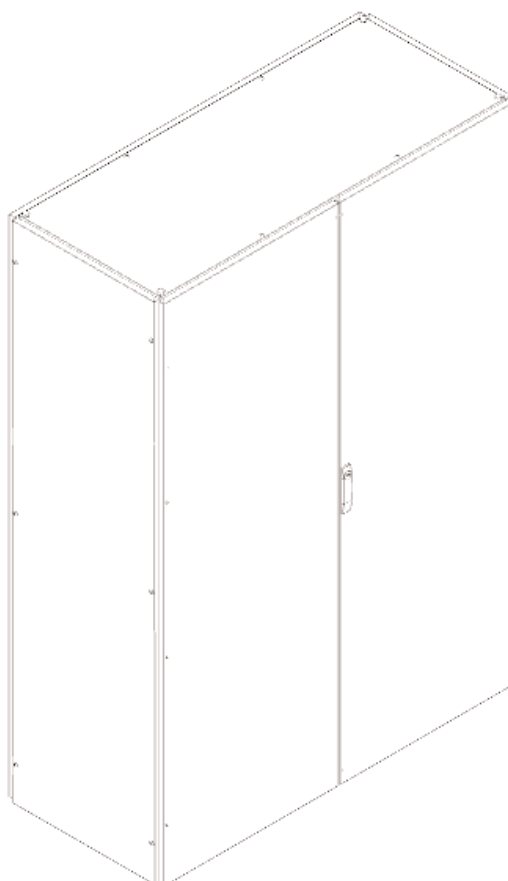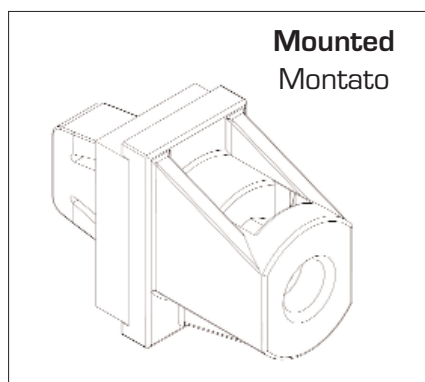
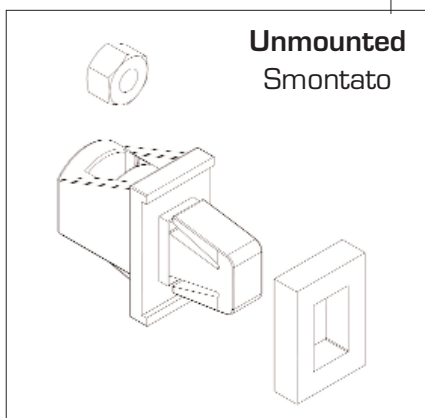
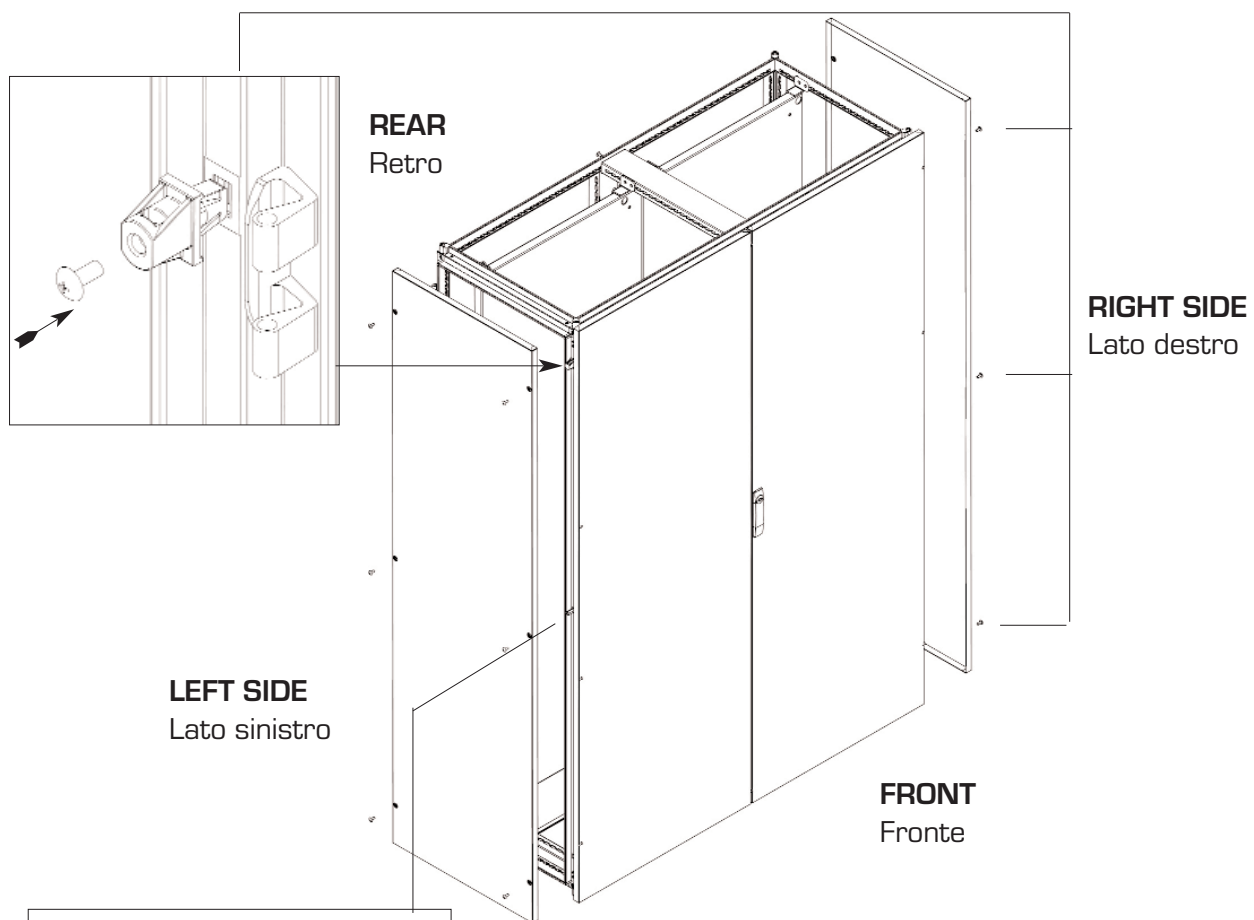


**OK K - FRONT DOOR** (H >1600 mm)  
**Porta anteriore** (H >1600 mm)





1

**LEFT DOOR**  
Porta sinistra

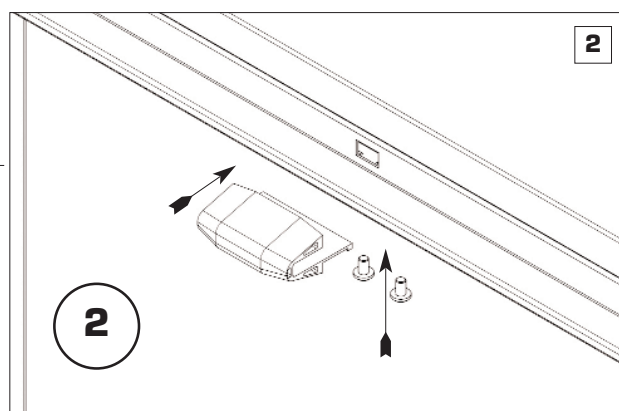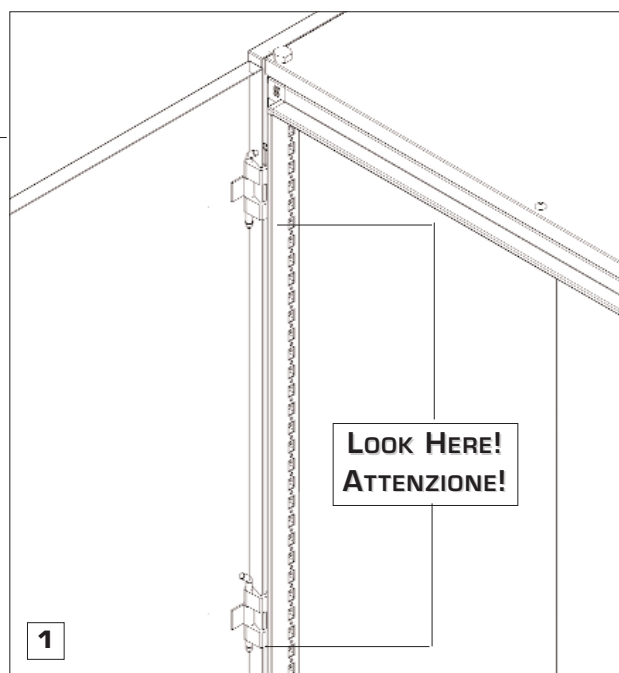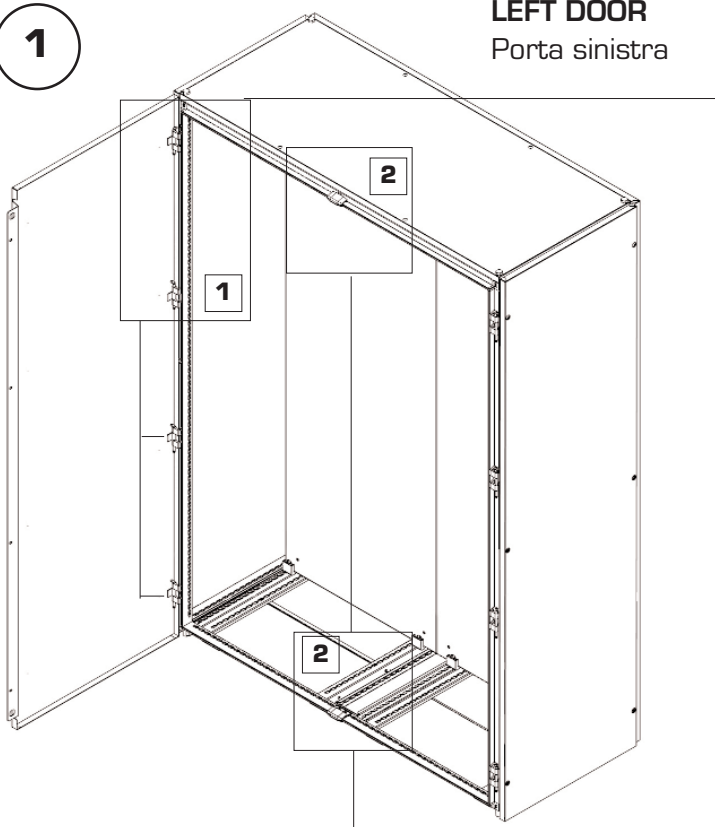



3

**RIGHT DOOR**  
Porta destra

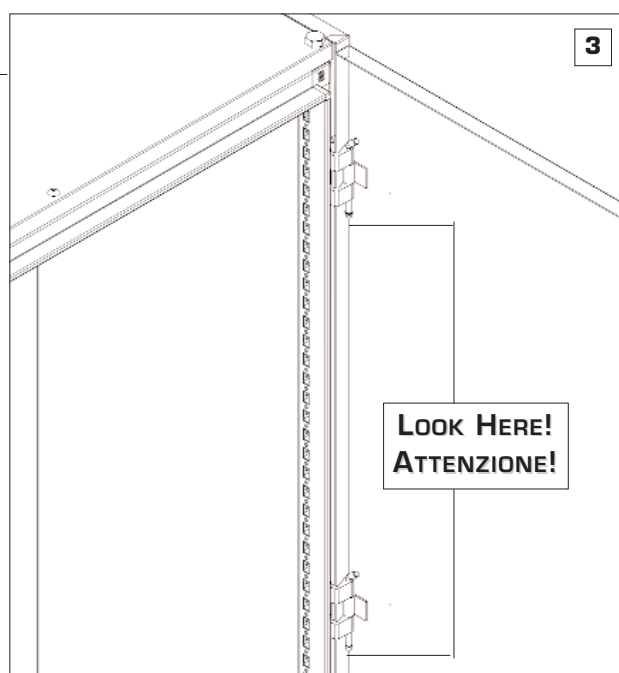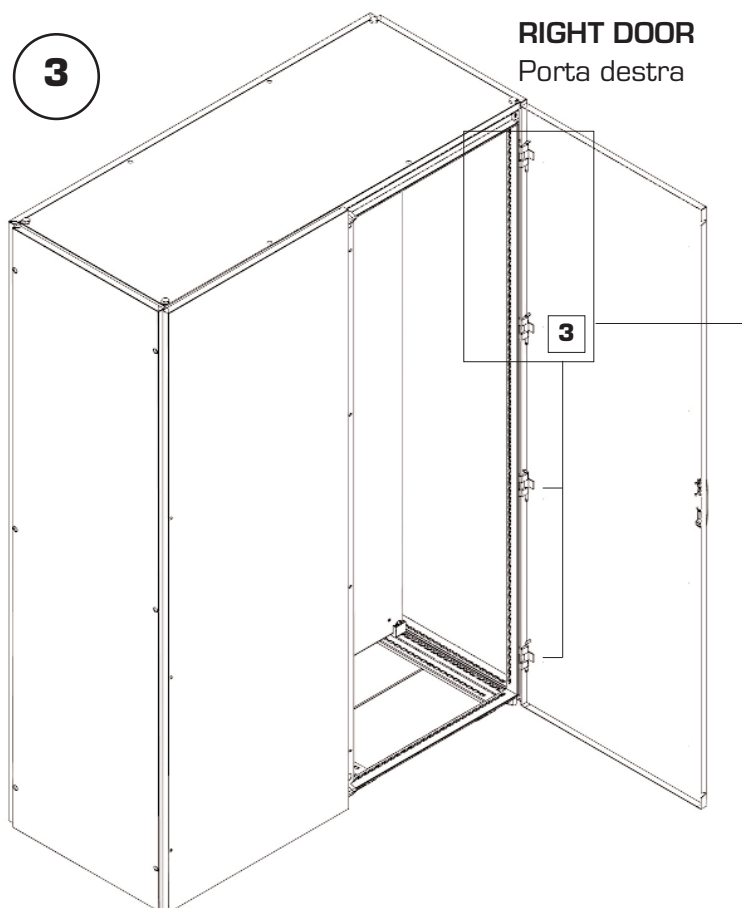


**SINGLE DOOR**  
 Porta singola

1

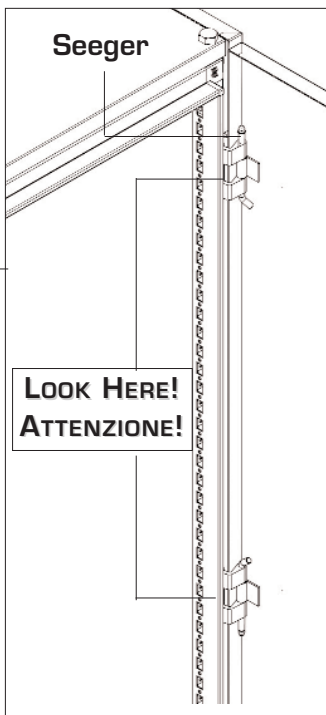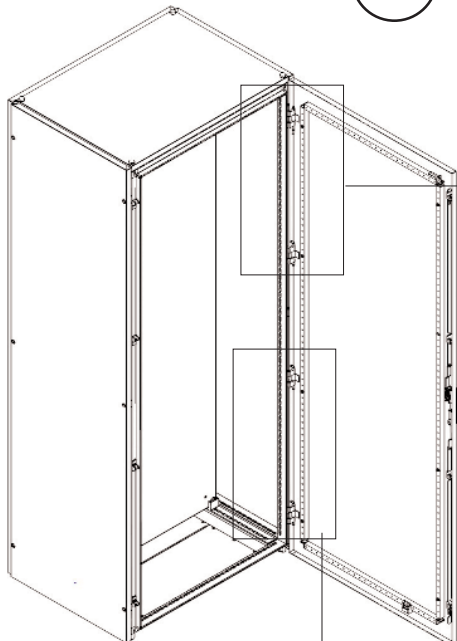


**DOUBLE DOOR**  
 Porta doppia


1

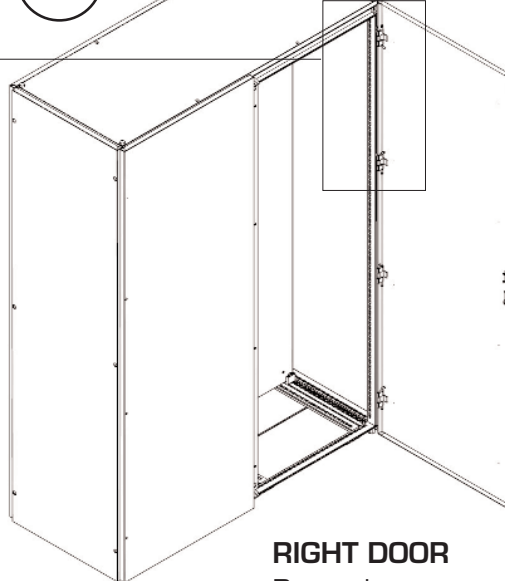


**RIGHT DOOR**  
 Porta destra

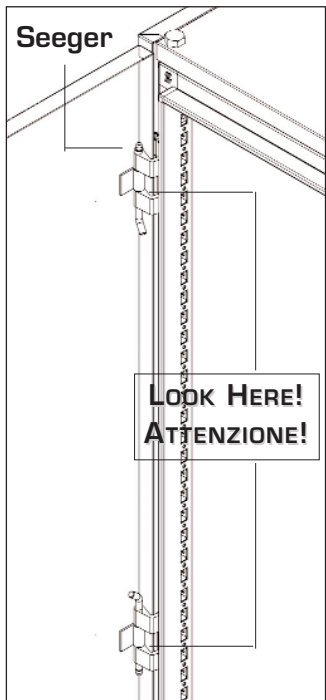


2

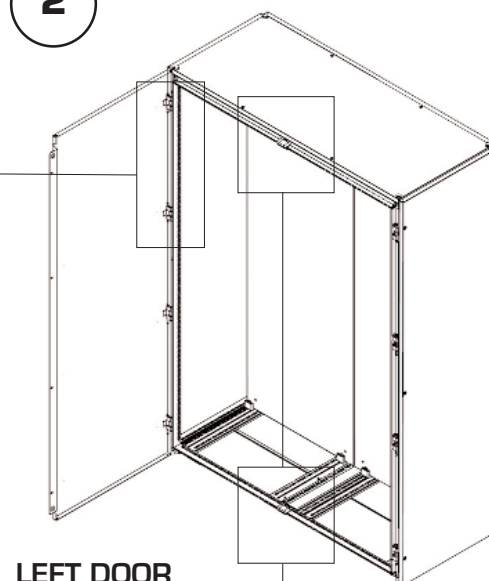


**LEFT DOOR**  
 Porta sinistra

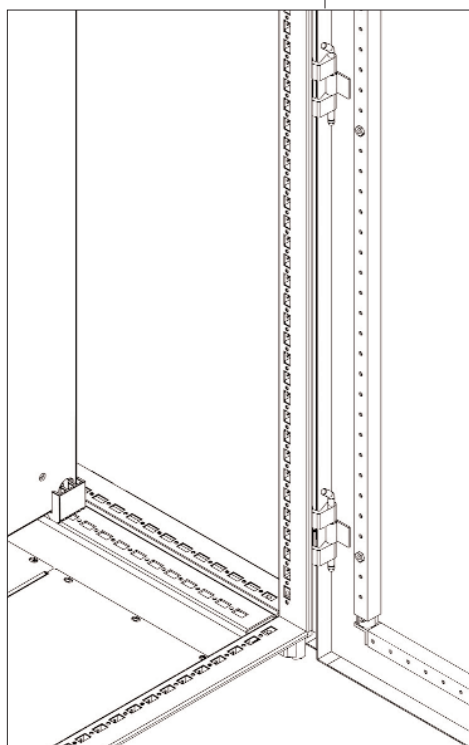

3



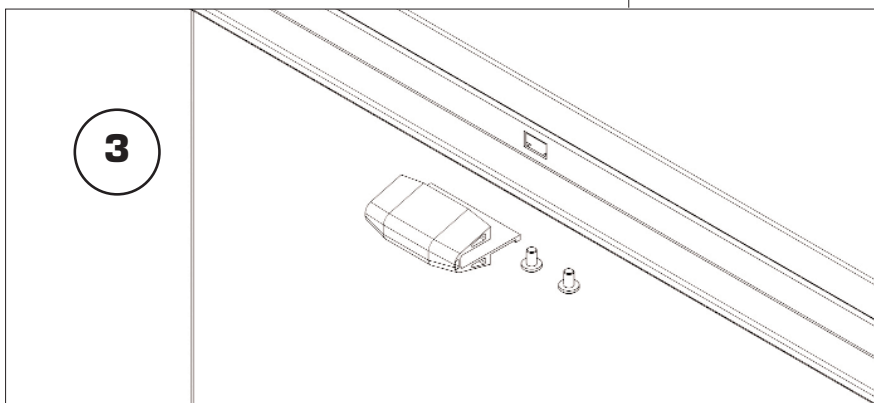





**OK K - Nottolino per serratura**  
**Mounting latch for closure of the door**

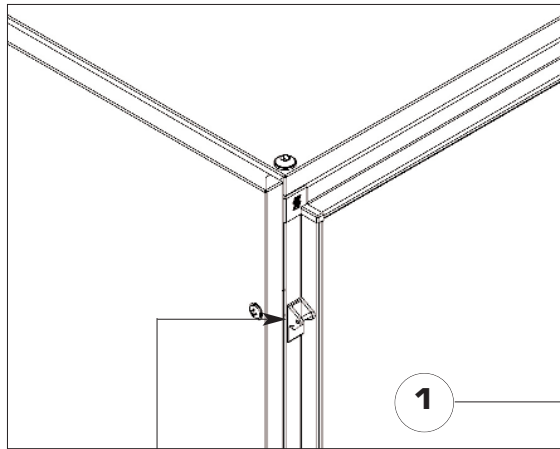




**Look Here !**  
**Attenzione!**

**Look Here !**  
**Attenzione!**

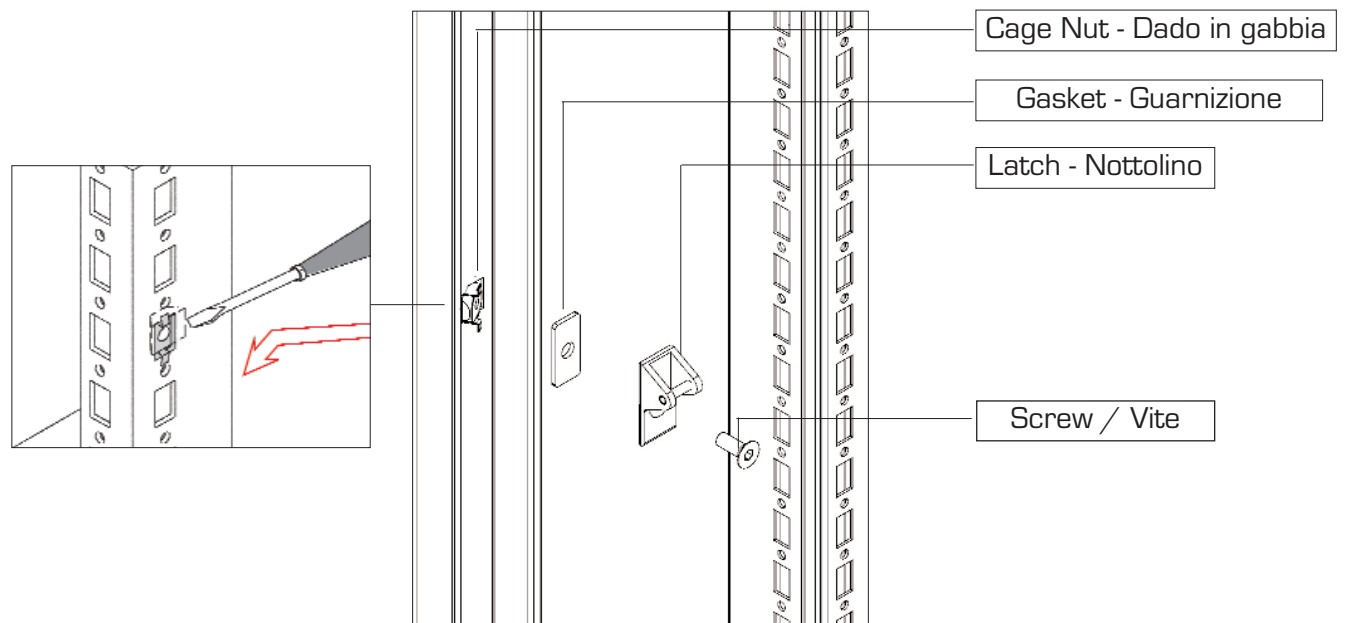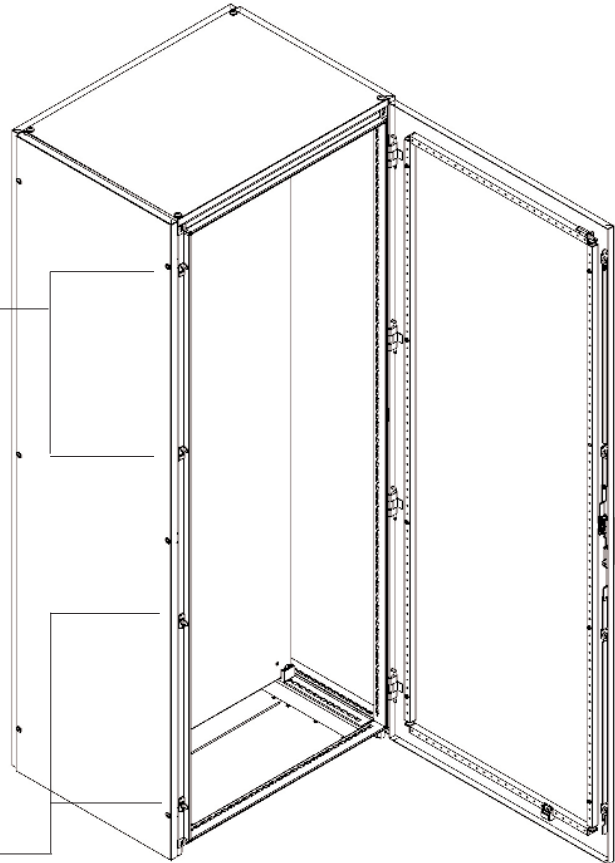
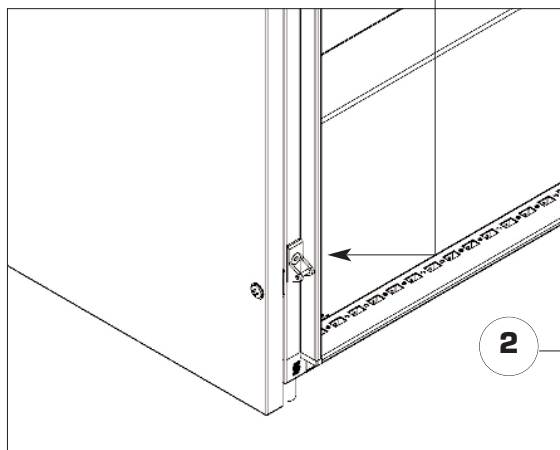


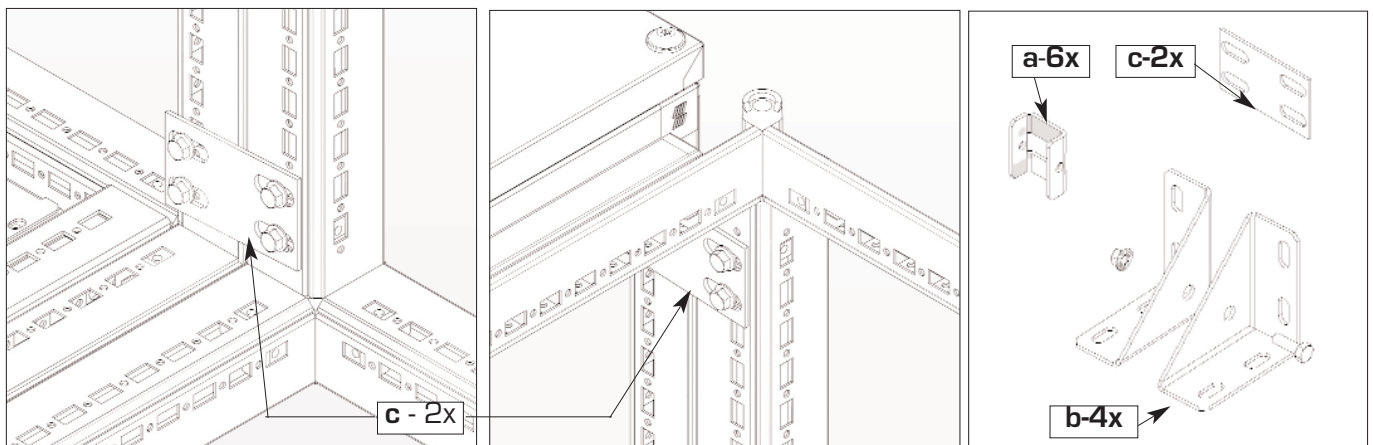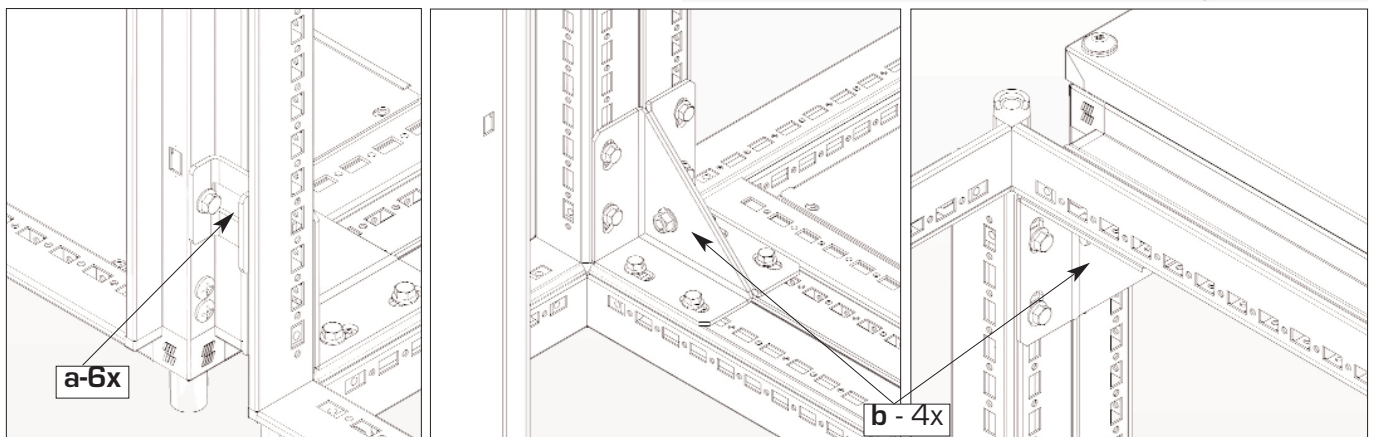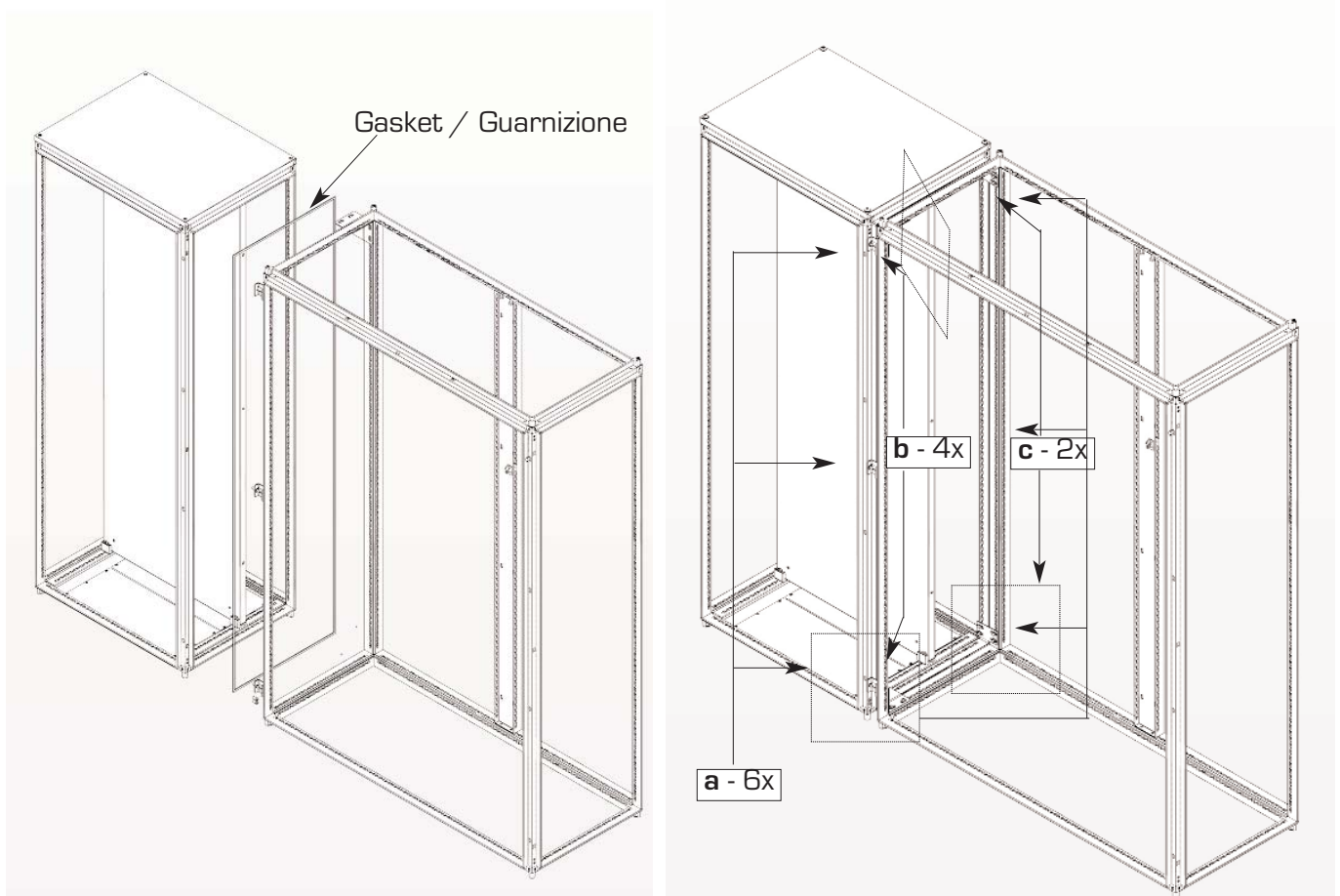


1

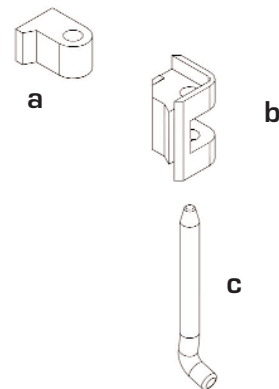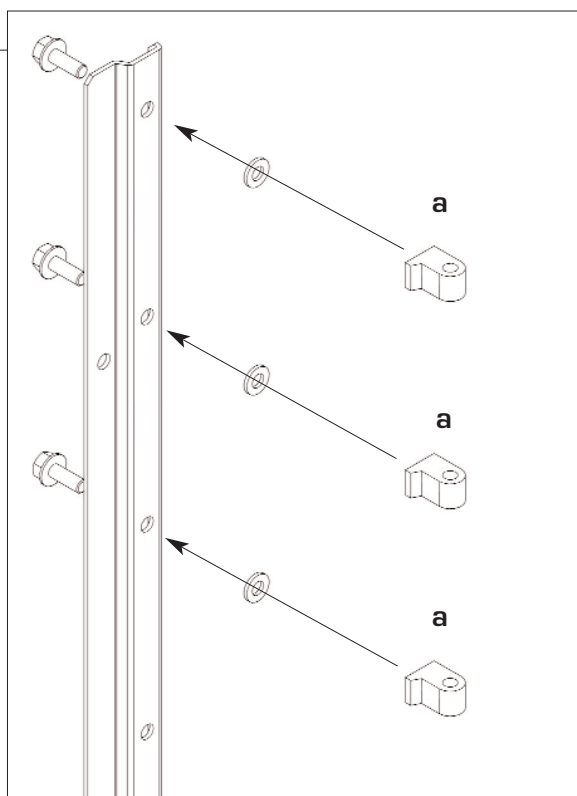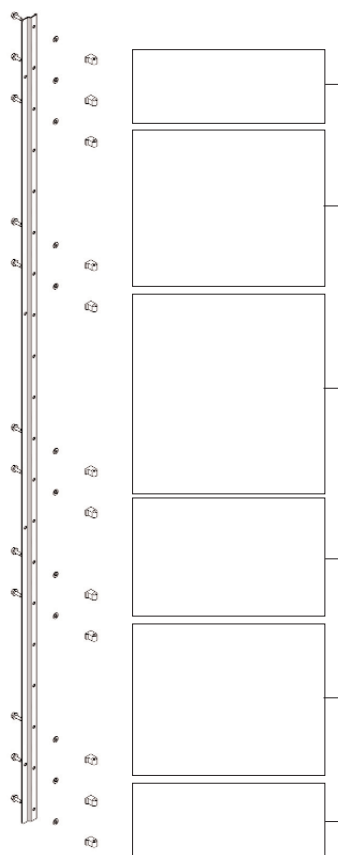


2

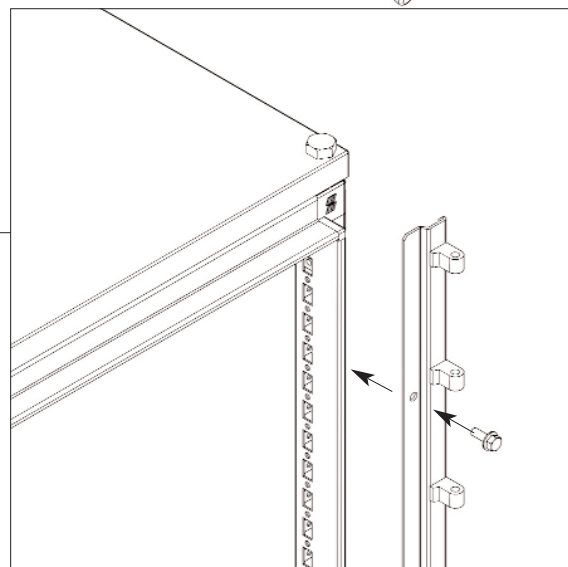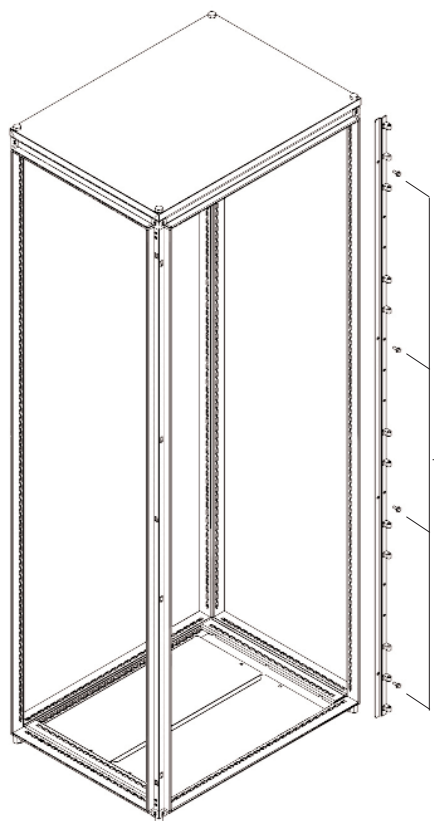




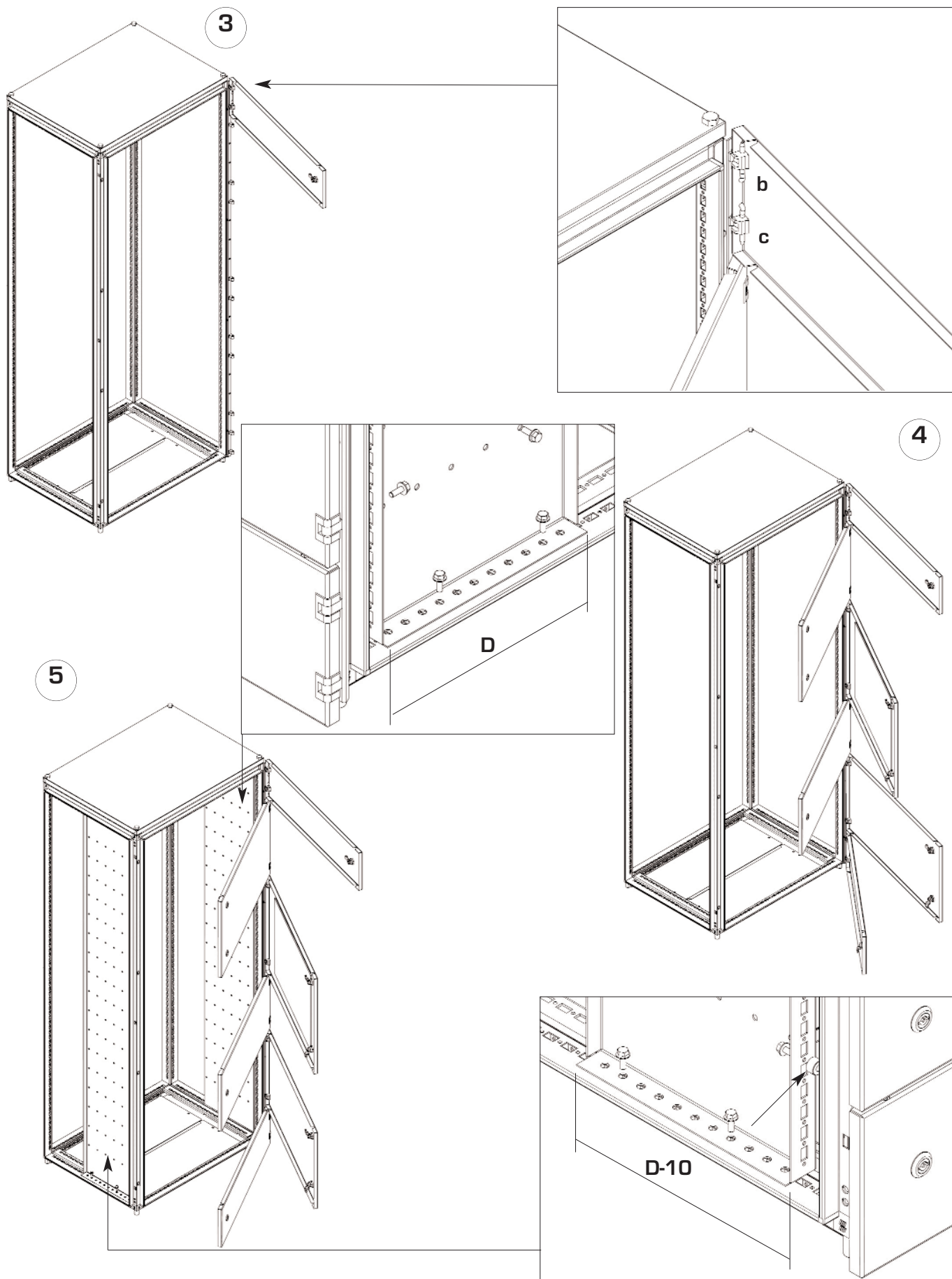


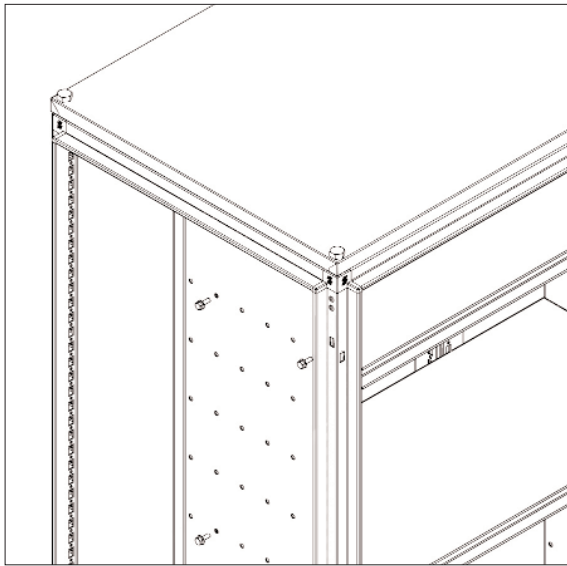



6





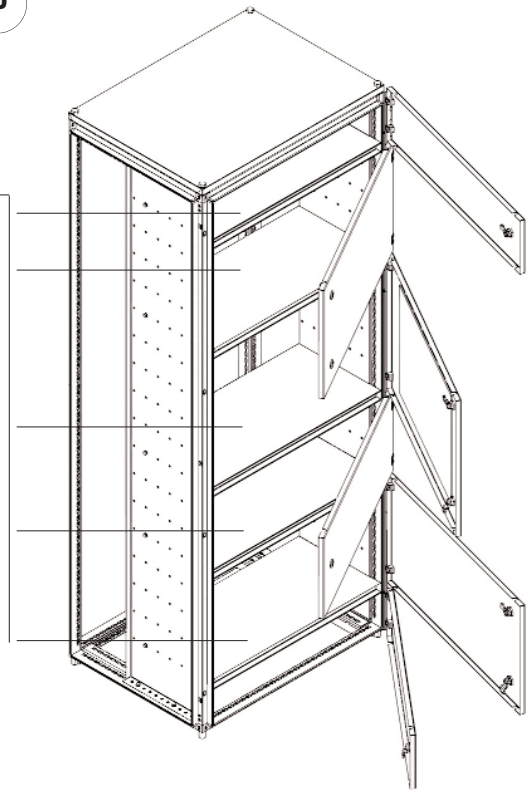




7





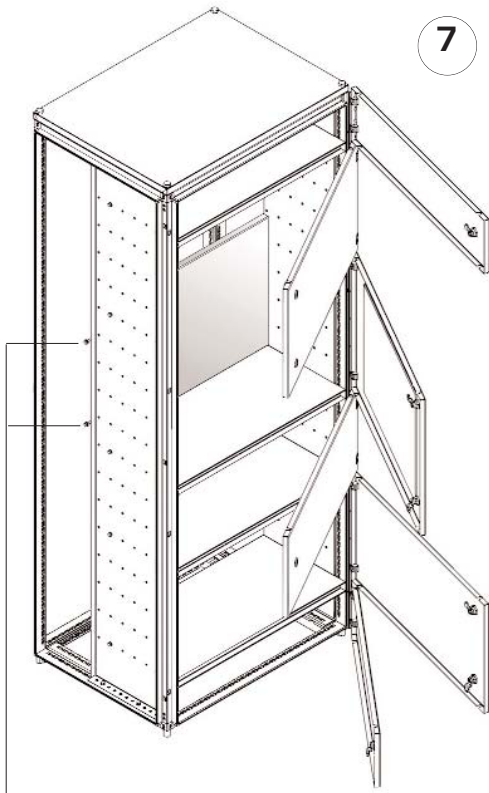








8

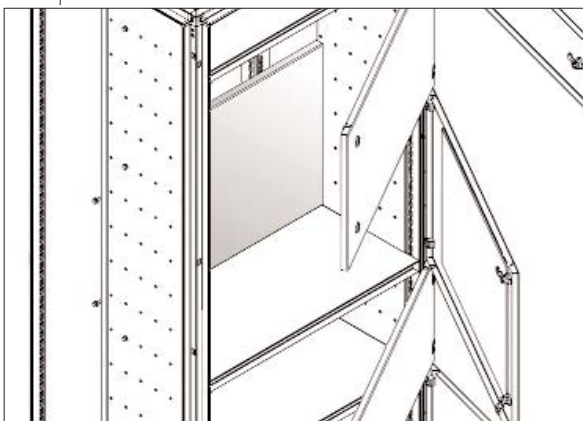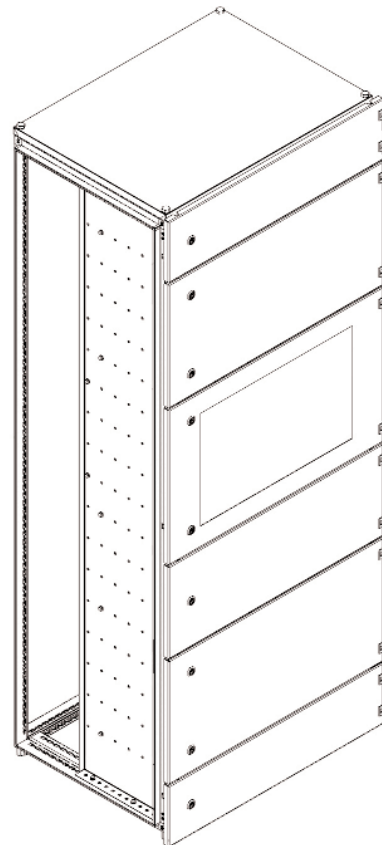


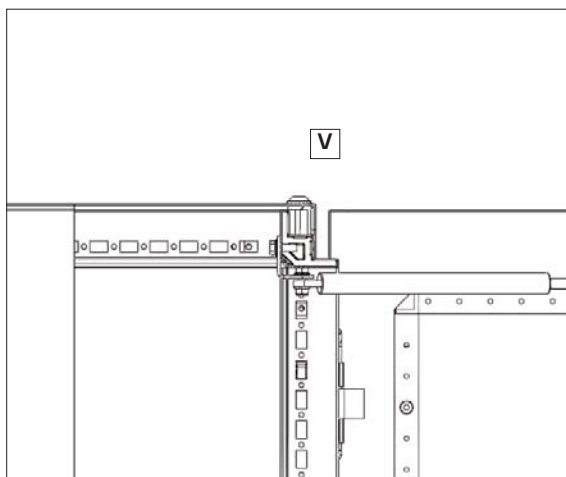
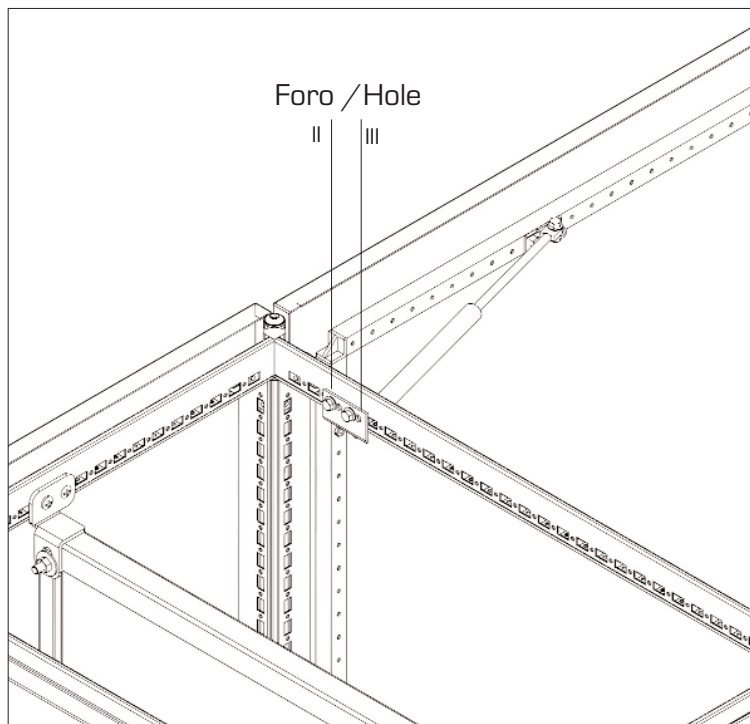
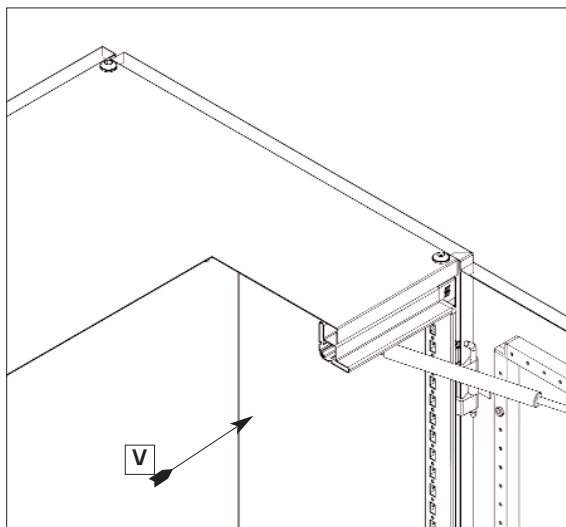
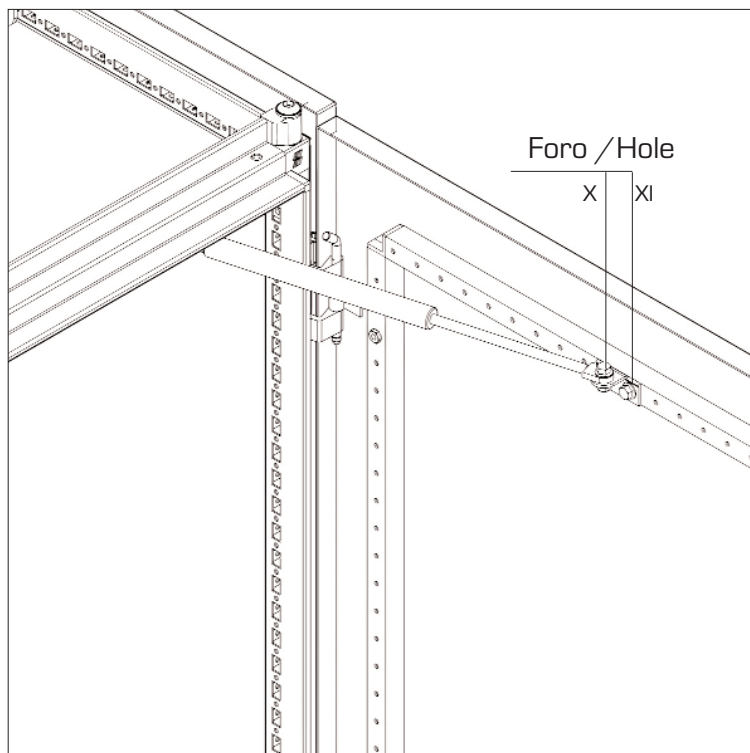
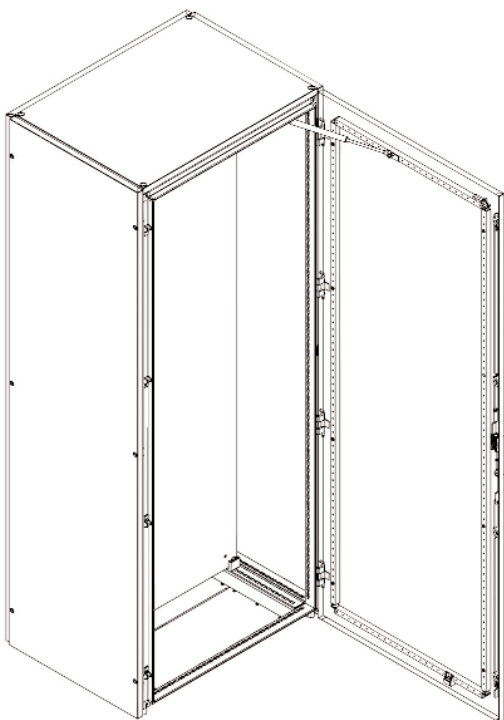


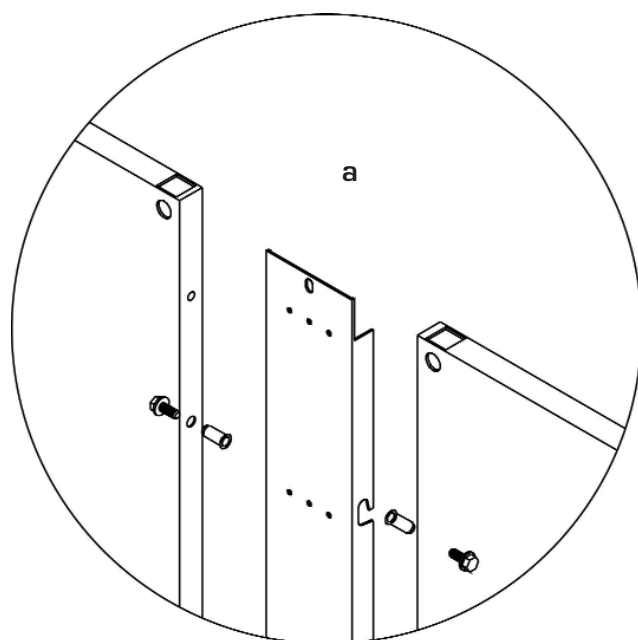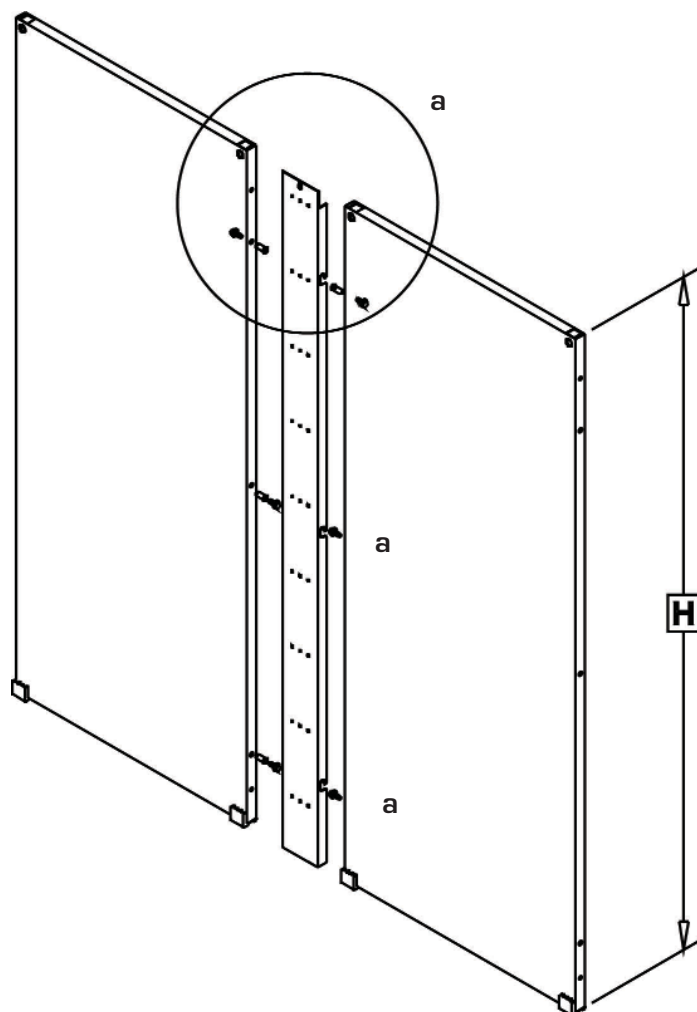

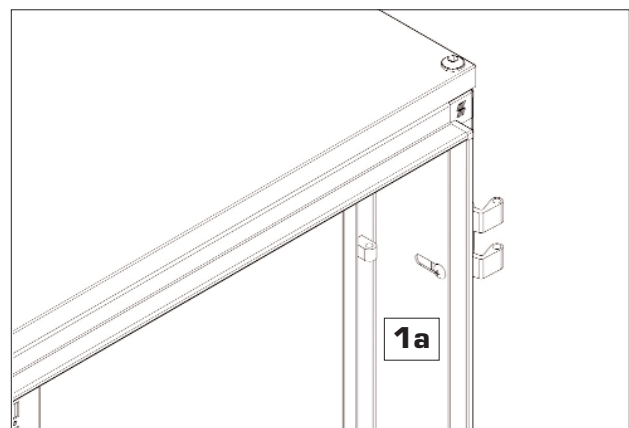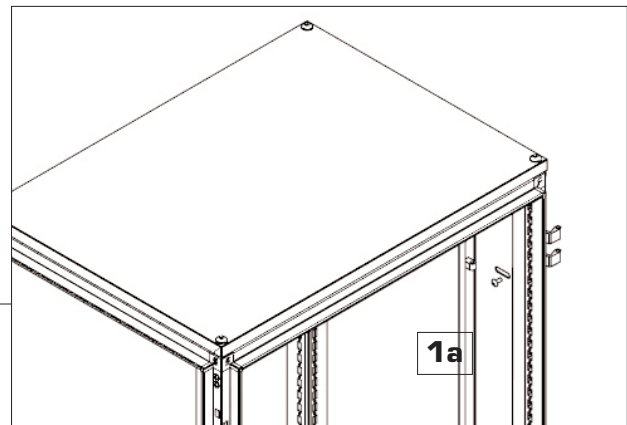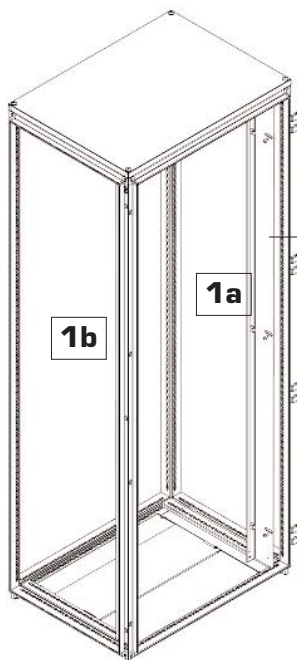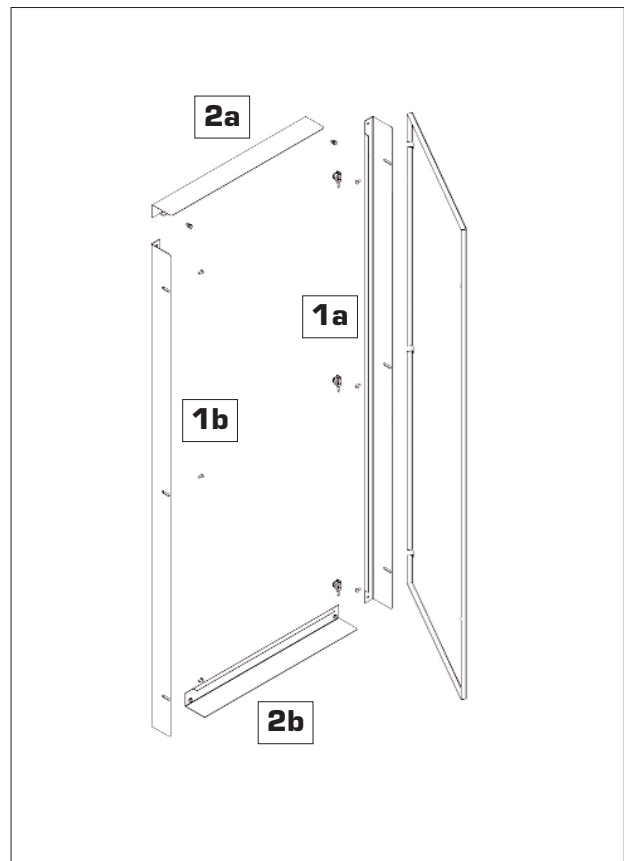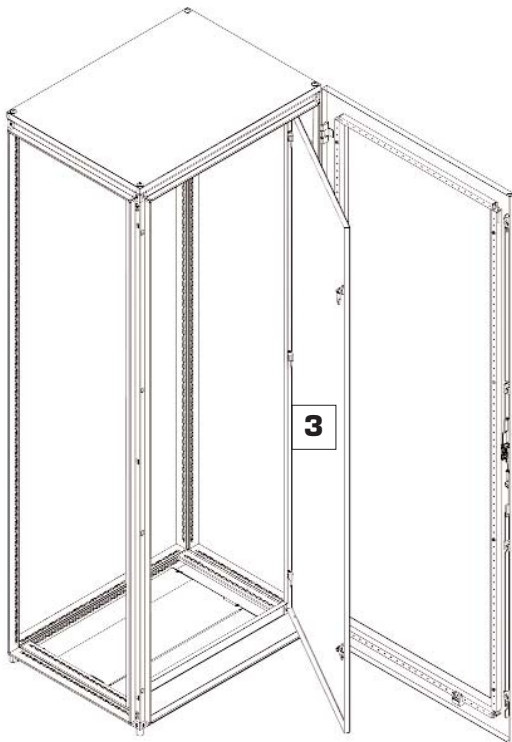

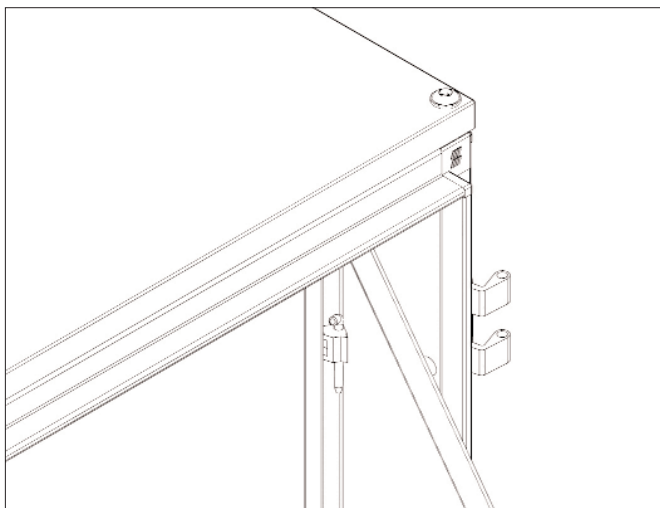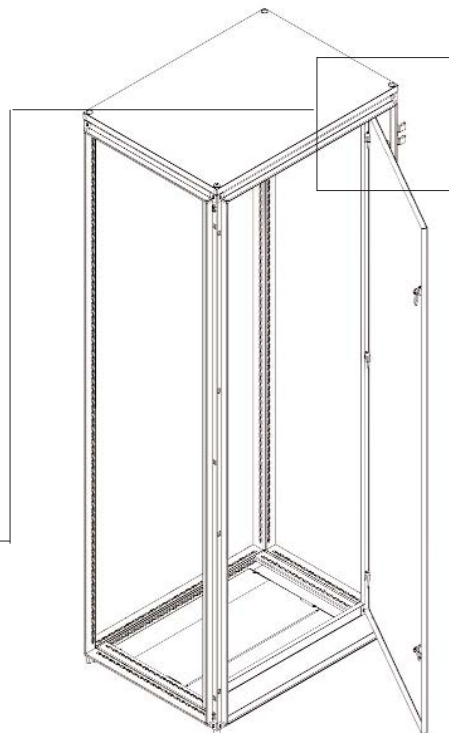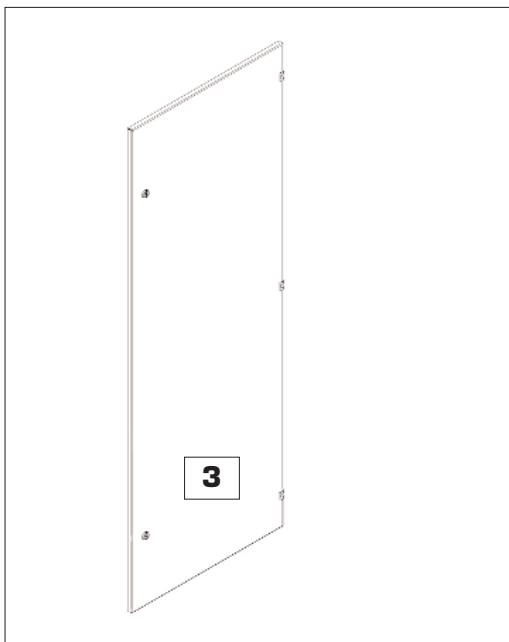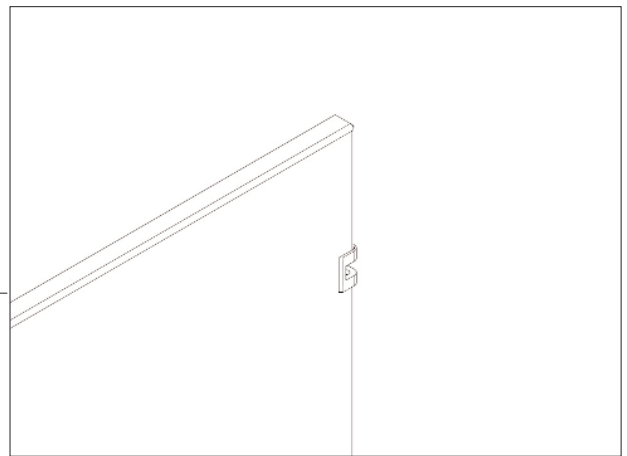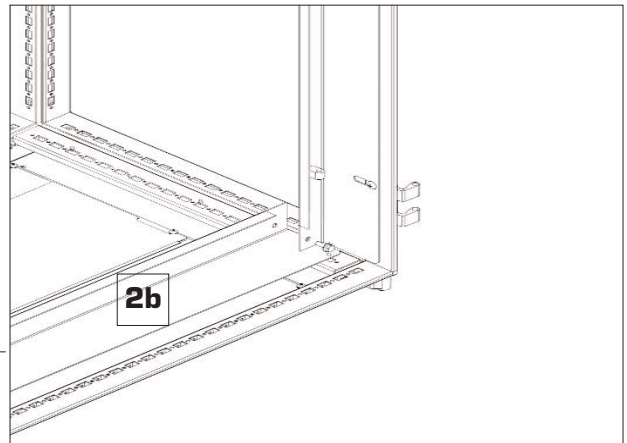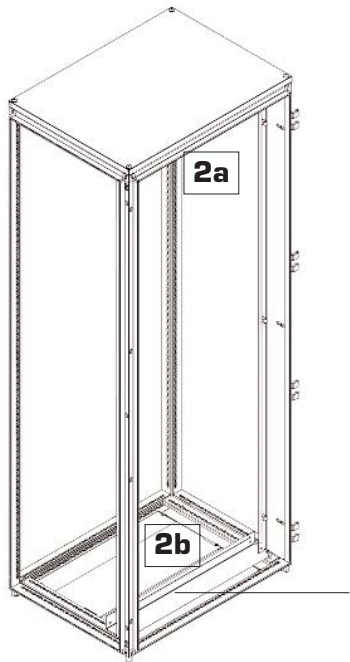








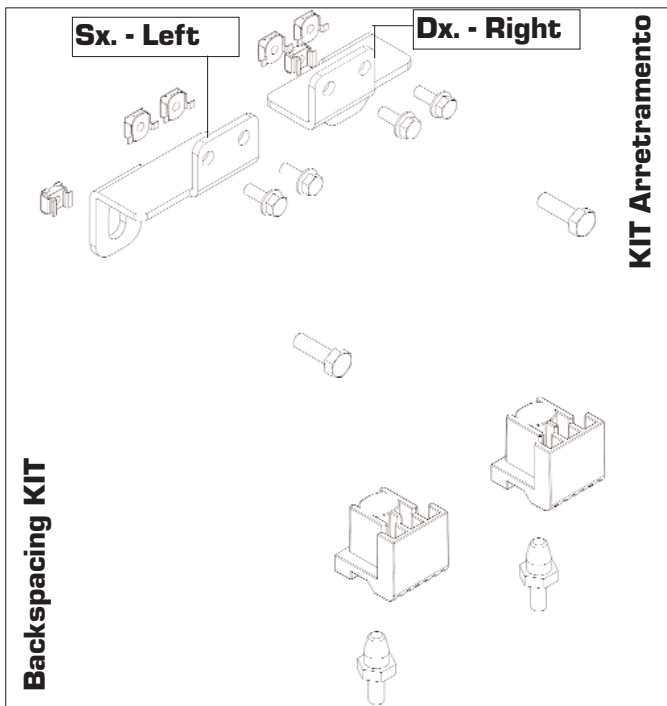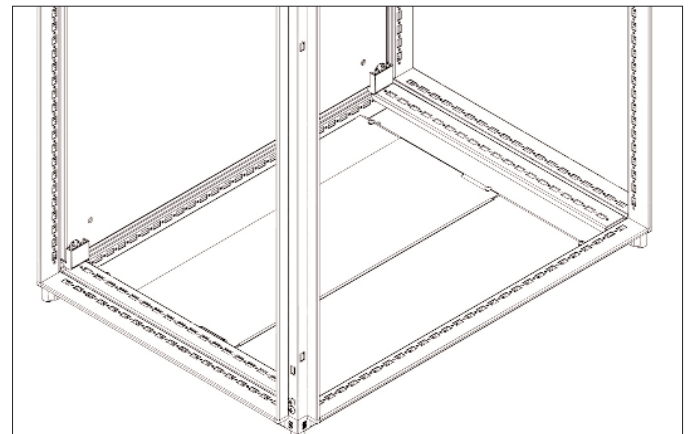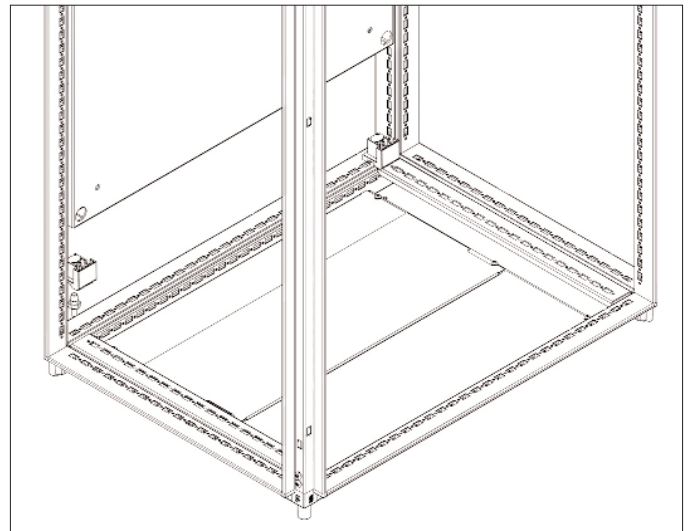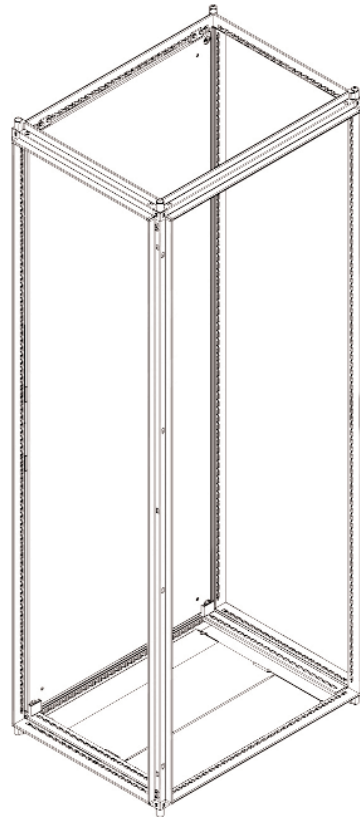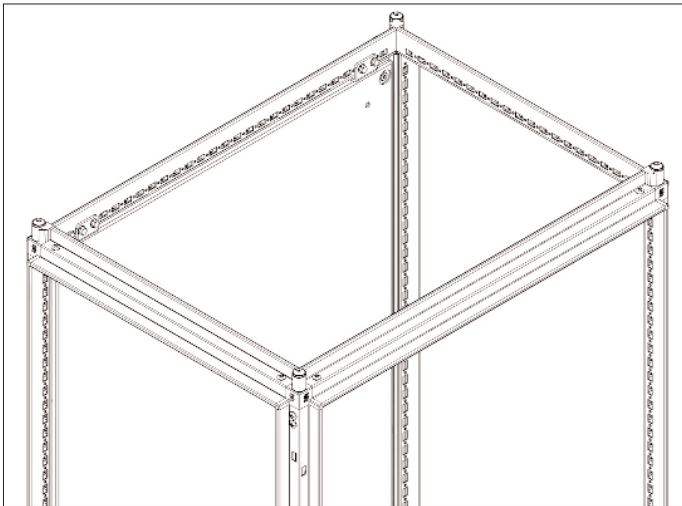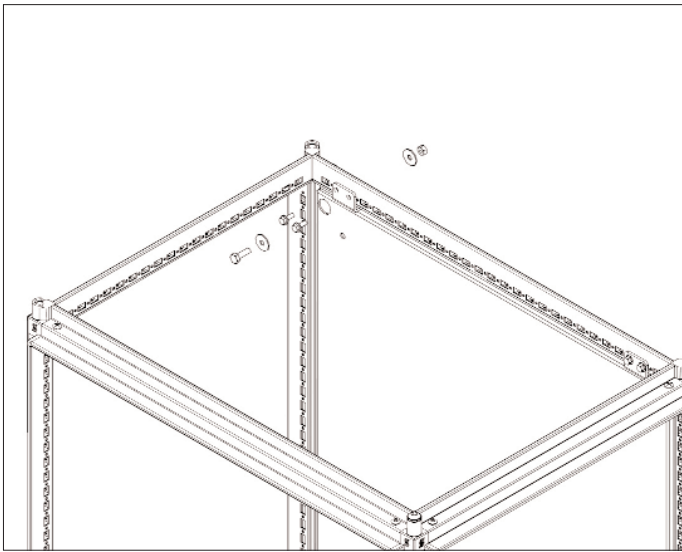


**OK K - FRONT DOOR 180°**  
**Porta anteriore 180°**





**Hinge**

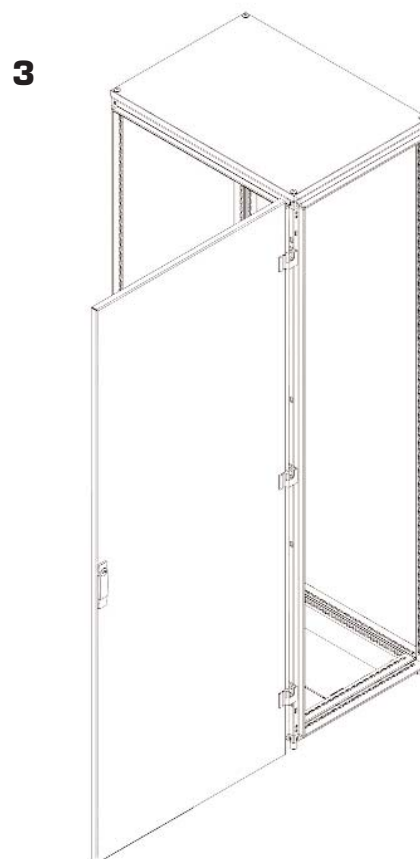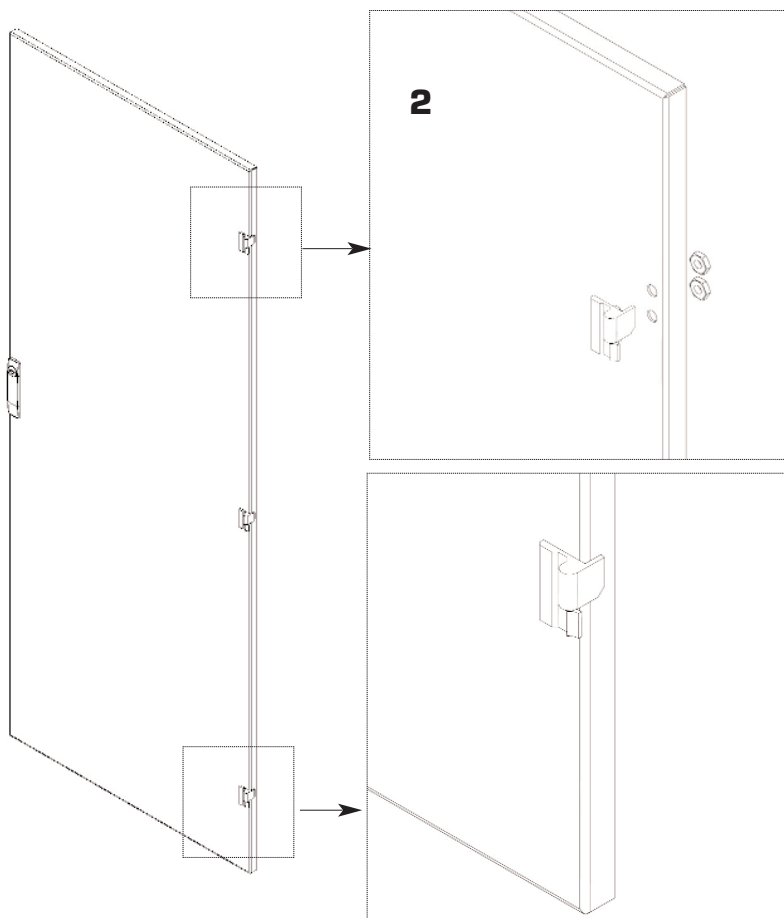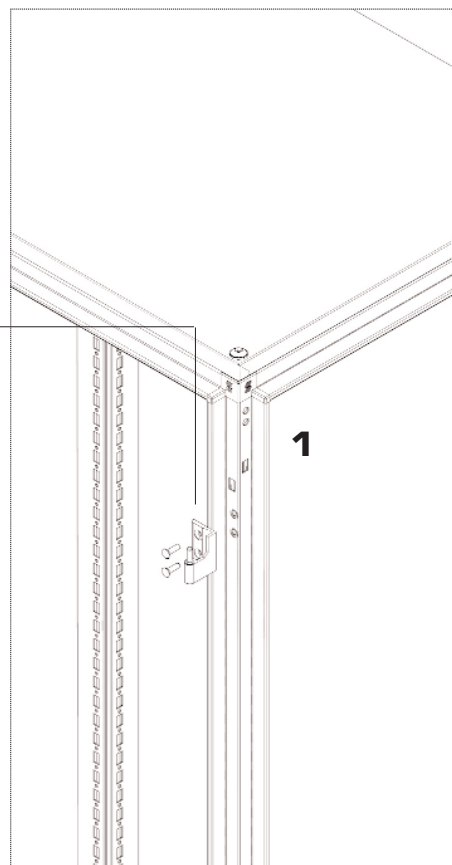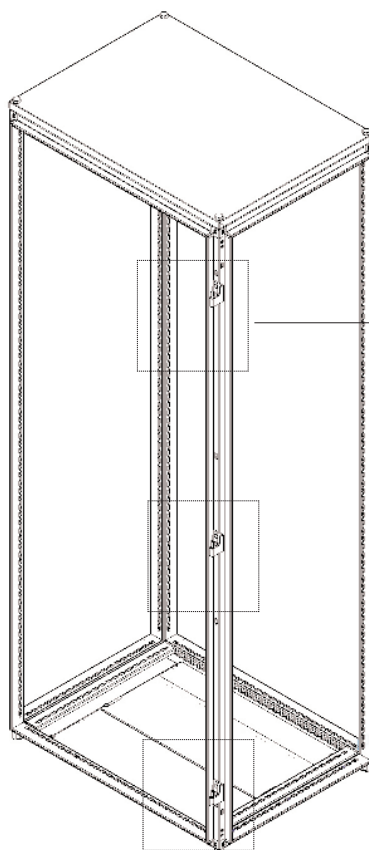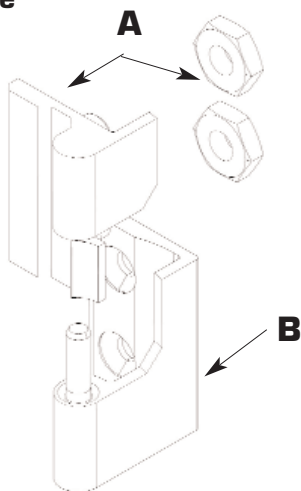



**Cerniera**  
**Hinge**

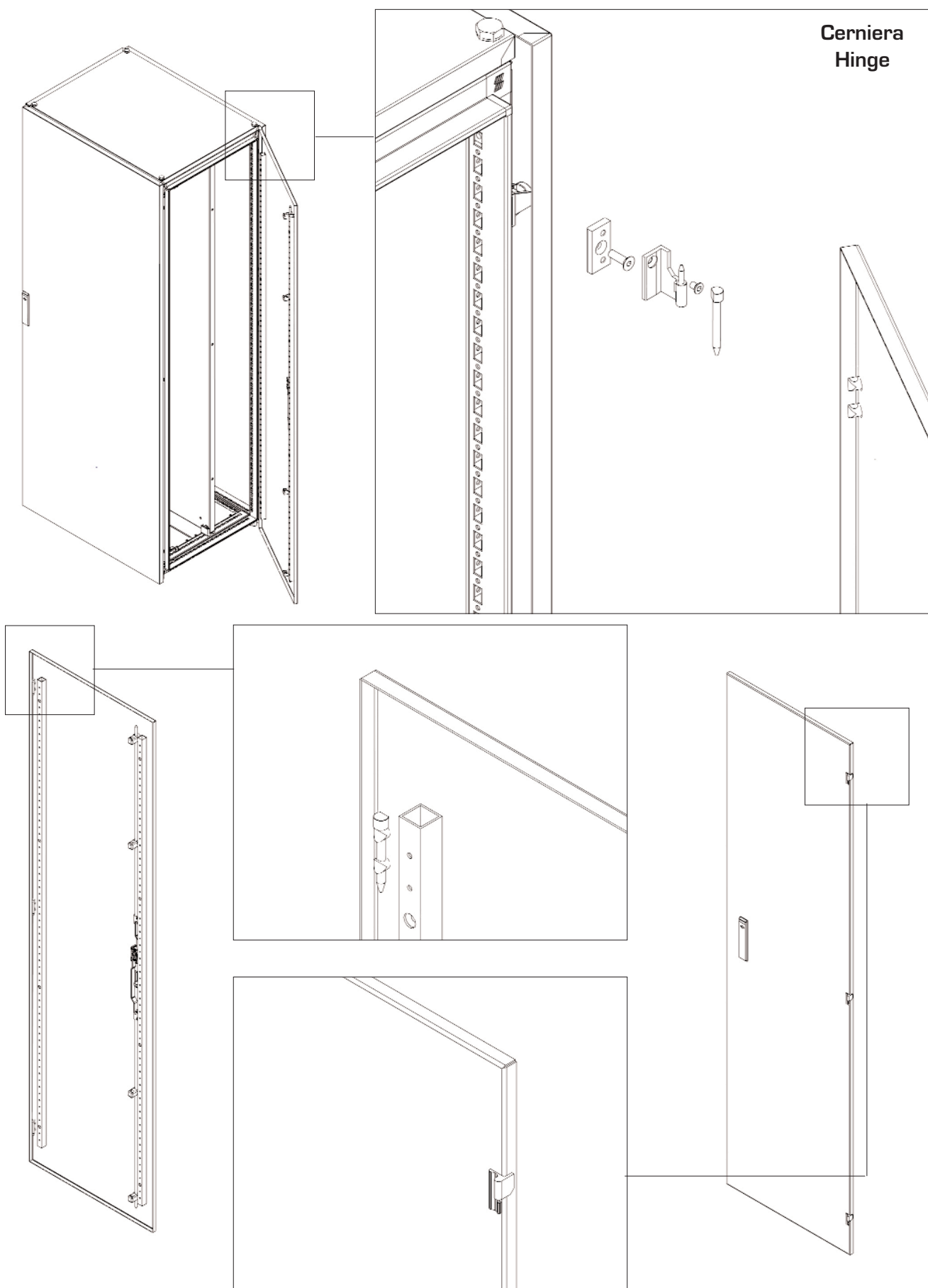

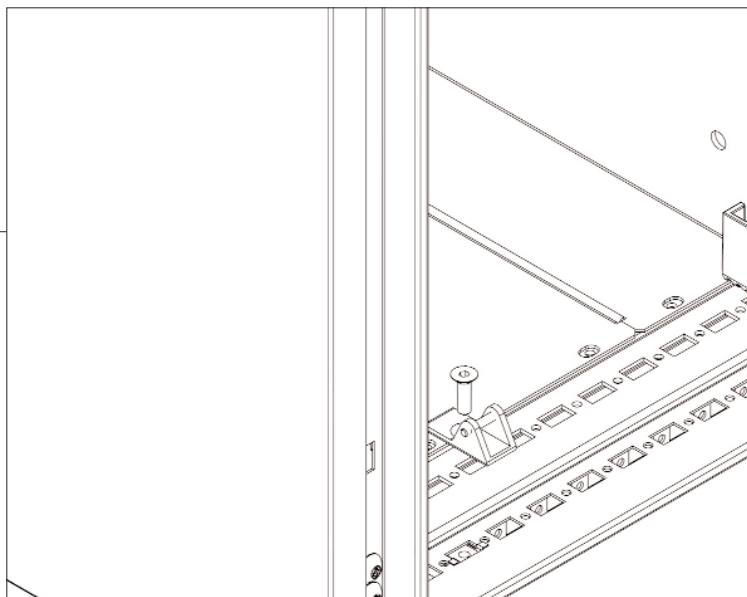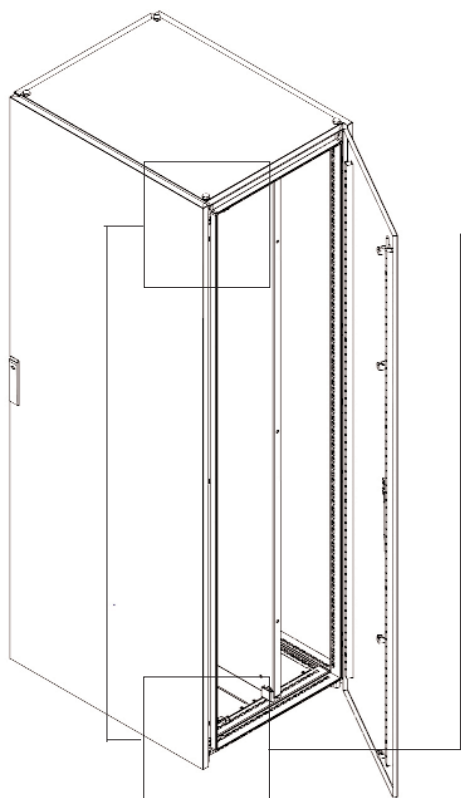


1. Adattatore - *Adaptor*
2. Vite - *Srew*
3. Cerniera fissa - *Fix Hinge*
4. Vite - *Screw*
5. Perno - *Pin*
6. Cerniera mobile - *Removable Hinge*






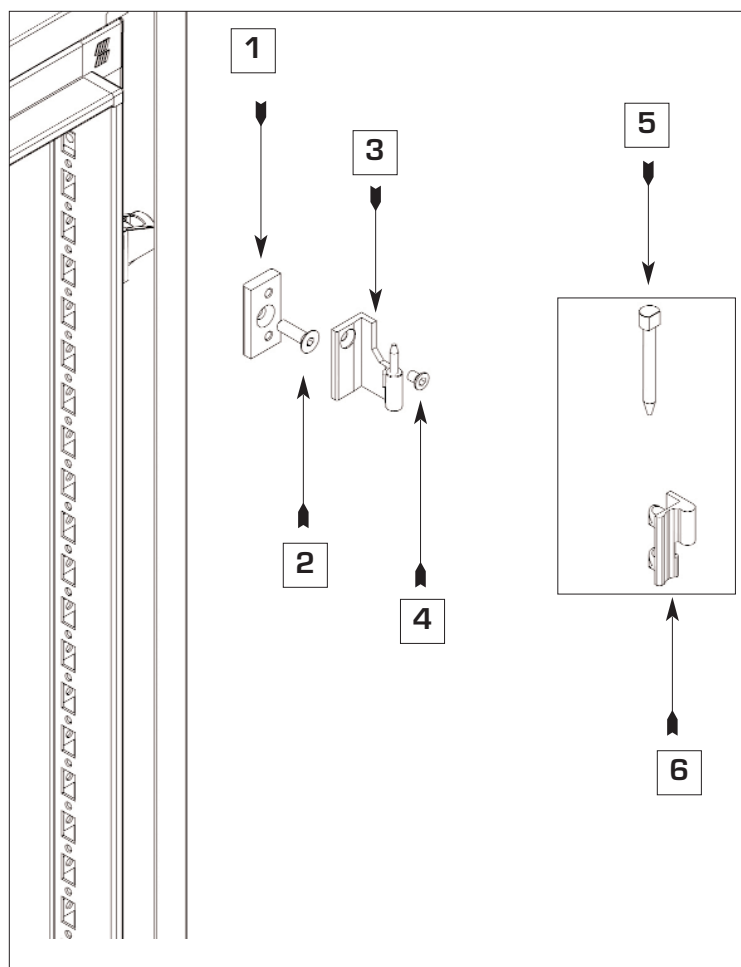


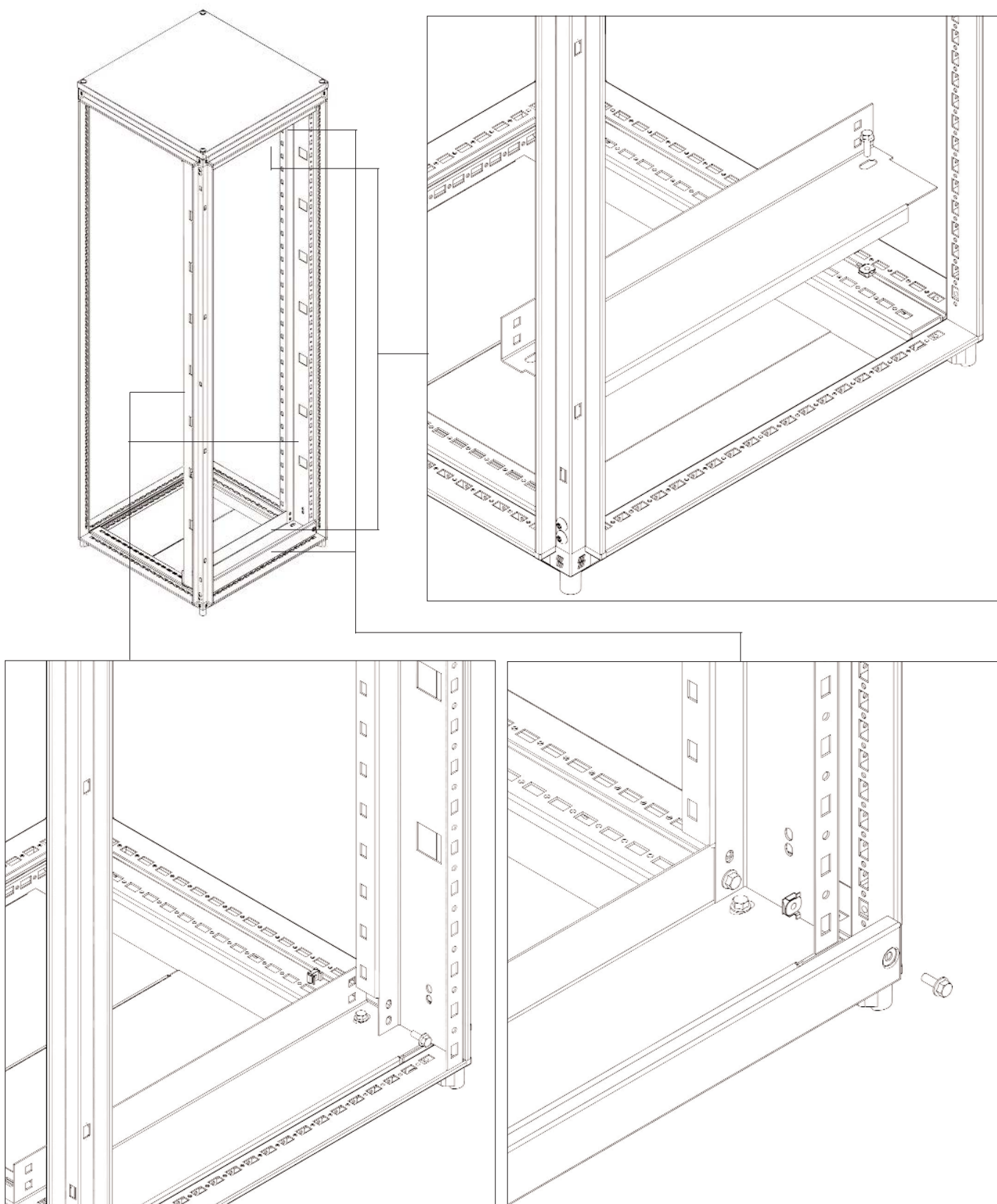












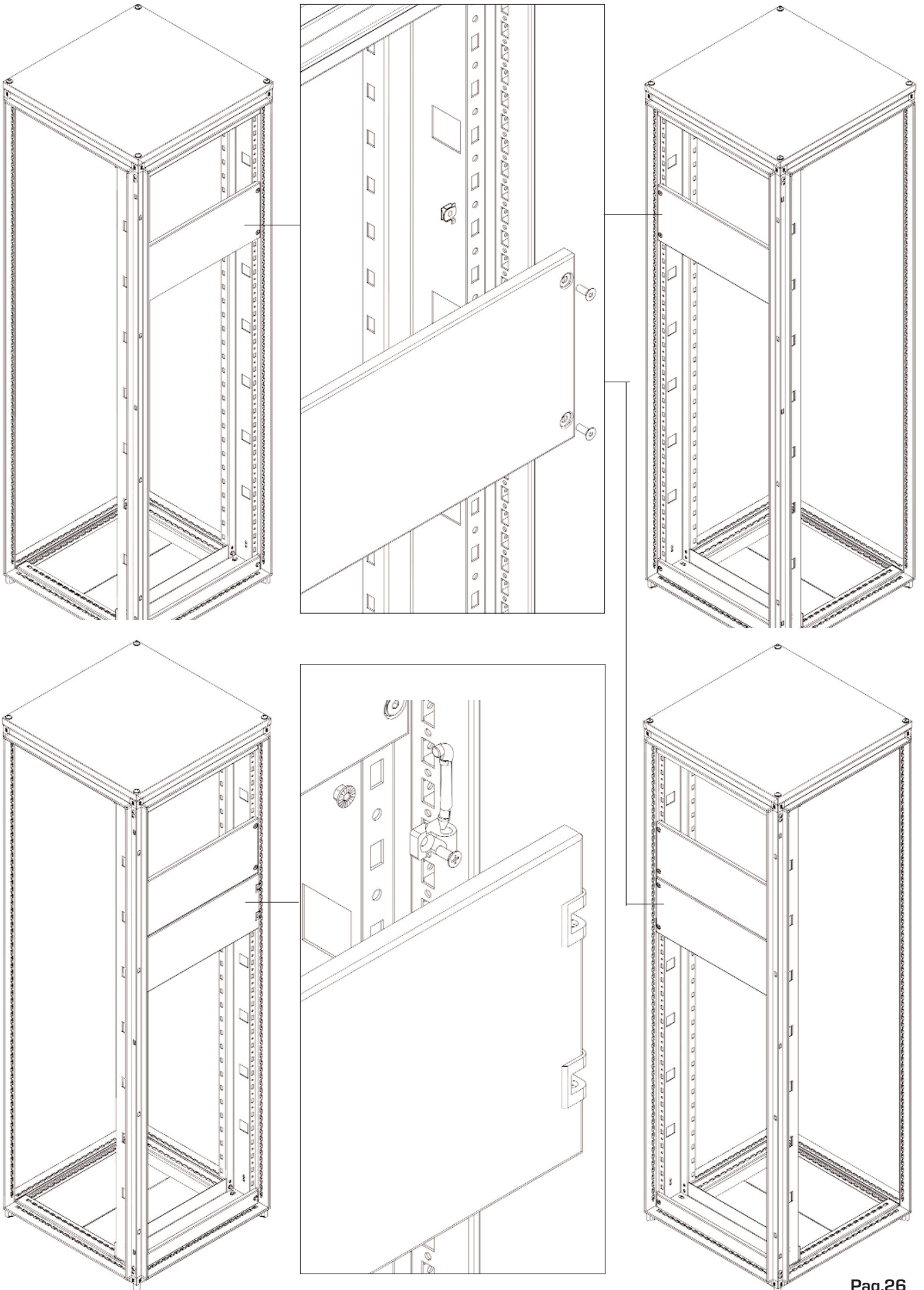




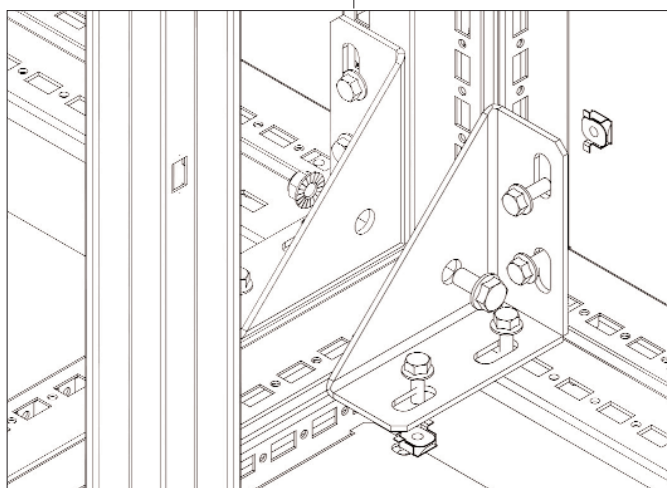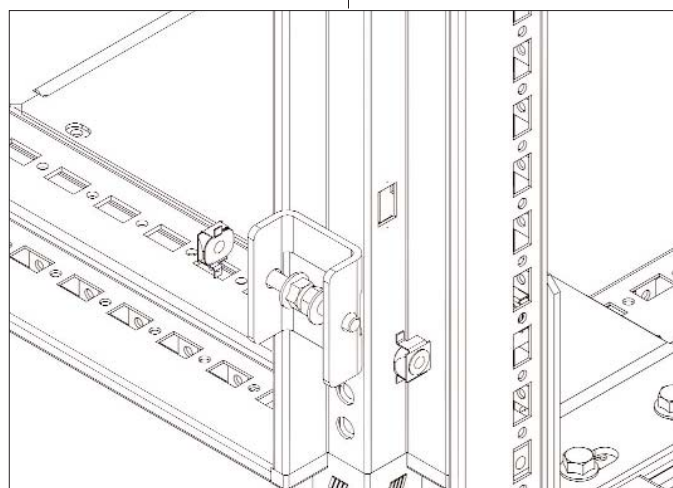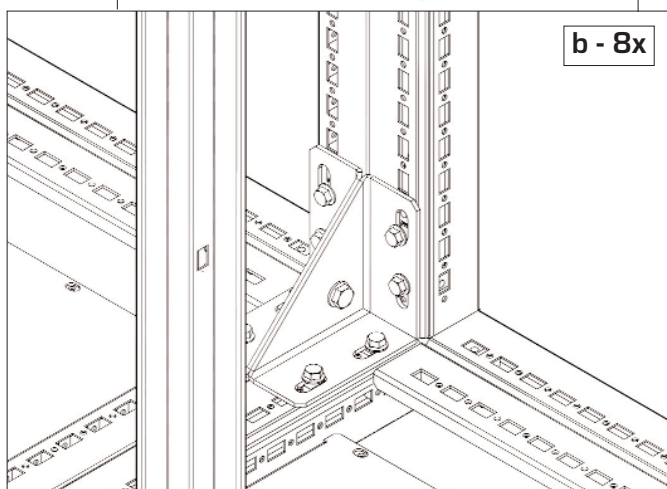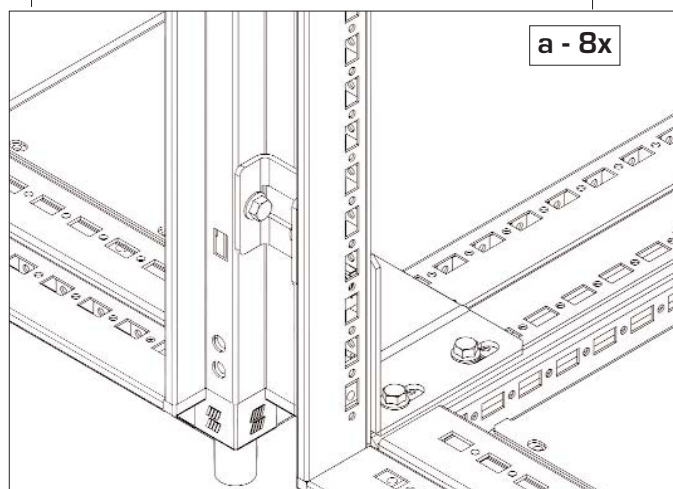
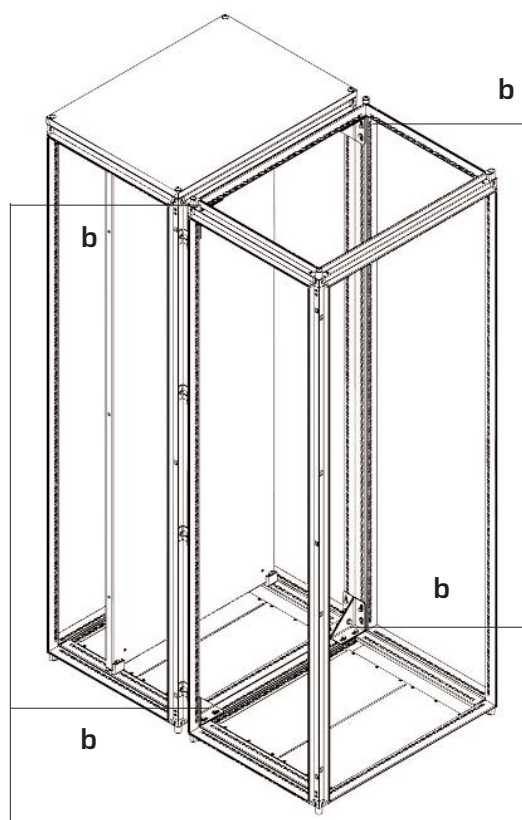
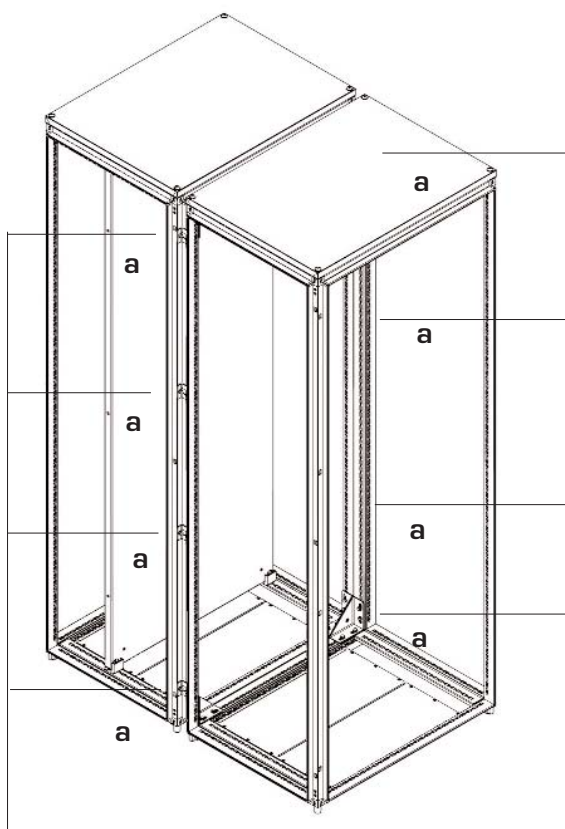


**OK** - **BCO110** FERMOPORTA MECCANICO  
Mechanical Door Block


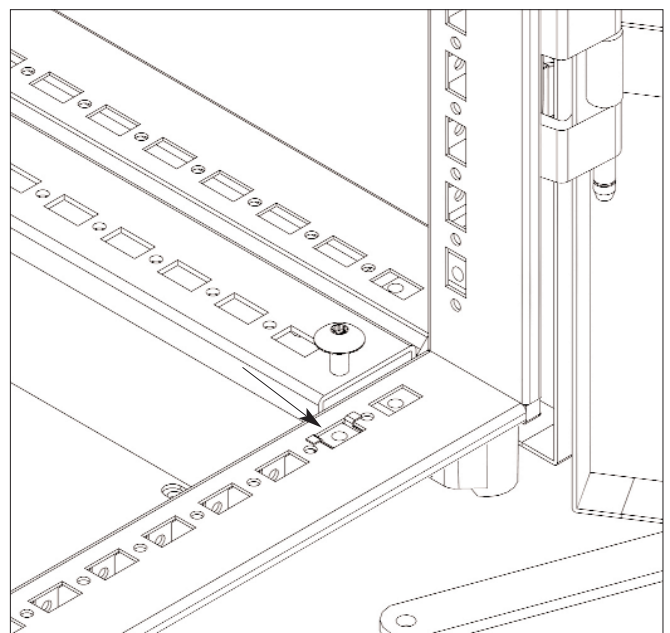
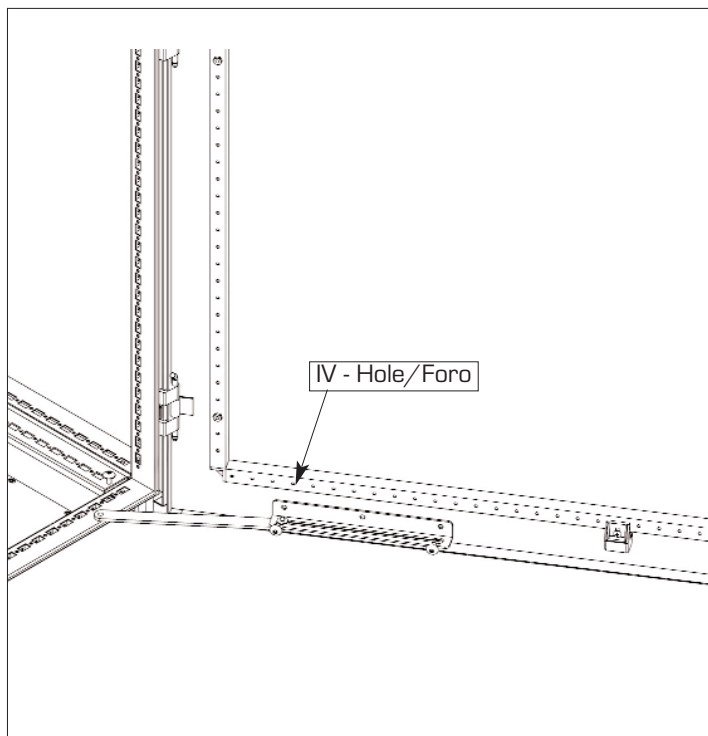
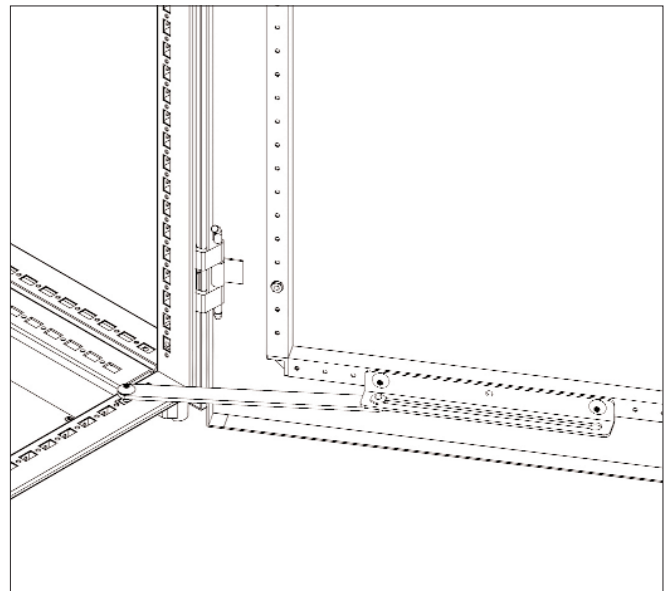
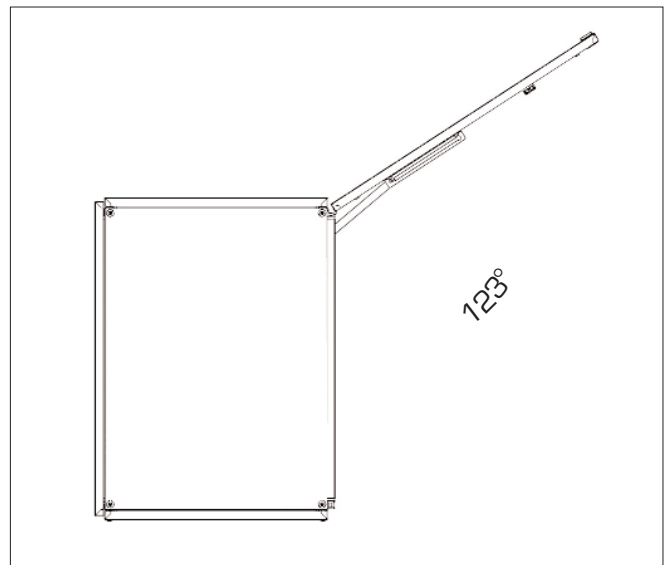
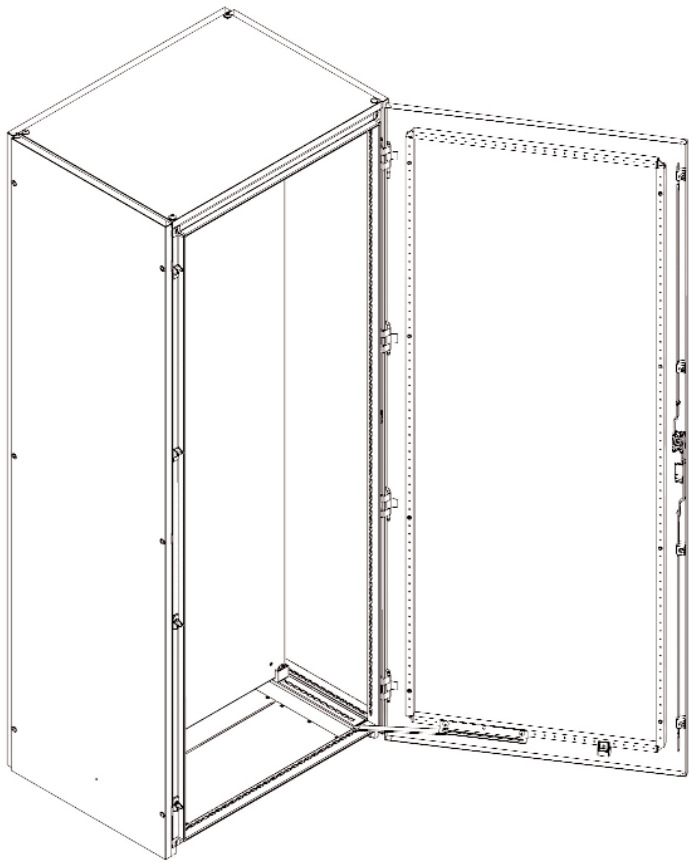


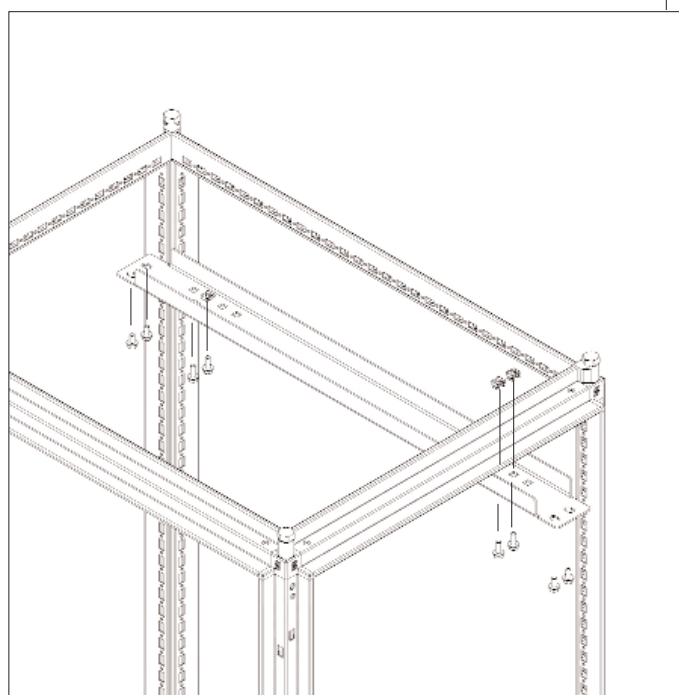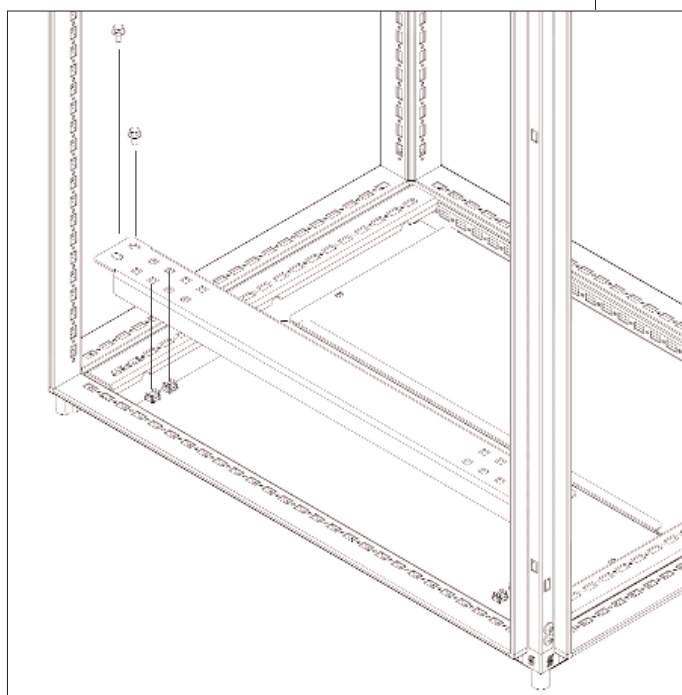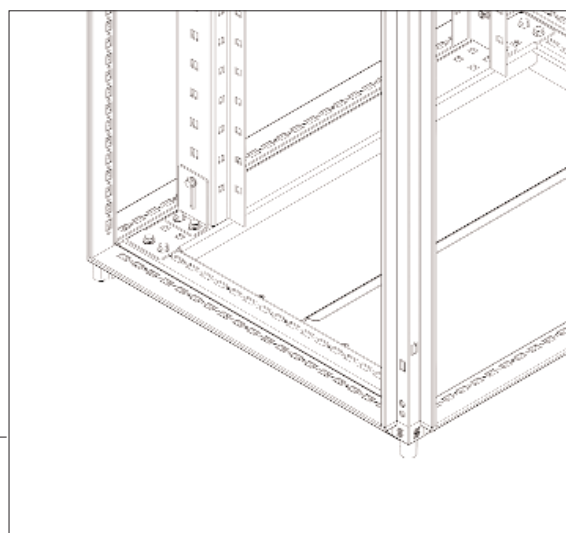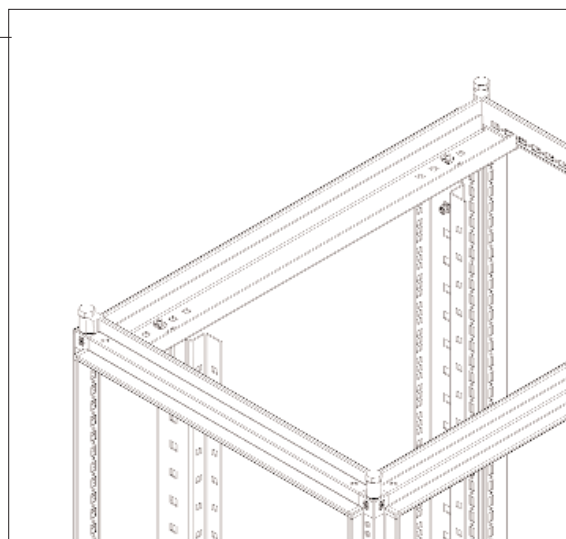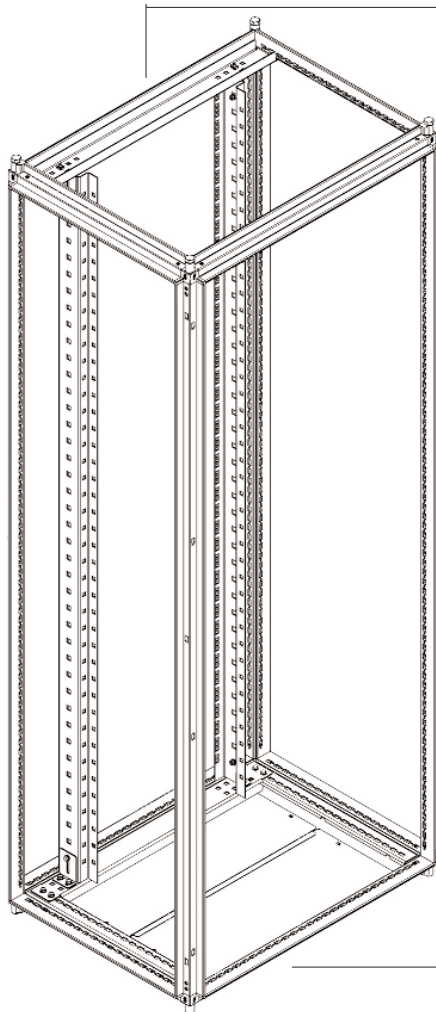





**OK** COPPIA MONTANTI RACK VERTICALI FISSI  
FIXED RACK VERTICAL STRUT PAIR

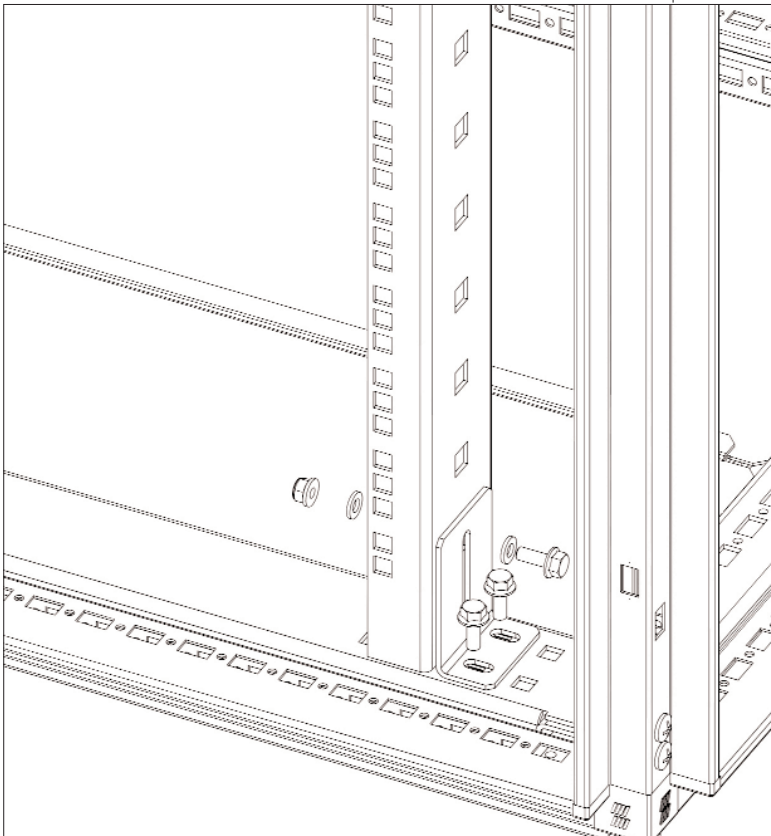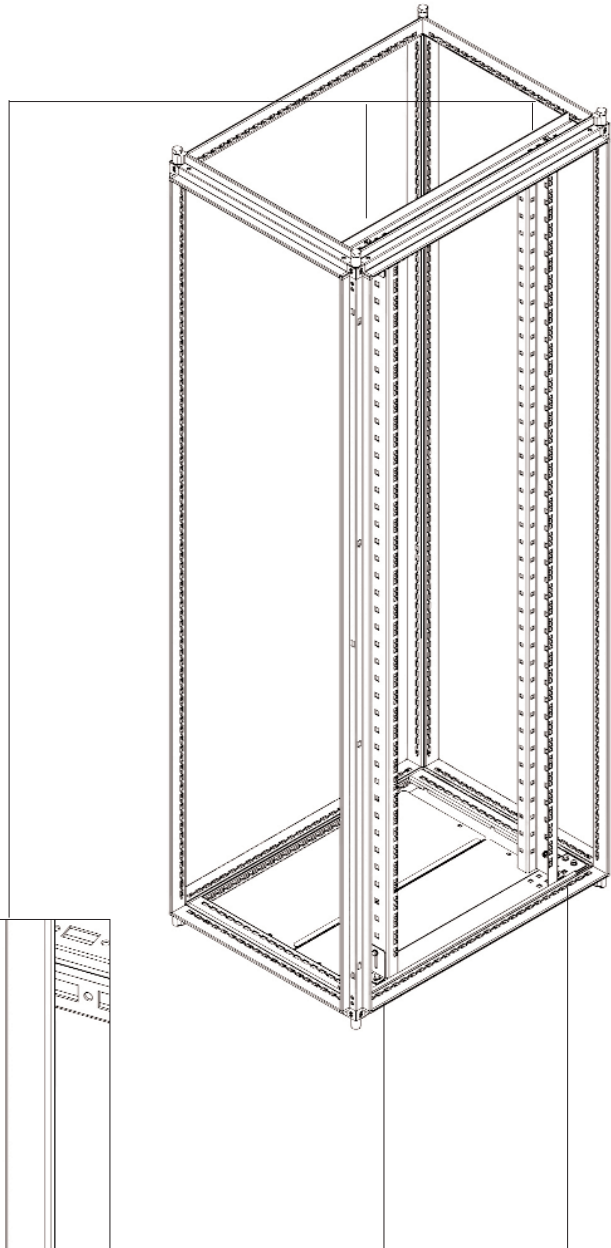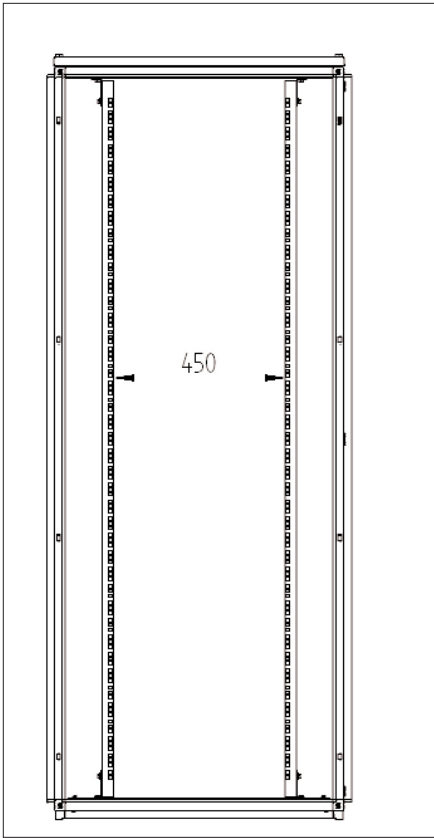



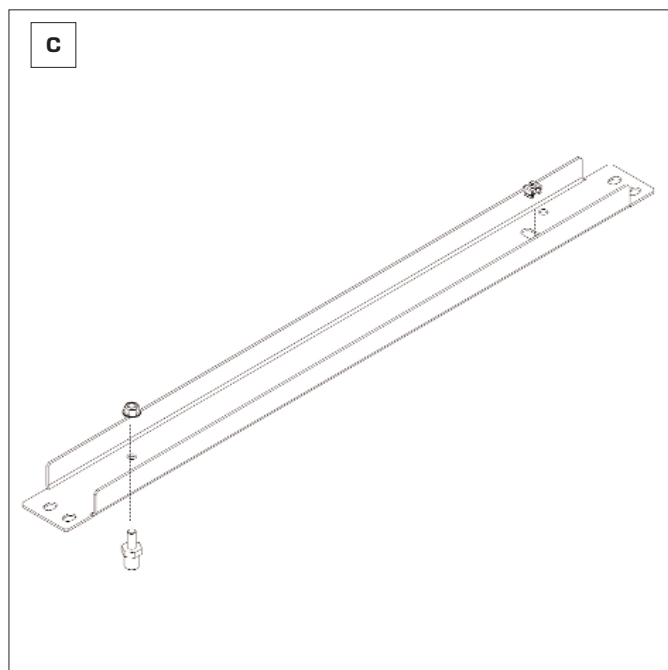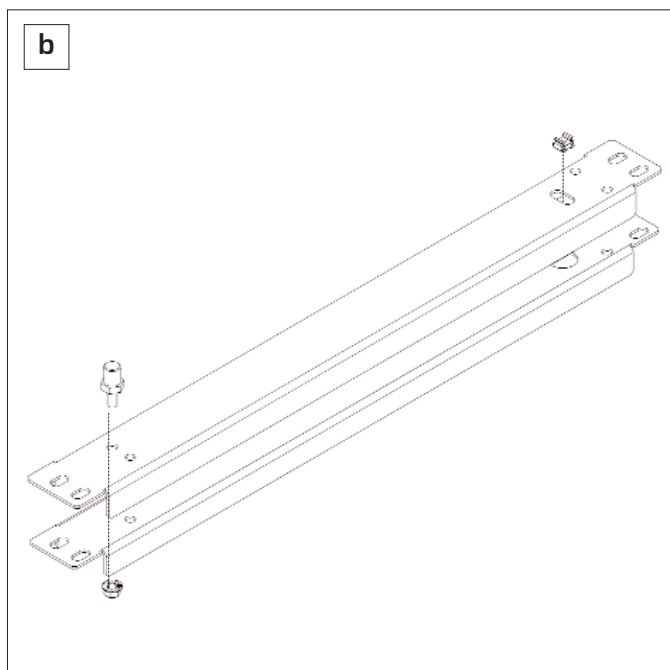
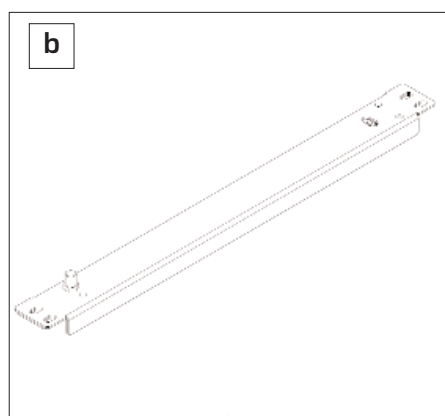
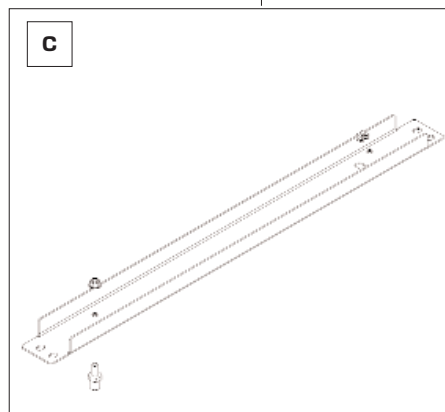
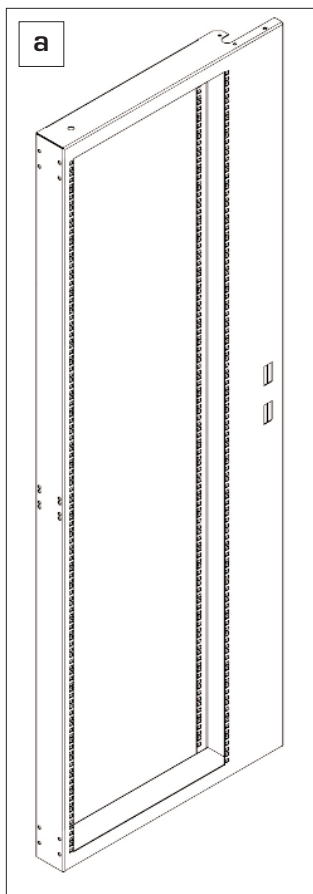
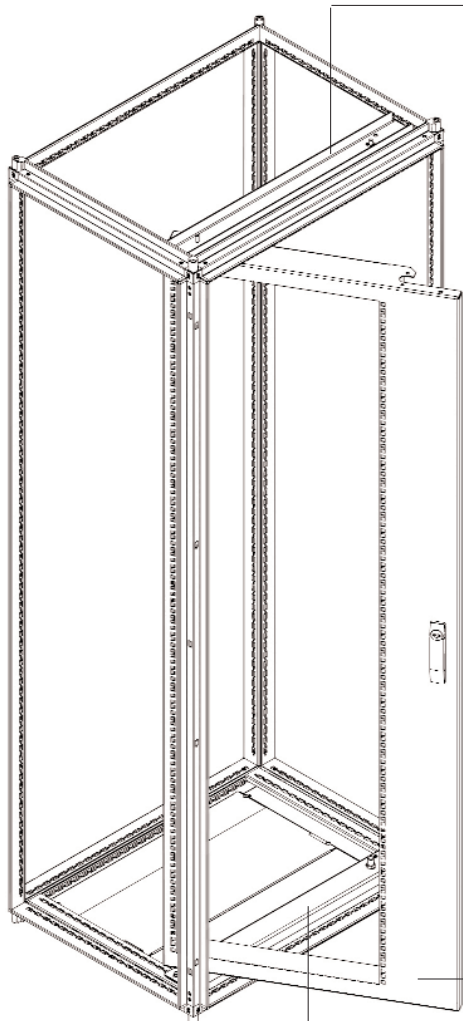


**OK** RACK INTERNO GIREVOLE 19" STANDARD  
19" INTERNAL SWIVEL RACK FRAME

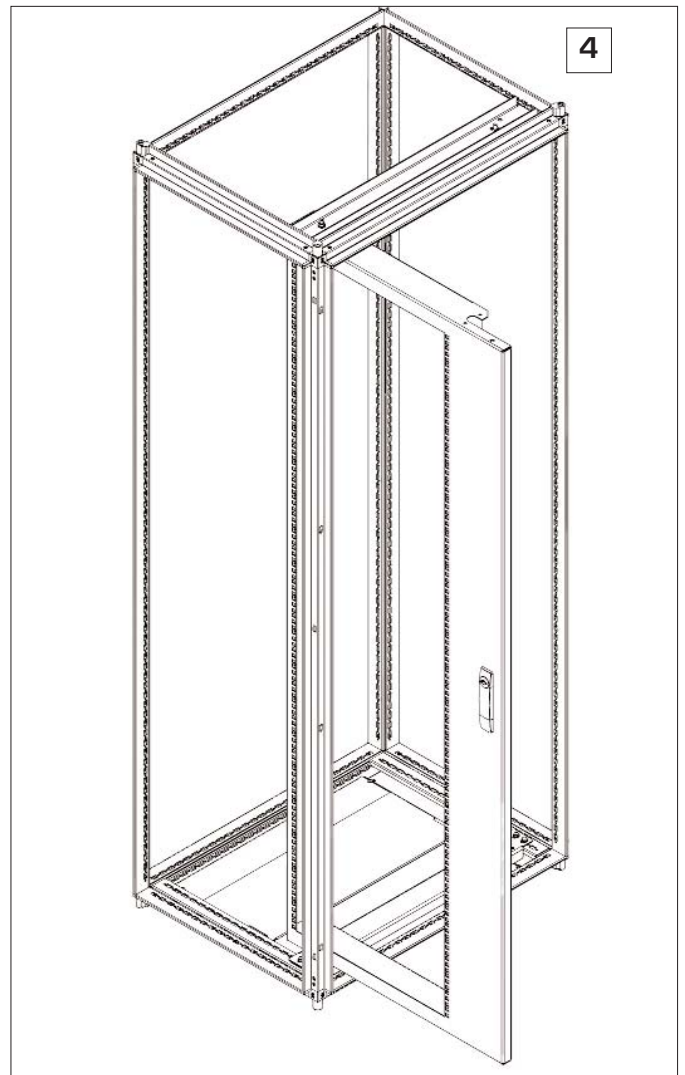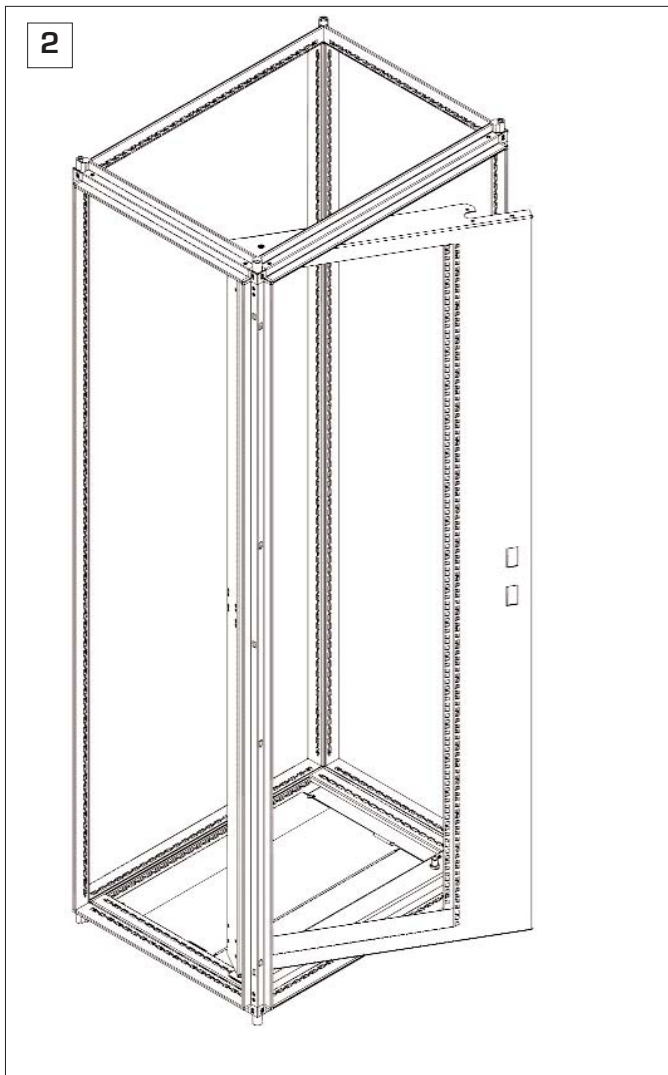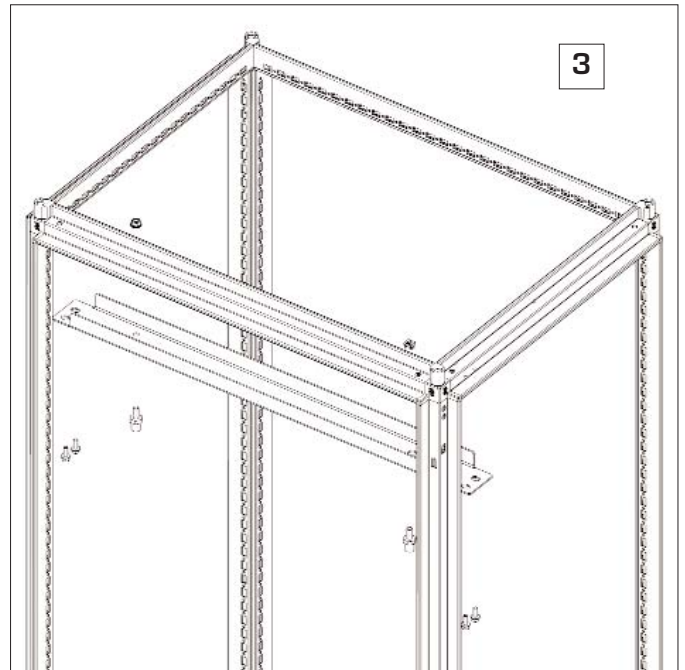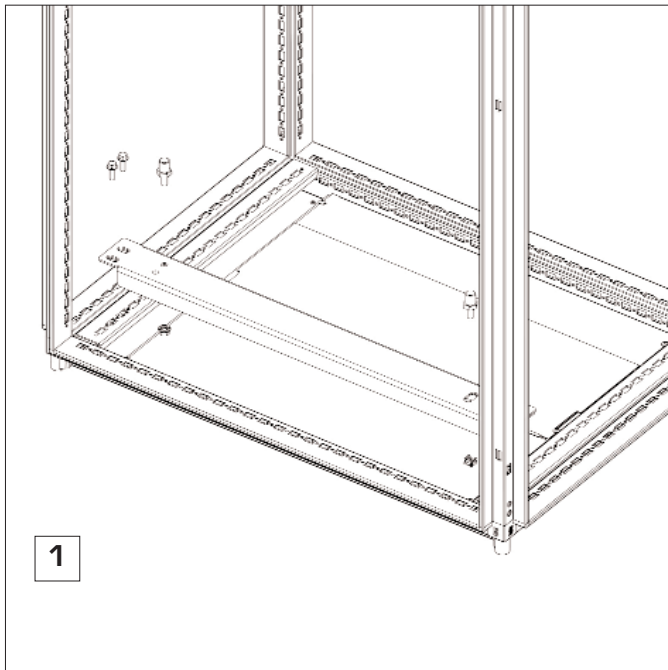




Due cerniere 180° - Two hinge 180°

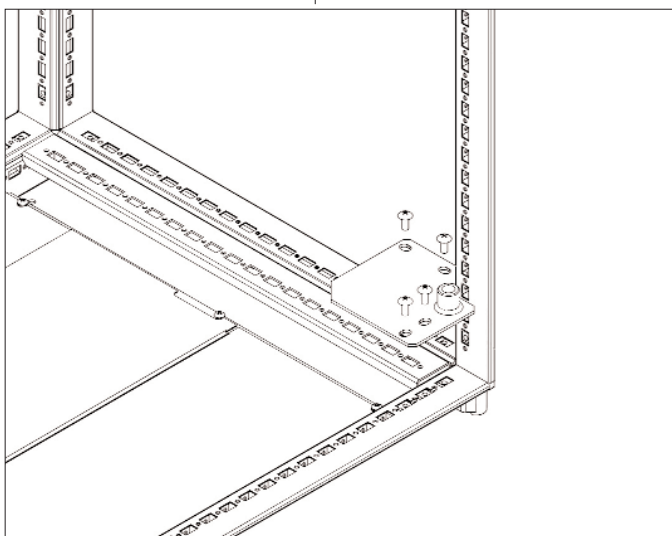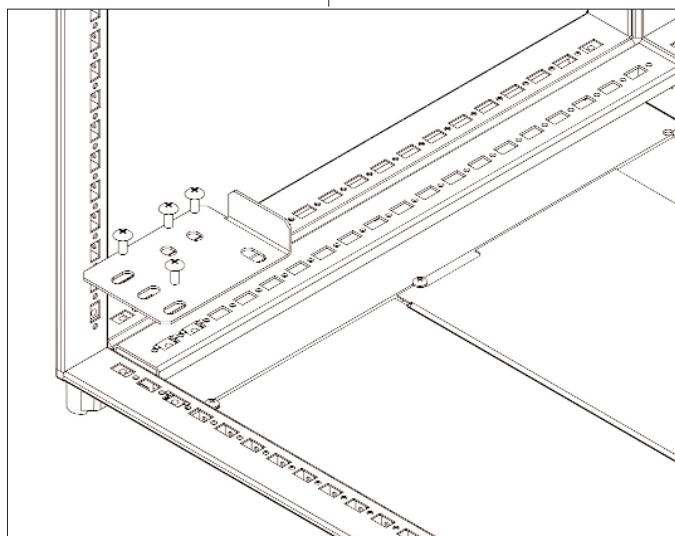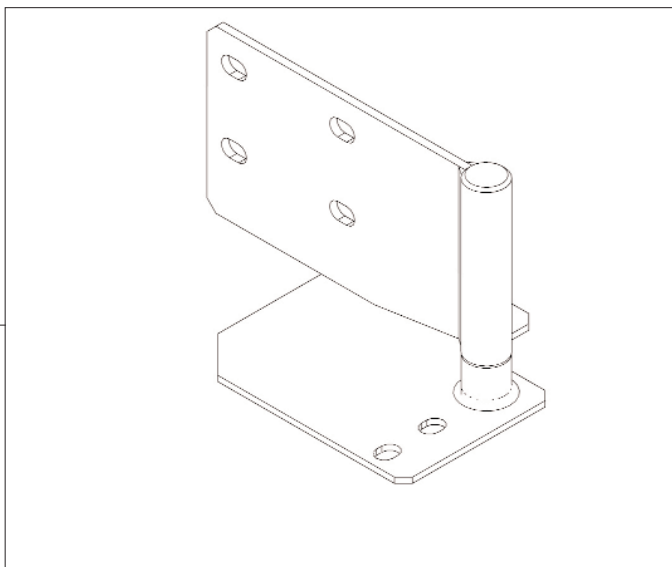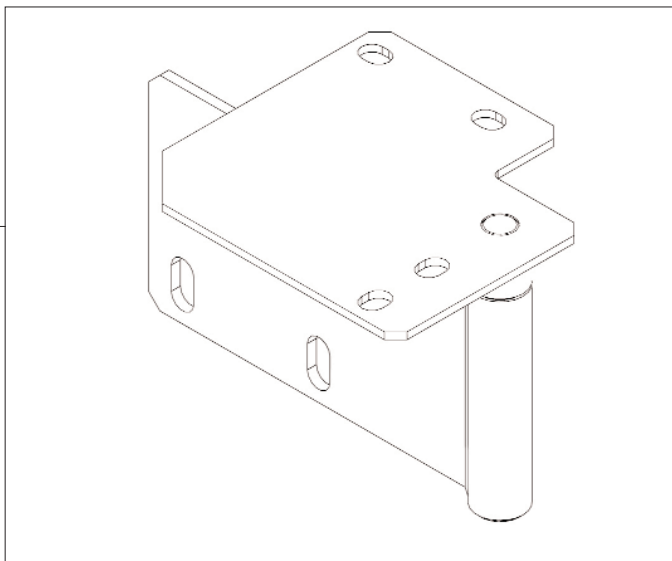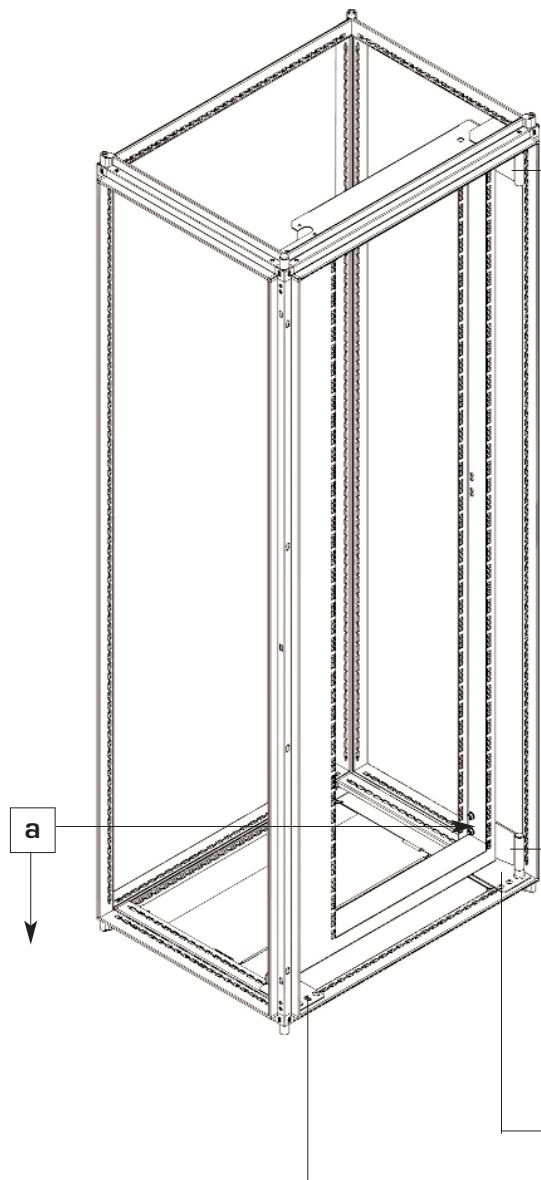

**OK RACK INTERNO GIREVOLE 19" CERNIERE 180°**  
**19" INTERNAL SWIVEL RACK FRAME Hinge 180°**

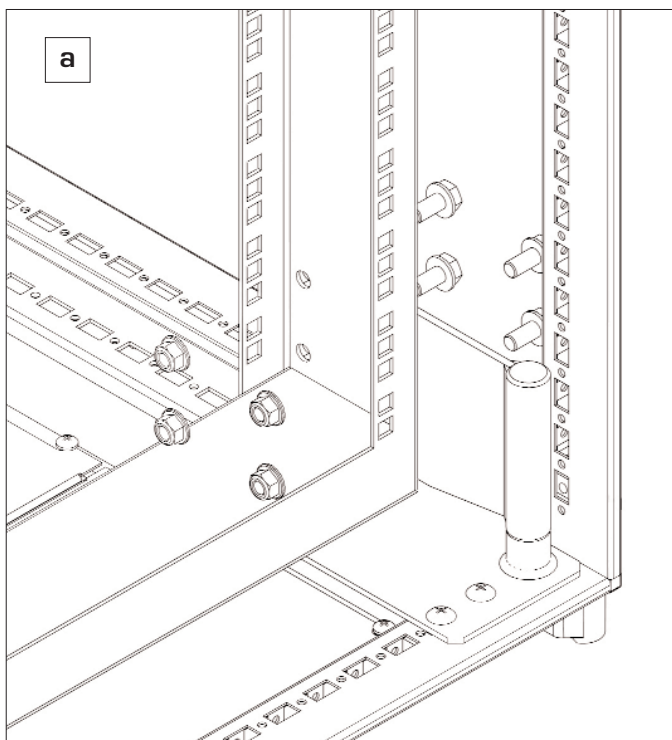

**Tre cerniere 180° - Three hinge 180°**

