


MONTAGGIO BRACCETTI "MAL2P TRX / TRX V / TRX G / TRX VG" "MAL2P TRX / TRX V / TRX G / TRX VG" ARMS MOUNTING

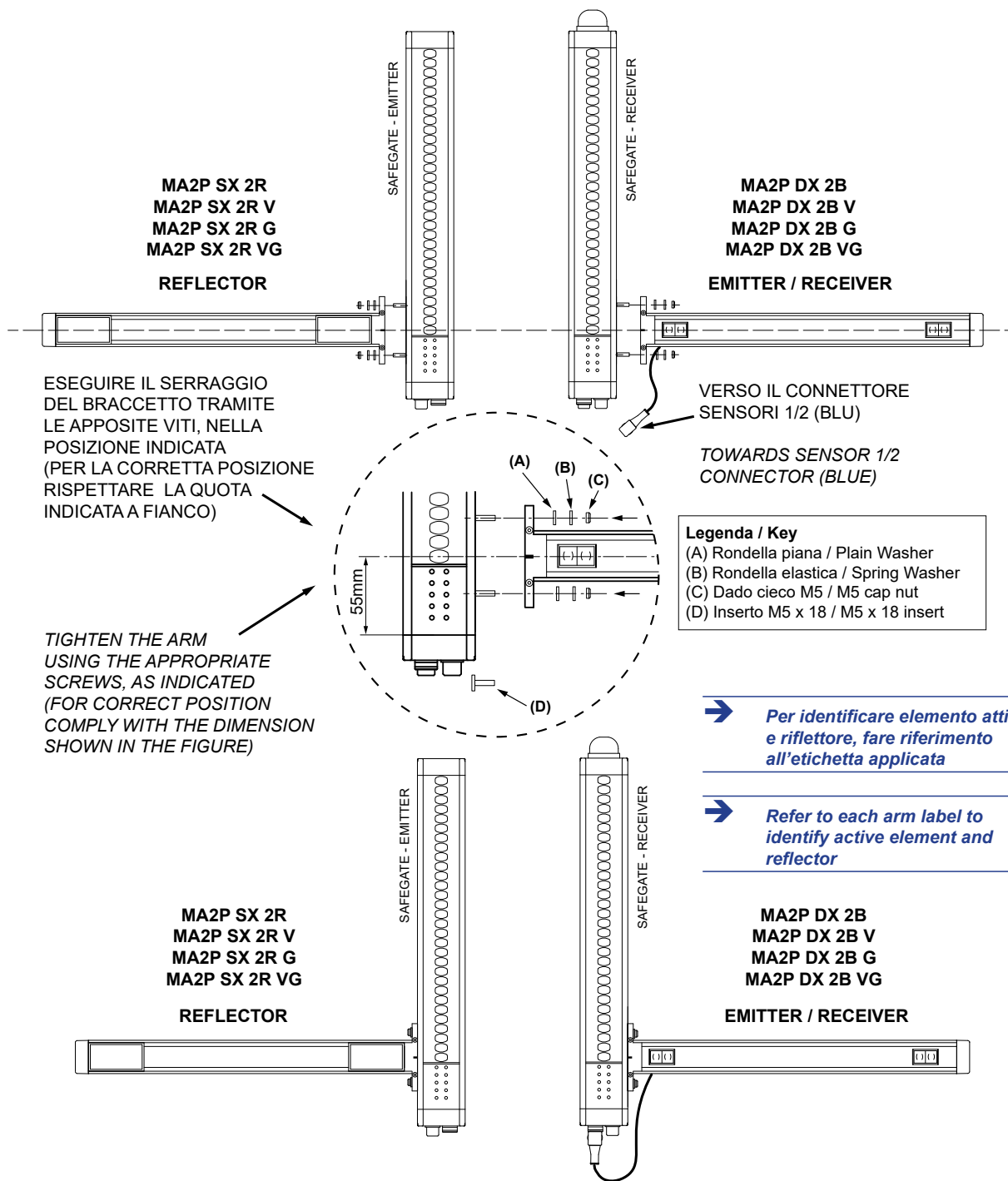

CARATTERISTICHE TECNICHE - TECHNICAL FEATURES

Portata utile / Working range	m	0...3,5 (MAL2P TRX, MAL2P TRX V) / 0...2 (MAL2P TRX G, MAL2P TRX VG)
Uscite / Outputs		PNP - 100mA - @ 24VDC
Consumo max / Power consumption	W	2
Sensori optoelettronici integrati / Opto-electronic integrated sensors		2 sensori paralleli attivi, con riflettore 2 parallel active sensors, with reflector
Temperatura di funzionamento / Working temperature	°C	-30...55
Grado di protezione / IP rating		IP65 / IP67
Lunghezza / Length	mm	360 (MAL2P TRX, MAL2P TRX G) - 430 (MAL2P TRX V, MAL2P TRX VG)
Sezione / Section	mm	35 X 45