

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



Home > Vacuum Technology for Automation > Vacuum Components > Mounting Elements > Spring Plungers > Spring Plungers FSTE > FSTE G1/8-AG 25

Spring plunger with damping and height compensation




Suction cup connection: G1/8"-M

Vacuum connection: G1/8"-F

Spring stroke Z: 25 mm

Design Data

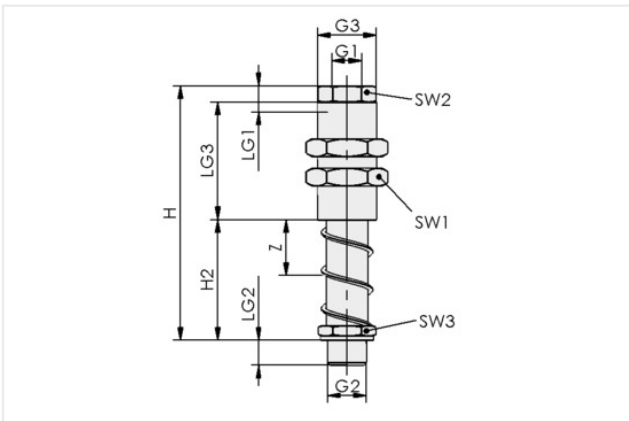

Attribute	Value
G1	G1/8"-F
G2	G1/8"-M
G3	M16x1-M
H	86.50 mm
H2	42.50 mm
LG1	8 mm
LG2	6.50 mm
LG3	30 mm
SW1	22 mm
SW2	12 mm
SW3	14 mm
Z (Stroke)	25 mm

Technical Data

Attribute	Value
Spring rate	0.14 N/mm
Spring pretension	3.57 N
Spring force, center	5.36 N
Vertical load	3700 N
Horizontal load	283 N
Weight	90 g

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603

Operating temperature

0 ... 80 °C

Product family

FSTE

Accessories



KGL G1/8-IG G1/8-AG A2

Part no...:10.01.03.00109

Thread G1: G1/8"-F

Thread G2: G1/8"-M

Height H: 26.5 mm

Material: Aust. Stainless steel



HTR-STA 47 1N D10/16 FL

Part no...:10.08.03.00085

Length L: 47 mm

Connection 1: Sliding block


Connection of suction cup, spring plunger: Contour D10 and D16

Shape: flat

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603

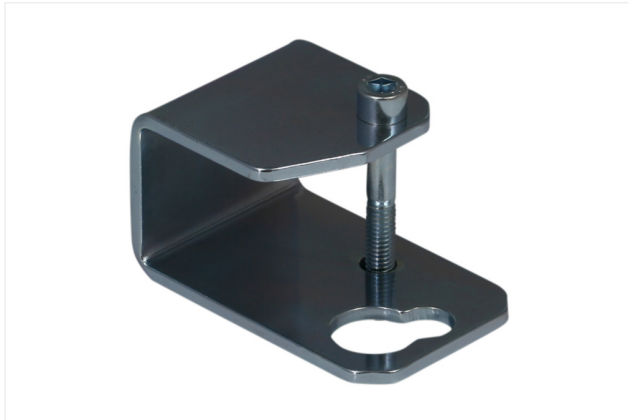

HTR-ST5 30x30 D10/16 WI

Part no...:10.08.03.00088

Connection 1: 30x30

Connection of suction cup, spring plunger: Contour D10 and D16

Shape: angled



HTR-ST5 40x40 D10/16 WI

Part no...:10.08.03.00089

Connection 1: 40x40

Connection of suction cup, spring plunger: Contour D10 and D16

Shape: angled



ST G1/8-AG 4 MS-V

Part no...:10.08.03.00153

Thread G1: G1/8"-M

Hose diameter (empf.) d: 4 mm

Material: Brass

Surface: nickel plated

Length L: 5 mm

Nominal diameter dn: 3.5 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



ST G1/8-AG 6 MS-V

Part no...:10.08.03.00154

Thread G1: G1/8"-M

Hose diameter (empf.) d: 6 mm

Material: Brass

Surface: nickel plated

Length L: 5 mm

Nominal diameter dn: 4.4 mm



ST G1/8-AG 9 MS-V

Part no...:10.08.03.00155

Thread G1: G1/8"-M

Hose diameter (empf.) d: 9 mm

Material: Brass

Surface: nickel plated

Length L: 5 mm

Nominal diameter dn: 4 mm



STV-GE G1/8-AG 4

Part no...:10.08.02.00202

Thread G1: G1/8"-M

Hose diameter: 4 mm

Material: Brass

Operating temperature: -20 ... 80 °C

External diameter D: 7.9 mm

Length L: 13.7 mm

Spring plunger

FSTE G1/8-AG 25

Part no.:10.01.02.00603



STV-GE G1/8-AG 6

Part no.:10.08.02.00204

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Brass

Operating temperature: -20 ... 80 °C

External diameter D: 11.4 mm

Length L: 16.4 mm



STV-GE G1/8-AG 8

Part no.:10.08.02.00206

Thread G1: G1/8"-M

Hose diameter: 8 mm

Material: Brass

Operating temperature: °C

External diameter D: 14 mm

Length L: 20.7 mm



STV-W G1/8-AG 4

Part no.:10.08.02.00156

Thread G1: G1/8"-M

Hose diameter: 4 mm

Material: Nickel plated

Operating temperature: -20 ... 80 °C

Length L: 16.4 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



STV-W G1/8-AG 6

Part no...:10.08.02.00158

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Nickel plated

Operating temperature: -20 ... 80 °C

Length L: 20.1 mm



STV-W G1/8-AG 8

Part no...:10.08.02.00160

Thread G1: G1/8"-M

Hose diameter: 8 mm

Material: Nickel plated

Operating temperature: -20 ... 80 °C

Length L: 24 mm



STV-GE G1/8-AG 6 HT

Part no...:10.08.02.00389

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Brass

Operating temperature: -20 ... 120 °C

External diameter D: 11.6 mm

Length L: 19 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



STV-W G1/8-AG 6

Part no...:10.08.02.00288

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Plastic

Operating temperature: °C

Length L: 20.8 mm



STV-W G1/8-AG 6 HT

Part no...:10.08.02.00391

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Brass

Operating temperature: -50 ... 200 °C

Length L: 22.5 mm



STV-WF G1/8-AG 4

Part no...:10.08.02.00166

Thread G1: G1/8"-M

Hose diameter: 4 mm

Material: Nickel plated

Operating temperature: -10 ... 70 °C

Length L: 17.4 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



STV-WF G1/8-AG 6

Part no...:10.08.02.00168

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Nickel plated

Operating temperature: -10 ... 70 °C

Length L: 21.4 mm



STV-WF G1/8-AG 8

Part no...:10.08.02.00170

Thread G1: G1/8"-M

Hose diameter: 8 mm

Material: Nickel plated

Operating temperature: -10 ... 70 °C

Length L: 23.4 mm



STV-WF G1/8-AG 10

Part no...:10.08.02.00257

Thread G1: G1/8"-M

Hose diameter: 10 mm

Material: Nickel plated

Operating temperature: -10 ... 70 °C

Length L: 25.2 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603



STV-T G1/8-AG 4

Part no...:10.09.02.00039

Thread G1: G1/8"-M

Hose diameter: 4 mm

Material: Brass

Operating temperature: °C

Length L: 32.5 mm



STV-T G1/8-AG 6

Part no...:10.09.02.00040

Thread G1: G1/8"-M

Hose diameter: 6 mm

Material: Brass

Operating temperature: °C

Length L: 41.5 mm



STV-T G1/8-AG 8

Part no...:10.09.02.00041

Thread G1: G1/8"-M

Hose diameter: 8 mm

Material: Brass

Operating temperature: °C


Length L: 48.7 mm

Spring plunger

FSTE G1/8-AG 25

Part no...:10.01.02.00603

Spare parts

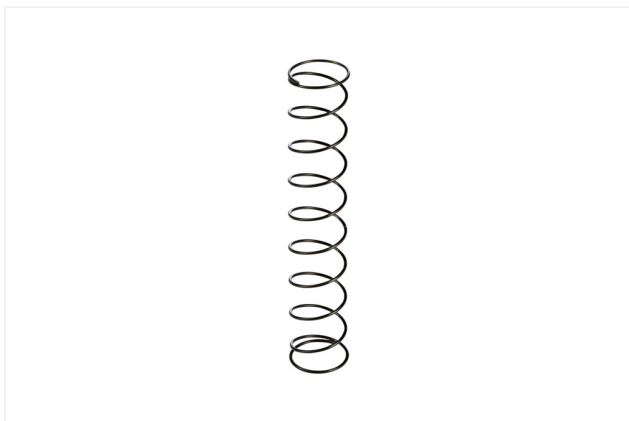

DRUCK-FED 0.63x10.97 62 0.143

Part no...:20.08.02.00092

Length L: 62 mm

Spring rate: 0.143 N/mm