

Bellows suction cup (round)

SPB1 20 ED-65 SC040

Part no...:10.01.06.02452

Home > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Packaging > SPB1 20 ED-65 SC040

Bellows suction cup (round) with 1.5 corr. for dynamic handling of cardboard and rigid packaging




Size: 20

Suction cup material: Elastodur

Material hardness [Shore A]: 65 Shore A

Number of folds: 1.5

Design Data

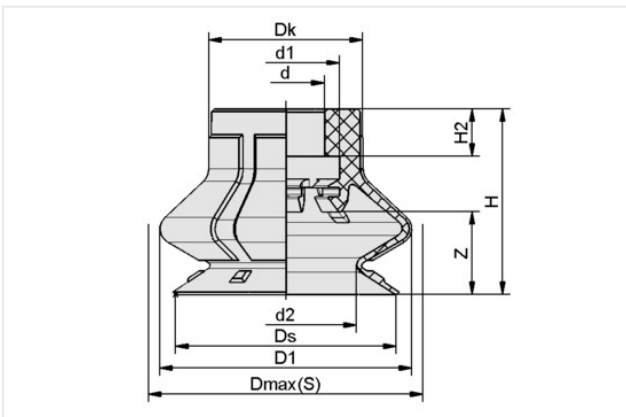

Attribute	Value
d	7.50 mm
d1	10.50 mm
d2	13.80 mm
D1	24.60 mm
Dk	15.10 mm
Dmax(S)	26.30 mm
Ds	21.40 mm
H	18 mm
H2	4.60 mm
Z (Stroke)	8 mm

Technical Data

Attribute	Value
Suction force (-600mbar)	9.90 N
Pull-off force	16.20 N
Lateral force	9.80 N
Volume	3.11 cm ³
Curve radius (min) (convex)	15 mm
Hose diameter (empf.) d	4 mm
Size	20
Nipple family	SC 040

Bellows suction cup (round)

SPB1 20 ED-65 SC040

Part no...:10.01.06.02452

Number of folds	1.50
Suction cup material	Elastodur
Material hardness [Shore A]	65 Shore A
Weight	2.20 g
Product family	SPB1

Accessories



SC 040 G1/8-AG

Part no...:10.01.06.02490

Connection geometry: 40

Connection: G1/8"-M

Length L1: 20.2 mm

Fitting length: 6 mm

Nominal diameter dn: 4.1 mm



SC 040 G1/8-IG

Part no...:10.01.06.02482

Connection geometry: 40

Connection: G1/8"-F

Length L1: 20.7 mm

Fitting length: 14 mm

Nominal diameter dn: 4.1 mm

Bellows suction cup (round)

SPB1 20 ED-65 SC040

Part no...:10.01.06.02452



SIEB 11x1 MS-A2 280 0.28/0.16

Part no...:10.07.01.00309

External diameter D: 11 mm

Length L: 1 mm

Material: Brass / Stainless steel

Filter pore size: 280 µm



SPI 18 PA SPB1-20

Part no...:10.01.06.03385

Size: 18

Material: Polyamide

Use: SPB1-20



SC 040 NPT1/8-AG

Part no...:10.01.06.02541

Connection geometry: 40

Connection: NPT1/8-M

Length L1: 20.9 mm

Fitting length: 6 mm

Nominal diameter dn: 4.1 mm

Bellows suction cup (round)

SPB1 20 ED-65 SC040

Part no...:10.01.06.02452



SC 040 NPT1/8-IG

Part no...:10.01.06.02542

Connection geometry: 40

Connection: NPT1/8-F

Length L1: 20.7 mm

Fitting length: 14 mm

Nominal diameter dn: 4.1 mm