

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589

Home > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Packaging > SPB4 30 SI-55 SC080

### Bellows suction cup (round) with 4.5 folds for process reliable handling of pouches and flex. prod.




Size: 30

Suction cup material: Silicone SI

Material hardness [Shore A]: 55 Shore A

Number of folds: 4.5

### Design Data

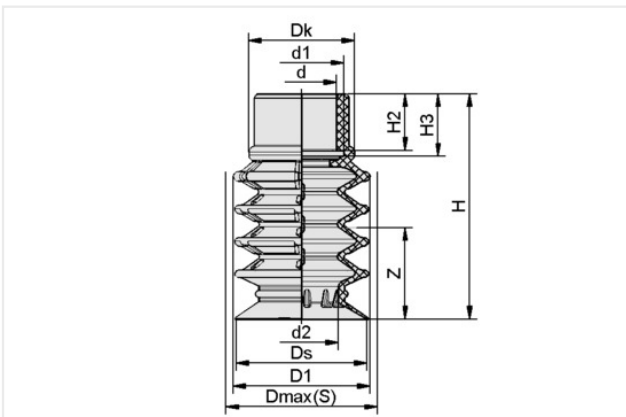

Attribute	Value
d	16 mm
d1	19.60 mm
d2	17 mm
D1	31 mm
Dk	24.40 mm
Dmax(S)	31.50 mm
Ds	30.20 mm
H	52 mm
H2	13 mm
H3	14.40 mm
Z (Stroke)	20 mm

### Technical Data

Attribute	Value
Suction force at -200 mbar	5.30 N
Suction force at -400 mbar	10.60 N
Suction force (-600mbar)	16 N
Pull-off force at -200 mbar	9.90 N
Pull-off force at -400 mbar	13 N
Volume	15.61 cm <sup>3</sup>
Size	30

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589

Nipple family	SC 080
Number of folds	4.50
Suction cup material	Silicone SI
Material hardness [Shore A]	55 Shore A
Weight	9.30 g
Product family	SPB4

### Accessories



#### SC 080 G1/4-AG

Part no...:10.01.06.03268

Connection geometry: 80

Vacuum connection: G1/4"-M

Length L1: 32 mm

Fitting length: 7.5 mm

Nominal diameter dn: 8 mm



#### SC 080 G1/4-IG

Part no...:10.01.06.03271

Connection geometry: 80

Vacuum connection: G1/4"-F

Length L1: 32 mm

Fitting length: 17.5 mm

Nominal diameter dn: 11 mm

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589



### SC 080 G1/8-AG

Part no...:10.01.06.03142

Connection geometry: 80

Vacuum connection: G1/8"-M

Length L1: 28 mm

Fitting length: 7.5 mm

Nominal diameter dn: 4 mm



### SC 080 G1/8-IG

Part no...:10.01.06.03270

Connection geometry: 80

Vacuum connection: G1/8"-F

Length L1: 32 mm

Fitting length: 17.5 mm

Nominal diameter dn: 8.6 mm



### SC 080 G3/8-AG

Part no...:10.01.06.02593

Connection geometry: 80

Vacuum connection: G3/8"-M

Length L1: 32 mm

Fitting length: 7.5 mm

Nominal diameter dn: 10.3 mm

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589



### SC 080 G3/8-IG

Part no...:10.01.06.02594

Connection geometry: 80

Vacuum connection: G3/8"-F

Length L1: 32 mm

Fitting length: 17.5 mm

Nominal diameter dn: 11 mm



### SIEB 17x0.8 MS-A2 103 0.103/0.07

Part no...:10.07.01.00320

External diameter D: 17 mm

Length L: 0.8 mm

Material: Brass / Stainless steel

Filter pore size: 103 µm



### SPI 24 PE SPB4-30

Part no...:10.01.06.02855

Size: 24

Material: Polyethylene

Use: SPB4-30

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589



### SPSE 30

Part no...:10.01.06.02953

Size: 30



### SSB 16-27 ST-VZ

Part no...:10.07.10.00002

Clamping range: 16.0 ... 27.0 mm

Material: Galvanized steel



### SC 080 NPT1/4-AG

Part no...:10.01.06.03662

Connection geometry: 80

Vacuum connection: NPT1/4-M

Length L1: 32.2 mm

Fitting length: 7.5 mm

Nominal diameter dn: 8 mm

## Bellows suction cup (round)

SPB4 30 SI-55 SC080

Part no...:10.01.06.02589



### SC 080 NPT1/4-IG

Part no...:10.01.06.03663

Connection geometry: 80

Vacuum connection: NPT1/4-F

Length L1: 32 mm

Fitting length: 17.5 mm

Nominal diameter dn: 10.3 mm



### SC 080 NPT3/8-AG

Part no...:10.01.06.03664

Connection geometry: 80

Vacuum connection: NPT3/8-M

Length L1: 32.4 mm

Fitting length: 7.5 mm

Nominal diameter dn: 10.3 mm



### SC 080 NPT3/8-IG

Part no...:10.01.06.03665

Connection geometry: 80

Vacuum connection: NPT3/8-F

Length L1: 32 mm

Fitting length: 17.5 mm

Nominal diameter dn: 10.3 mm