

## Bellows suction cup (round)

SPB4 20 SI-55 G1/4-AG

Part no...:10.01.06.03515

Home > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Packaging > Bellows Suction Cups  
SPB4 (4.5 Folds) > SPB4 20 SI-55 G1/4-AG

### Bellows suction cup (round) for very uneven workpieces



Size: 20


Suction cup material: Silicone SI

Material hardness [Shore A]: 55 Shore A

Thread G1: G1/4"-M

Number of folds: 4.5

### Design Data

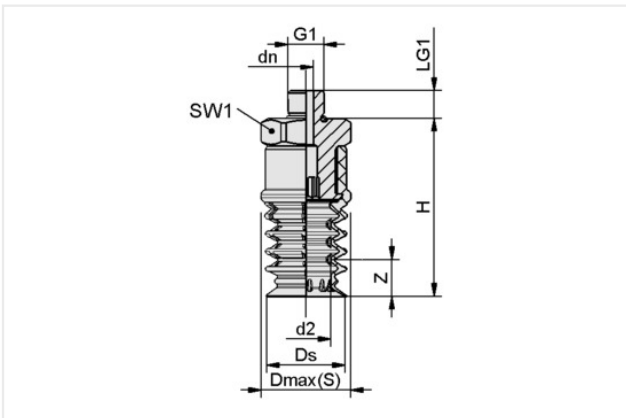

Attribute	Value
d2	13.50 mm
dn	8 mm
Dmax(S)	24.40 mm
Ds	21.40 mm
G1	G1/4"-M
H	48.40 mm
LG1	10 mm
SW1	22 mm
Z (Stroke)	10 mm

### Technical Data

Attribute	Value
Suction force (-600mbar)	8 N
Pull-off force	11 N
Volume	7.90 cm <sup>3</sup>
Hose diameter (empf.) d	9 mm
Number of folds	4.50
Suction cup material	Silicone SI
Material hardness [Shore A]	55 Shore A
Weight	20.70 g

## Bellows suction cup (round)

SPB4 20 SI-55 G1/4-AG

Part no...:10.01.06.03515

Product family

SPB4

### Accessories



**SIEB 17x0.8 MS-A2 103 0.103/0.07**

Part no...:10.07.01.00320

External diameter D: 17 mm

Length L: 0.8 mm

Material: Brass / Stainless steel

Filter pore size: 103 µm



**SSB 16-27 ST-VZ**

Part no...:10.07.10.00002


Clamping range: 16.0 ... 27.0 mm

Material: Galvanized steel

## Bellows suction cup (round)

SPB4 20 SI-55 G1/4-AG

Part no...:10.01.06.03515

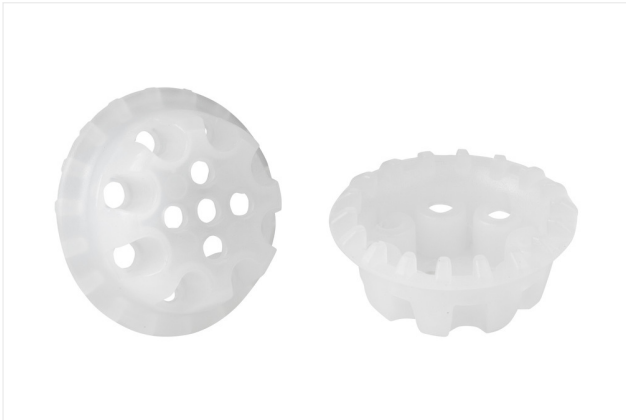

### SPI 16 PE SPB4-20

Part no...:10.01.06.02915

Size: 16

Material: Polyethylene

Use: SPB4-20

## Spare parts



### SC 080 G1/4-AG

Part no...:10.01.06.03268

Connection geometry: 80

Vacuum connection: G1/4"-M

Length L1: 32 mm

Fitting length: 7.5 mm

Nominal diameter dn: 8 mm



### SPB4 20 SI-55 SC080

Part no...:10.01.06.02588

Size: 20

Suction cup material: Silicone SI

Material hardness [Shore A]: 55 Shore A

Number of folds: 4.5