

## Bellows suction cup (round)

SPB4 50 SI-55 G1/4-AG

Part no...:10.01.06.03532

Home > Vacuum Technology for Automation > Vacuum Components > Area Gripping Systems and End Effectors > Vacuum End Effectors VEE > Suction Cups for Vacuum End Effectors > SPB4 50 SI-55 G1/4-AG

### Bellows suction cup (round) for very uneven workpieces



Size: 50


Suction cup material: Silicone SI

Material hardness [Shore A]: 55 Shore A

Thread G1: G1/4"-M

Number of folds: 4.5

### Design Data

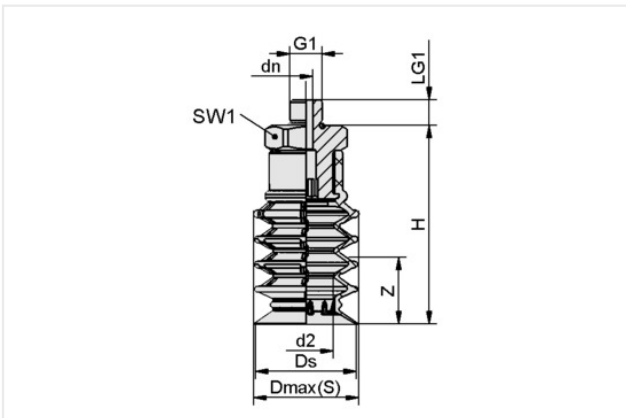

Attribute	Value
d2	30 mm
dn	8 mm
Dmax(S)	51.50 mm
Ds	50.30 mm
G1	G1/4"-M
H	83.50 mm
LG1	10 mm
SW1	27 mm
Z (Stroke)	36.50 mm

### Technical Data

Attribute	Value
Suction force (-600mbar)	49.50 N
Pull-off force	62 N
Volume	64.55 cm <sup>3</sup>
Hose diameter (empf.) d	12 mm
Number of folds	4.50
Suction cup material	Silicone SI
Material hardness [Shore A]	55 Shore A
Weight	50 g

## Bellows suction cup (round)

SPB4 50 SI-55 G1/4-AG

Part no...:10.01.06.03532

Product family

SPB4

### Accessories



#### SIEB 19.5x1 MS-A2 103

Part no...:10.07.01.00321

External diameter D: 19.5 mm

Length L: 1 mm

Material: Brass / Stainless steel

Filter pore size: 103 µm



#### SSB 20-32 ST-VZ

Part no...:10.07.10.00003

Clamping range: 20.0 ... 32.0 mm

Material: Galvanized steel

## Bellows suction cup (round)

SPB4 50 SI-55 G1/4-AG

Part no...:10.01.06.03532



### SPI 42 PE SPB4-50

Part no...:10.01.06.02916

Size: 42

Material: Polyethylene

Use: SPB4-50

## Spare parts



### SC 090 G1/4-AG

Part no...:10.01.06.02793

Connection geometry: 90

Vacuum connection: G1/4"-M

Length L1: 33.5 mm

Fitting length: 7.5 mm

Nominal diameter dn: 8 mm



### SPB4 50 SI-55 SC090

Part no...:10.01.06.02613

Size: 50

Suction cup material: Silicone SI

Material hardness [Shore A]: 55 Shore A

Number of folds: 4.5