

# STRIDE<sup>®</sup> ANTENNA

MODEL #SE-ANT150

DOME LTE ANTENNA, PANEL MOUNT

FOR USE WITH SE-SL3011-4G AND SE-SL3011-4GG



## Features

- 4G LTE coverage
- Low profile, 48mm height and 50mm diameter
- UV and vandal resistant ABS housing
- Heavy duty screw mount
- 3-meter low-loss CFD200 cable
- SMA Male connector
- IP67 compliant
- Extended operating temperature range
- RoHS Compliant

## Electrical Specifications


Communication System	700 LTE/AMPS/GSM	DCS/PCS/UMTS	2700 LTE	2.4 GHz WiFi
Frequency (MHz)	700-960	1710-2170	2500-2800	2400-2483
Efficiency	40%	55%	40%	38%
Peak Gain (dBi)	1.2	3.2	2.5	1.5
Avg. Gain (dBi)	-4.5	-2.5	-4.5	-4.5
VSWR	< 3.0:1			
Impedance	50Ω			
Polarization	Linear			
Radiation Pattern	Omni-directional			
Input Power	5W			

## Environmental Specifications

Operating Temperature Range	-40°C to 85°C [-40°F to 185°F]
Storage Temperature Range	-40°C to 105°C [-40°F to 221°F]
Relative Humidity	Up to 95% non-condensing


**NOTE: ANTENNA IS REQUIRED AND MUST REMAIN CONNECTED DURING OPERATION**

## Mechanical Drawing unit: mm [in]

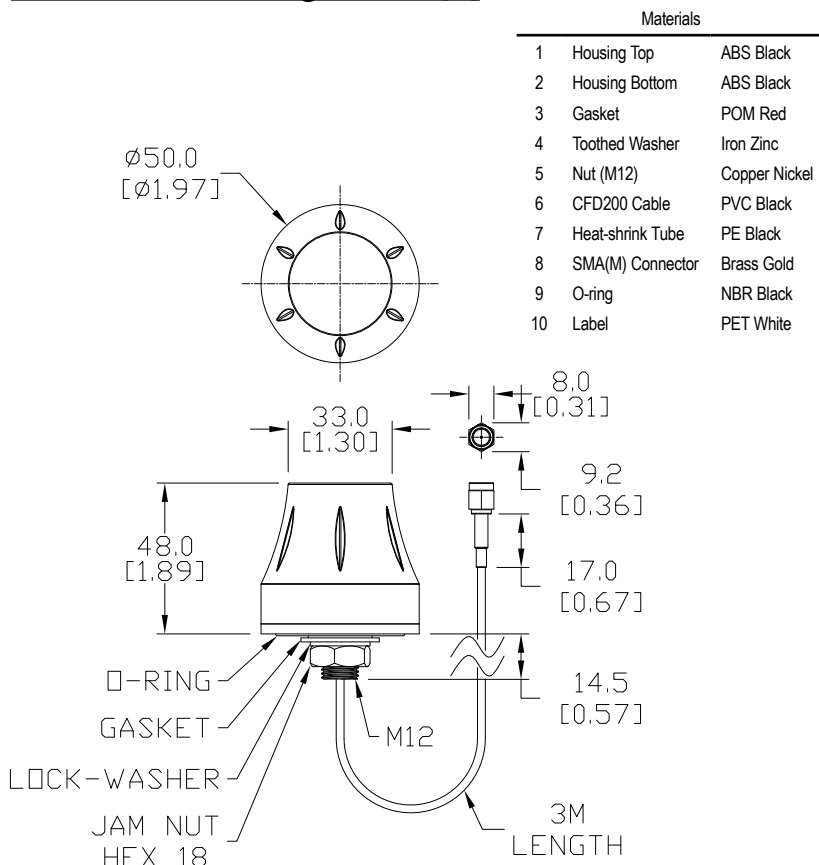

## Mounting Instructions

Recommended torque: 2.94 N·m [26 lb·in]  
 Maximum torque: 3.92 N·m [34.7 lb·in]

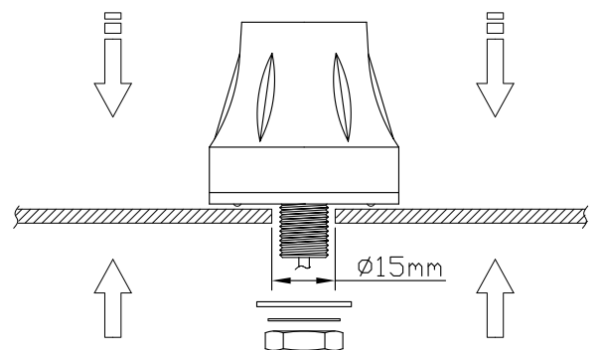

## Additional Help and Support

- For additional product support, specifications, and installation, a User Manual, SE-SLVPN-USER-M, is available for the accompanying VPN Router as a downloadable PDF file from the Online Documentation area of [www.AutomationDirect.com](http://www.AutomationDirect.com)
- For additional technical support and questions, call our Technical Support team @ 770-844-4200.

