

MR200KR10

Measuring wheel MR200KR10

Circumference 200 mm,

Surface finish: Metal, knurled

Fields of application: Pasteboard, wood, textiles, rubber, soft plastic.


For encoder with shaft Ø 10 mm



Product data

Circumference	200 mm
Surface finish	Metal, knurled
Moment of inertia	$3 \times 10^3 \text{ gcm}^2$
Wheel body material	Aluminum
Standard bore-hole	Ø 10 mm
Width	12 mm
Operating temperature	-30 °C up to +180 °C [-22 °F up to +356 °F]
Weight	60 g
Order number MR200KR10	Measuring wheel, bore-hole Ø 10 mm

Drawing MR200K10R

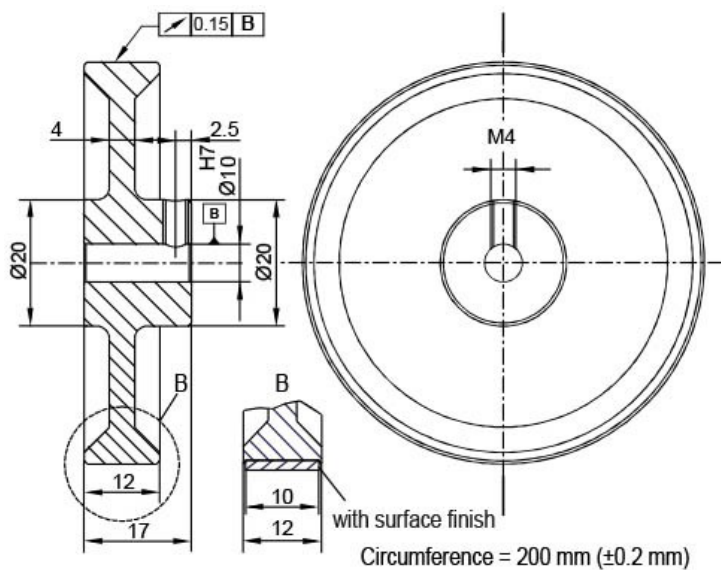

All dimensional specifications in mm

