

MR500KR10
 Measuring wheel
 MR500KR10


Circumference 500 mm,
 Surface finish: Metal, knurled
 Fields of application: Pasteboard, wood,
 textiles, rubber, soft plastic.
 For encoder with shaft Ø 10 mm.



Product data

Circumference	500 mm
Surface finish	Metal, knurled
Moment of inertia	17.1 x 10 ³ gcm ²
Wheel body material	Aluminum
Standard bore-hole	Ø 10 mm
Width	25 mm
Operating temperature	-30 °C up to +180 °C [-22 °F up to +356 °F]
Weight	505 g
Order number MR500KR10	Measuring wheel, bore-hole Ø 10 mm

Drawing MR500KR10

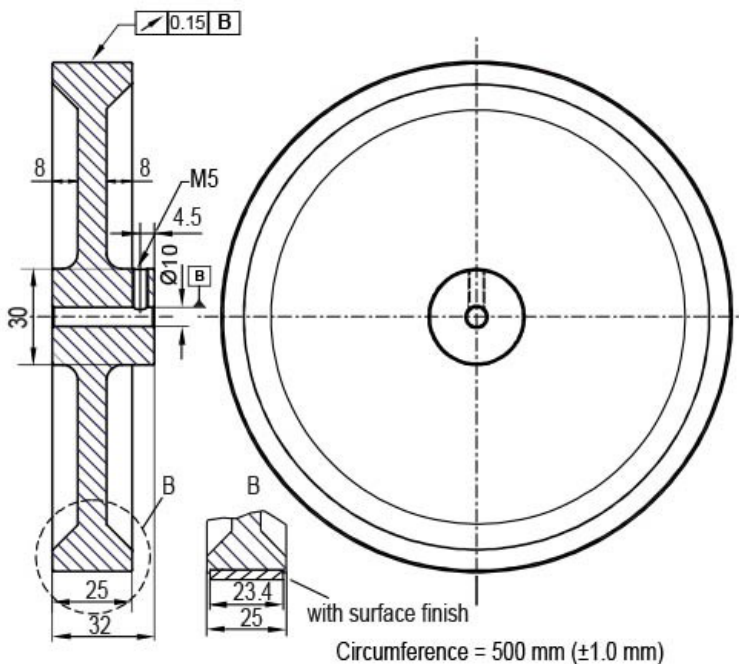

All dimensional specifications in mm

