

**Measuring wheel
 MR500NG10**


Circumference 500 mm,
 Surface finish: Synthetic (pimpled Polyurethan)
 Fields of application: rough textiles, carpet, cable
 measuring, fleece, paper, pasteboard, wood, plastic.
 For encoder with shaft Ø 10 mm.



Product data

Circumference	500 mm
Surface finish	pimpled
Hardness/Shore A	60
Moment of inertia	15.5 x 10 ³ gcm ²
Wheel body material	Aluminum
Standard bore-hole	Ø 10 mm
Width	25 mm
Operating temperature	-30 °C up to +80 °C [-22 °F up to +176 °F]
Weight	483 g
Order number MR500NG10	Measuring wheel, bore-hole Ø 10 mm

Drawing MR500NG10

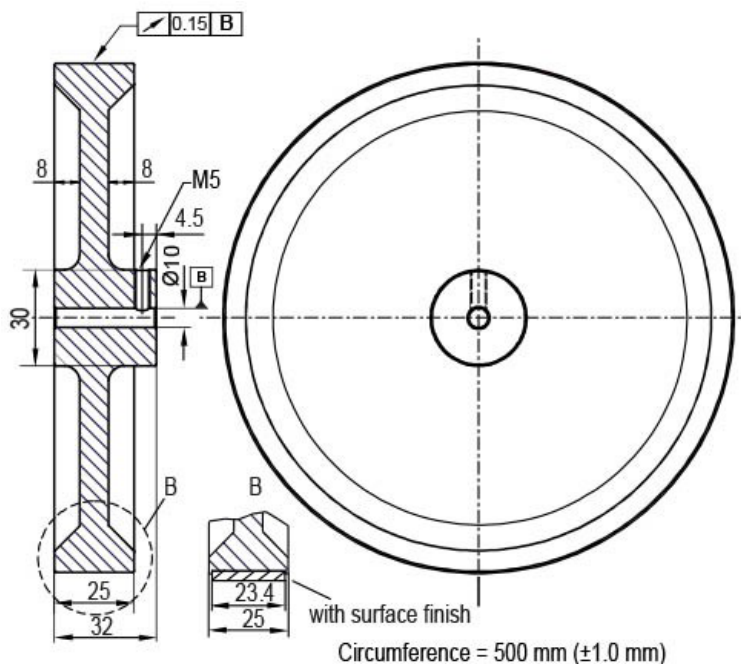

All dimensional specifications in mm

