




Ⓢ Anschluss **ausschließlich** durch ausgebildete Elektro-Fachkräfte.
 Ⓣ Electrical connection is to be made by trained electrical specialists **only**.
 Ⓤ Le branchement doit **uniquement** être effectué par des professionnels.
 Ⓥ Il collegamento deve essere eseguito **solo** da elettricisti specializzati.
 Ⓦ La conexión **sólo** debe ser realizada por electricistas debidamente formados.
 Ⓧ A ligação deve ser feita **exclusivamente** por profissional eléctrico especializado.
 Ⓨ Připojení smí **provádět** pouze kvalifikovaný personál.
 Ⓩ Podłączenie **wyłącznie** przez specjalistów-elektryków.
 ⓐ Liittäminen kuuluu **ainoastaan** koulutettujen sähköalan ammattilaisten tehtäviin.
 ⓒ Подключение проводится только специалистом-электриком.
 ⓔ Bağlantı **sadece** eğitimli elektrik teknisyenleri tarafından yapılmalıdır.
 ⓕ 布线需由专业电工执行

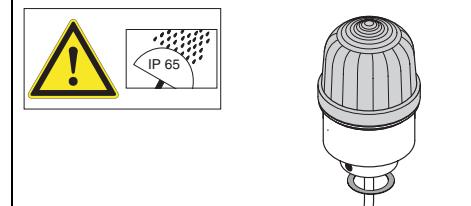


209 x00 00	12 – 240 V~, ≤ 7 W
209 x10 67	115 V~, 25 mA, $I_0 < 500$ mA
209 x10 68	230 V~, 25 mA, $I_0 < 500$ mA
209 x10 75	24 V~, 45 mA, $I_0 < 500$ mA
209 x20 55	24 V~, 100 mA, ~ 0.75 Hz
209 x20 67	115 V~, 20 mA, ~ 0.75 Hz
209 x20 68	230 V~, 30 mA, ~ 0.75 Hz
219 x00 00	12 – 240 V~, ≤ 10 W
219 x10 67	115 V~, 25 mA, $I_0 < 500$ mA
219 x10 68	230 V~, 25 mA, $I_0 < 500$ mA
219 x10 75	24 V~, 45 mA, $I_0 < 500$ mA
219 x20 55	24 V~, 100 mA, ~ 0.75 Hz
219 x20 67	115 V~, 20 mA, ~ 0.75 Hz
219 x20 68	230 V~, 30 mA, ~ 0.75 Hz
BA 15 d (209 x10 xx, 219 x10 xx)	
956 x00 75	24 V~, 45 mA
956 x00 67	115 V~, 15 mA
956 x00 68	230 V~, 15 mA
BA 15 d, ≤ 42 mm (1.65 "), (209 x00 00 ≤ 7 W)	
955 840 34	12 V
955 840 35	24 V
955 840 32	30 V
955 840 57	115 V
955 840 38	230 V
BA 15 d, ≤ 52 mm (2.05 "), (219 x00 00 ≤ 10 W)	
955 015 34	12 V
955 015 35	24 V
955 015 57	115 V
955 015 38	230 V

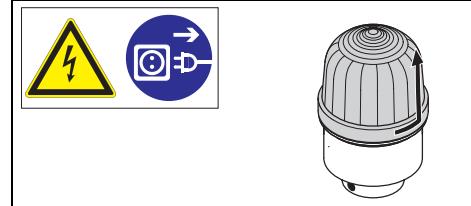


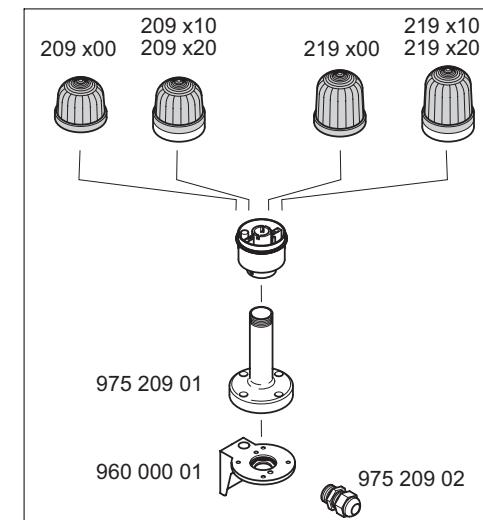








1

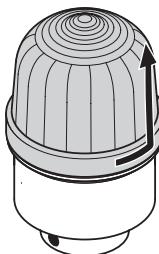

2

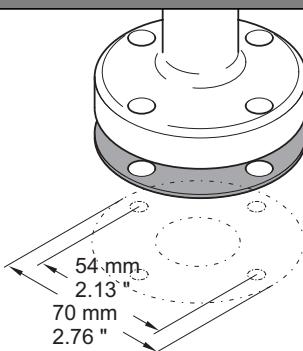2a - 975 209 01
2b - 960 000 01

2b

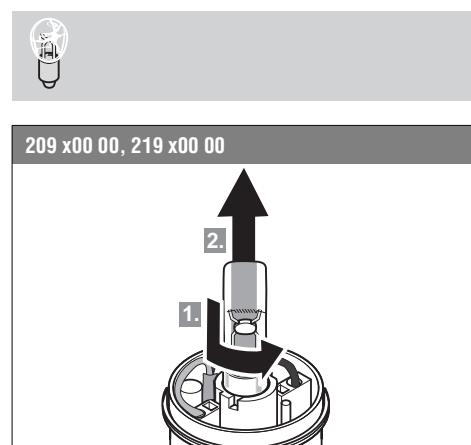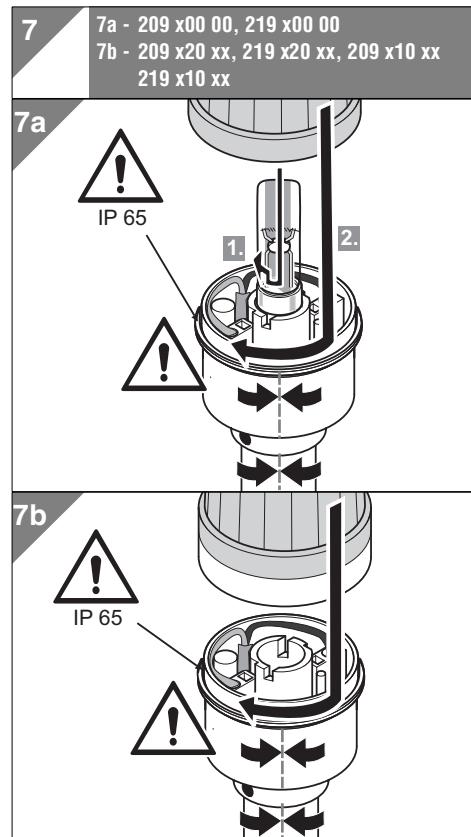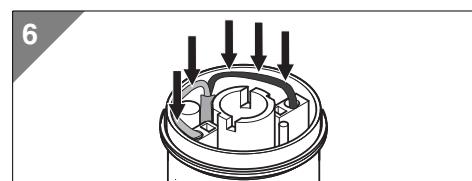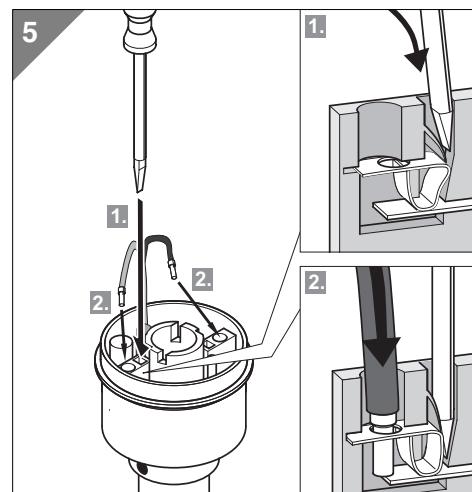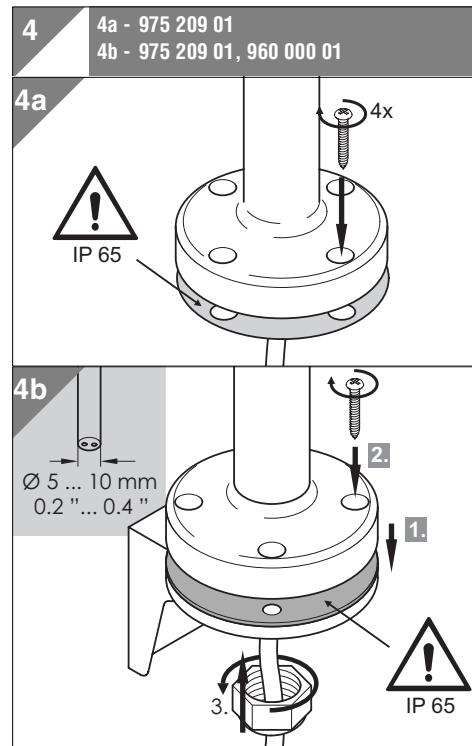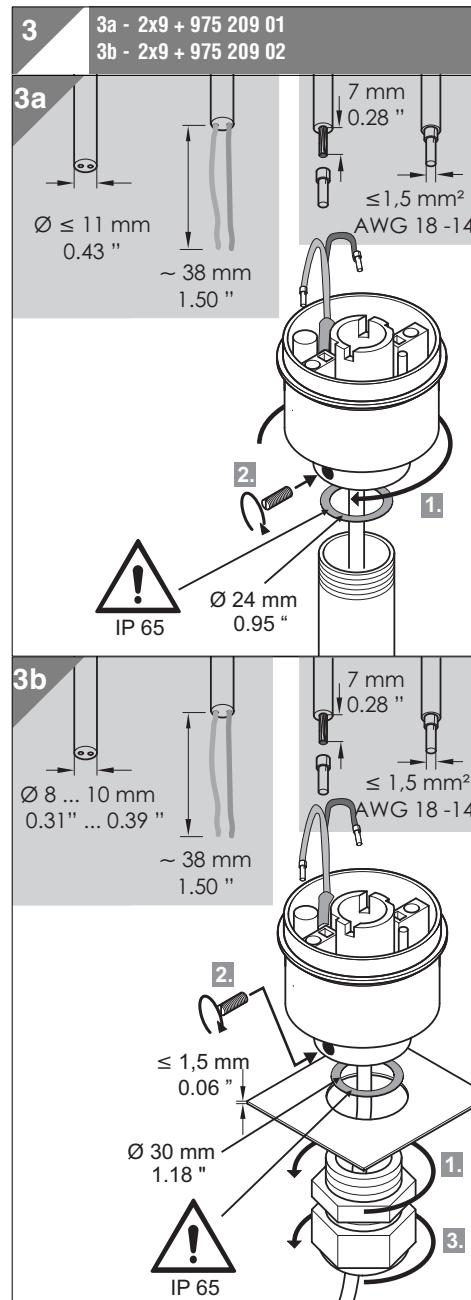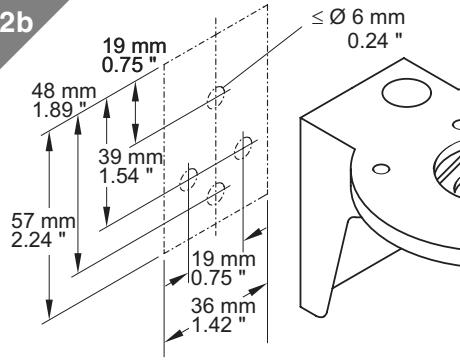

310.209.001.1007

© D


WERMA
SIGNALTECHNIK