


# SS703 -- Wallplates

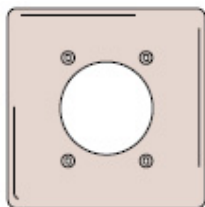

Single Receptacle Plates, 2-Gang 1 Device-Gang, Standard Size, Satin Stainless

### Product Specifications

<b>Product Type</b>	<p>Wall Plates</p>
<b>Plate Material</b>	Metallic
<b>Gangs</b>	2-Gang 1 Device
<b>Plate Group</b>	Single Receptacle Plates
<b>Single Receptacle Plate Image- Per Gang</b>	<p>2.156" Opening</p>
<b>Plate Size</b>	Standard
<b>Color/Material</b>	Satin Stainless
<b>Listings</b>	UL Standard 514D
<b>Certification</b>	UL Listed E92074, CSA Certified
<b>Thickness</b>	.04" (1.0)
<b>Mounting Screws</b>	6/32" X 3/8" Oval Milled Head
<b>Operating Temp</b>	-40 deg. C to 85 deg. C
<b>Appearance</b>	Slightly Beveled, Matte Finish
<b>Product Dimensions</b>	4.625" (117.48) X 2.875" (72.39)
<b>UPC Number</b>	88377820113
<b>Weight in LBS</b>	0.2

