


Product Datasheet

[Catalog Home](#)[Home Page](#)[Search](#)

SS703L-- Wallplates

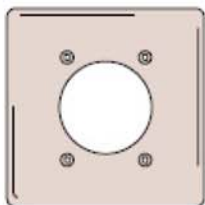

Single Receptacle Plates, 2-Gang 1 Device-Gang, Standard Size,
Satin 430 Stainless

Product Specifications

Product Type	<p>Wall Plates</p>
Plate Material	Metallic
Gangs	2-Gang 1 Device
Plate Group	Single Receptacle Plates
Single Receptacle Plate Image- Per Gang	<p>2.156" Opening</p>
Plate Size	Standard
Color/Material	Satin 430 Stainless
Listings	UL Standard 514D
Certification	UL Listed E92074, CSA Certified
Thickness	.04" (1.0)
Mounting Screws	6/32" X 3/8" Oval Milled Head
Operating Temp	-40 deg. C to 85 deg. C
Appearance	Slightly Beveled, Matte Finish
Product Dimensions	4.625" (117.48) X 2.875" (72.39)
UPC Number	88377809514
Weight in LBS	0.2

BRYANT®