


| TABLE A | |
|---------------|--------------|
| PART NO | LENGTH |
| GS-EDRV-CBL-2 | 2.0M [6.6FT] |
| | |
| | |

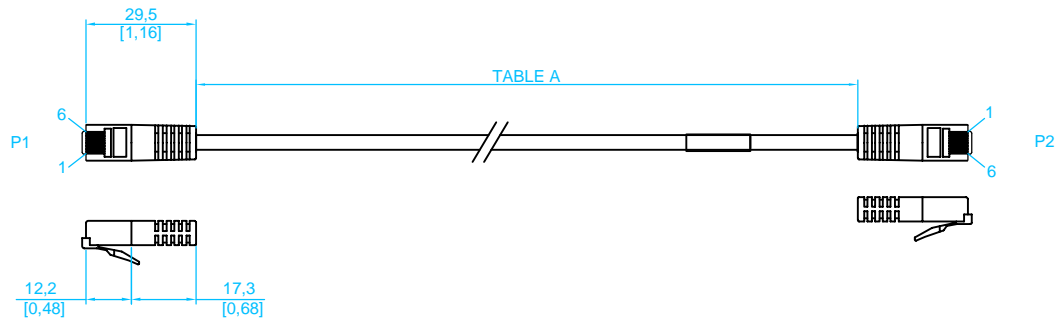

NOTES:

1. UL20251 26AWG*6C
OD: 2.5*7.0, JACKET BLACK COLOR
2. RJ12 6P6C MODULAR PLUG
CONTACT: BRASS, GOLD FLASH
3. MINIMUM BEND RADIUS: 36mm [1.42in]
4. OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN-OUT DIAGRAM



| | |
|------------------------|---------------|
| GS-EDRV-CBL-2 | |
| Rev: original | Date: 06/2010 |
| Units: mm [inches] | |
| Scale: none | |
| ZIPLINK GS Drive Cable | |
| | |