


| TABLE A         |              |
|-----------------|--------------|
| PART NO         | LENGTH       |
| GS-ISOCON-CBL-2 | 2.0M [6.6FT] |
|                 |              |
|                 |              |

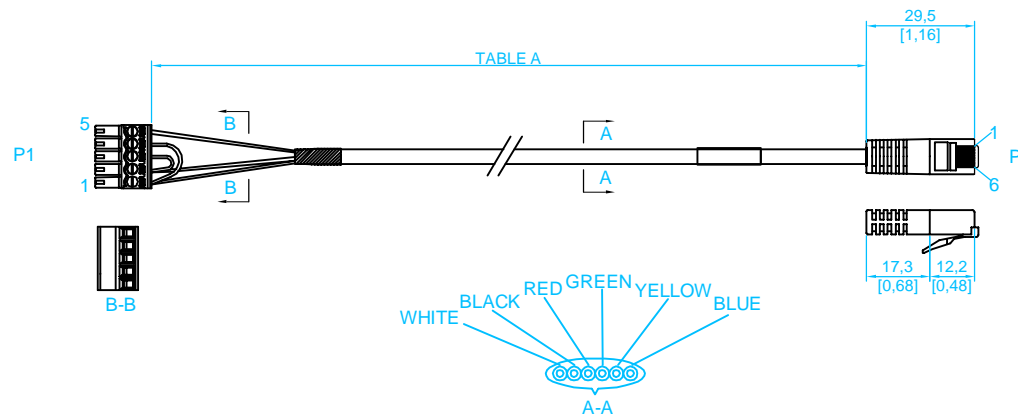

NOTES:

1. UL20251 26AWG\*6C  
OD: 2.5\*7, JACKET BLACK COLOR
2. 5 PIN TERMINAL BLOCK. 3.5mm.  
GREEN. DINKLE EC350V-05P.
3. RJ12 6P6C MODULAR PLUG  
CONTACT: BRASS, GOLD FLASH
4. MINIMUM BEND RADIUS: 36mm [1.42in].
5. OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN-OUT DIAGRAM



| GS-ISOCON-CBL-2   |               |
|---|---------------|
| Rev: original   | Date: 06/2010 |
| Units: mm [inches]  |               |
| Scale: none   |               |
| ZIPLINK GS Drive Cable  |               |
|  |               |