


TABLE A	
PART NO	LENGTH
STP-232RJ12-CBL-2	2.0m [6.6 ft]

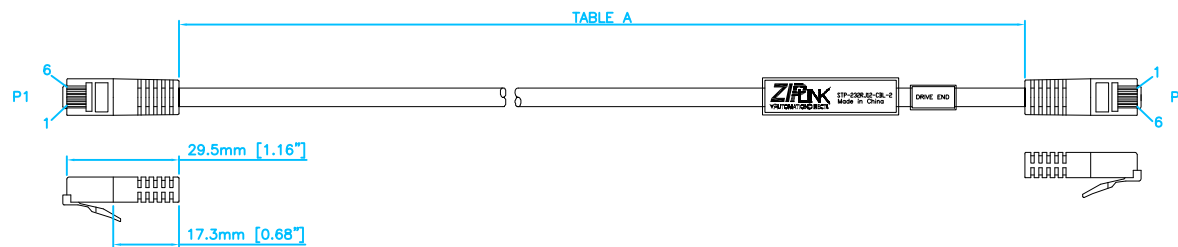

NOTES:

1. UL2464 28AWG*3C + TALCUM
OD: 4.5mm, JACKET BLACK COLOR
2. RJ12 6P6C MODULAR PLUG
CONTACT: BRASS, GOLD FLASH
3. MINIMUM BEND RADIUS: 36mm [1.42"]
4. OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN-OUT DIAGRAM



STP-232RJ12-CBL-2	
Rev: B	Date: 06/2013
Units: mm [inches]	
Scale: none	
ZIPLINK SURE STEP CABLE	
