



TABLE A	
PART NO	LENGTH
SVC-485CFG-CBL-2	2.0M [6.6FT]

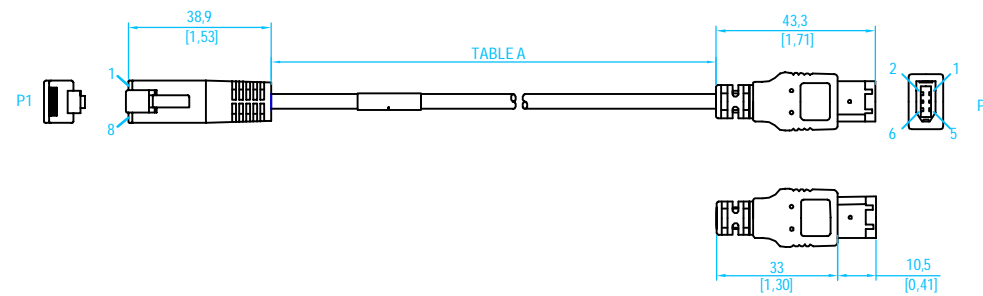

NOTE:

1. UL20276 28AWG*2P + AEB
OD: 5.0mm, JACKET WHITE COLOR
2. RJ45 8P8C MODULAR PLUG
CONTACT: BRASS, GOLD FLASH
3. 1394 6PIN PLUG SOLDERING TYPE
INSULATION: PBT, BLACK COLOR
CONTACT: BRASS, GOLD FLASH
4. MINIMUM BENDING RADIUS: 40mm [1.57"]
5. OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN-OUT DIAGRAM

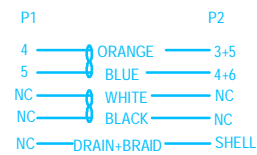

SVC-485CFG-CBL-2	
Rev: original	Date: 06/2010
Units: mm [inches]	
Scale: none	
ZIPLINK SVC DRIVE CABLE	