



TABLE A	
PART NO	LENGTH
SVC-485RJ12-CBL-2	2.0M [6.6FT]

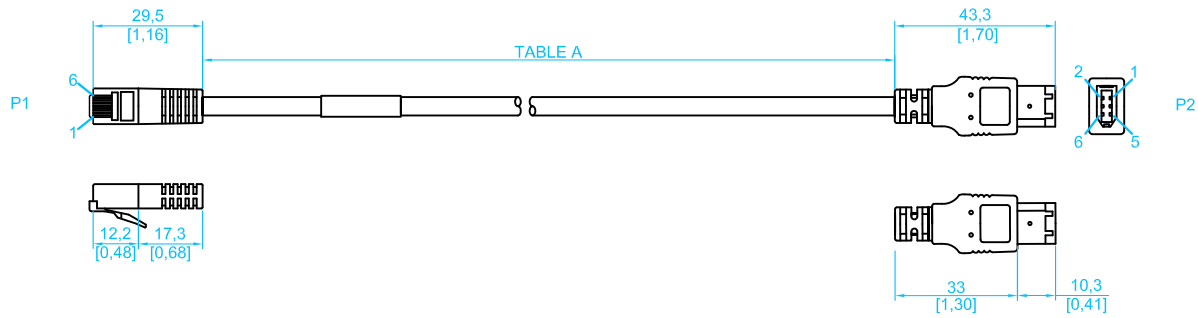

NOTES:

- UL20276 28AWG\*2P + AEB  
OD: 5.0mm, JACKET WHITE COLOR
- RJ12 6P6C MODULAR PLUG  
CONTACT: BRASS, GOLD FLASH
- 1394 6PIN PLUG SOLDER TYPE  
INSULATION: PBT, BLACK COLOR  
CONTACT: BRASS, GOLD FLASH
- MINIMUM BEND RADIUS: 40mm [1.57"]
- OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN-OUT DIAGRAM

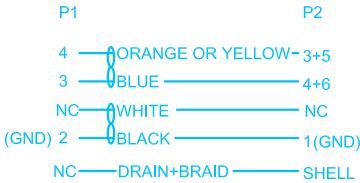

SVC-485RJ12-CBL-2	
Rev: original	Date: 06/2010
Units: mm [inches]	
Scale: none	
ZIPLINK SVC DRIVE CABLE	