

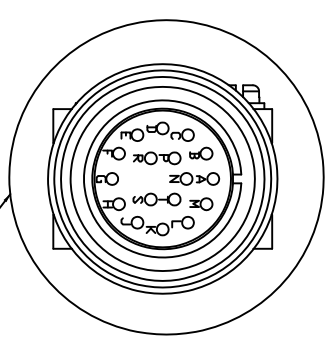
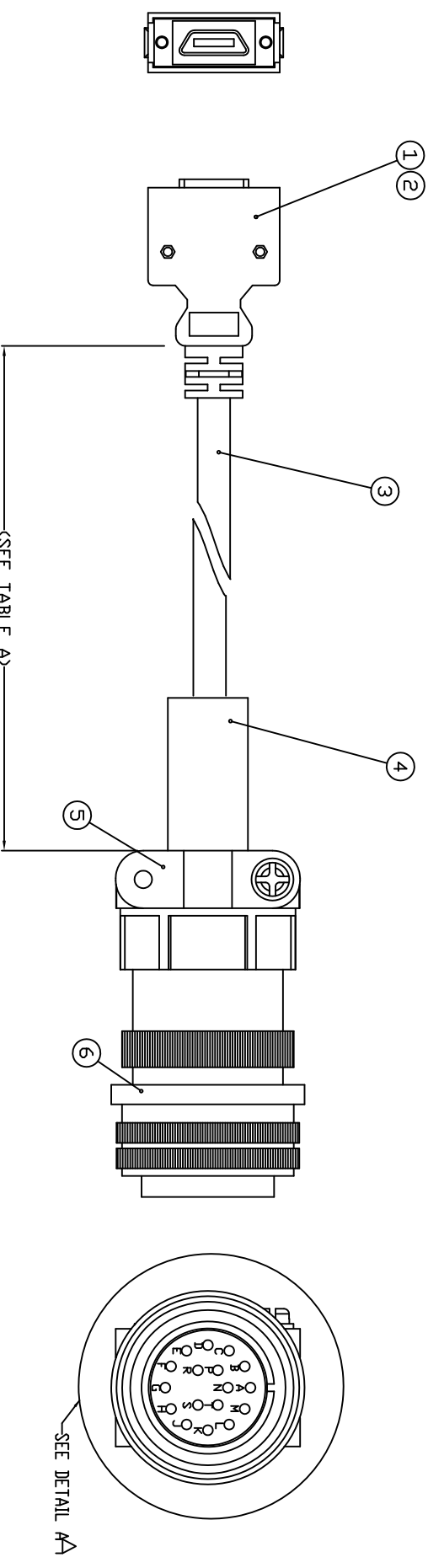


ITEM	UL RECOGNIZED COMPONENTS	Qty
1	Connector (ECBT2) 3M Company Electronics Solutions Div (ESD) cat. no. 10120 or equivalent	1
2	Cable (A4LV2) 26 AWGx5P 300V, 80°C UL2464 Twist Pair, Braided Shield (BLACK)	See Table A
3	Cable Receptacle (ECBT2) Amphenol Corp (E115497) cat. no. 97, MS 3106A-20-29S or equivalent	1

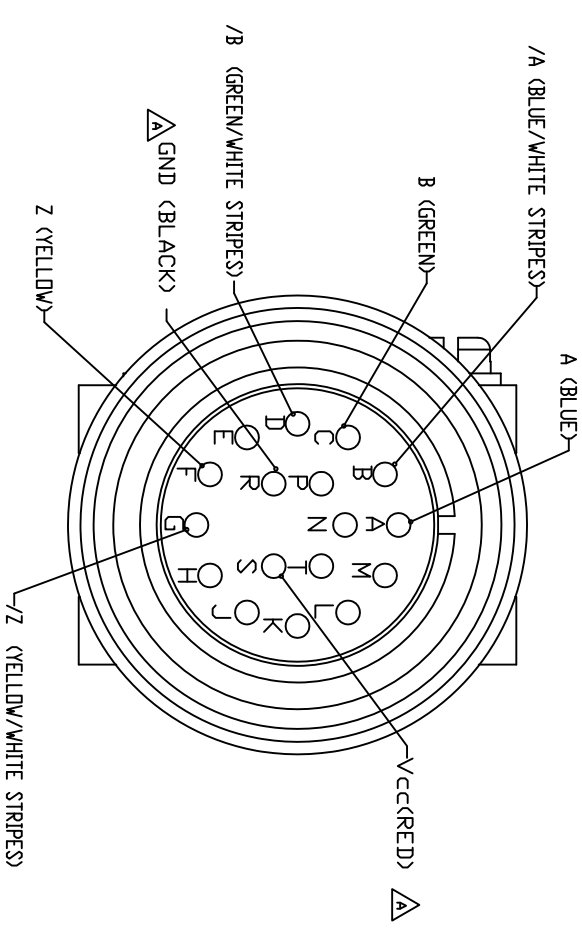

TWISTED PAIR SIGNALS
SV AND GND
SV AND GND
A AND /A
B AND /B
Z AND /Z

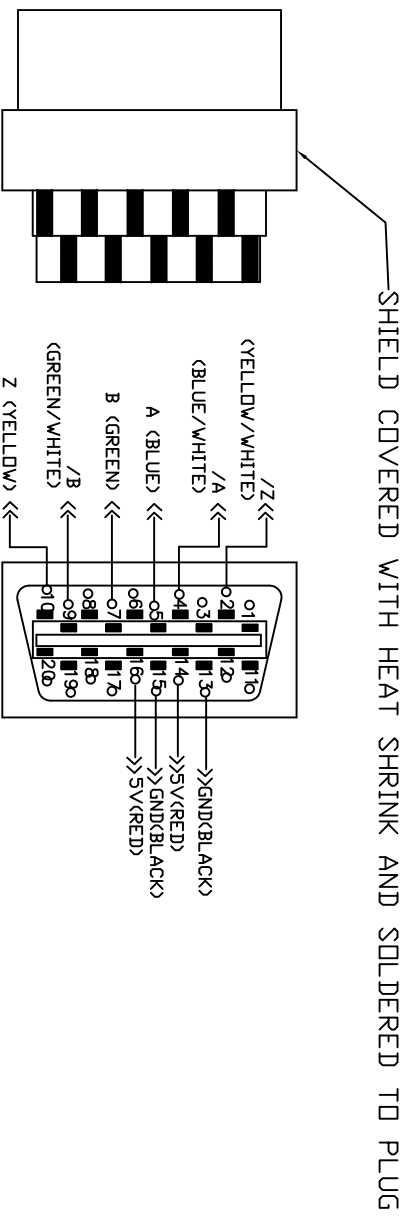

DETAIL A

TABLE A

PART NUMBER	LENGTH
SVC-EHH-010	3.0m [10 f+]
SVC-EHH-020	6.1m [20 f+]
SVC-EHH-030	9.1m [30 f+]
SVC-EHH-060	18.3m [60 f+]

- SPECIFICATIONS:
1. CURRENT – .361A at 5VDC
  2. OPERATING TEMPERATURE – 0–55°C (32–140°F)
  3. MINIMUM BEND RADIUS – 86 mm [3.4 in]

SVC-EHH-n	
Rev: original	Date: 05/2010
Units: mm [inches]	
Scale: none	
SURE SERVO ENCODER CABLE	
AUTOMATIONDIRECT	