


TABLE A

PART NO	LENGTH
ZL-CO-CBL20-1P	1000mm [39.37"]
ZL-CO-CBL20-2P	2000mm [78.74"]

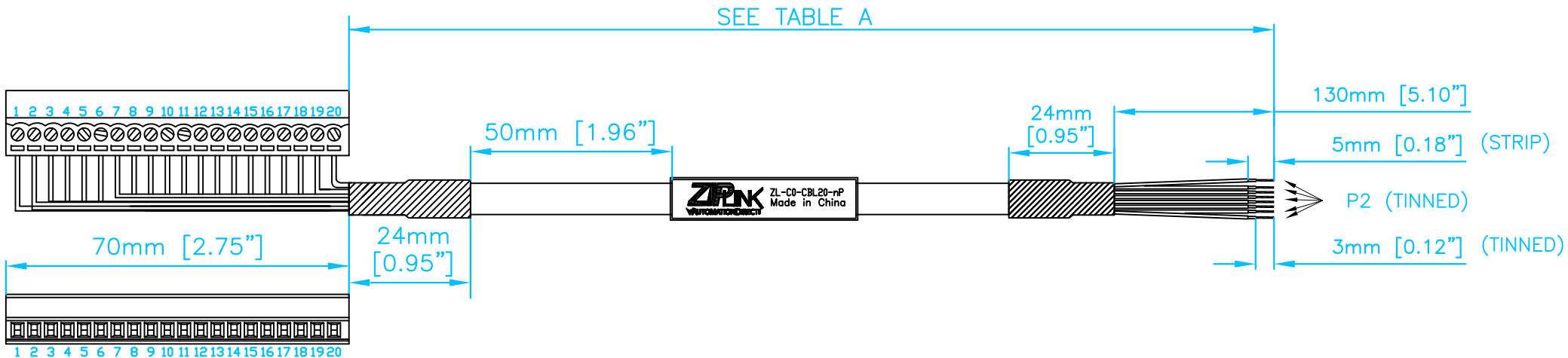

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	BLACK BLACK/WHITE	11	YELLOW YELLOW/BLACK
2	RED	12	LIGHT GREEN
3	ORANGE	13	LIGHT BLUE
4	GREEN	14	PINK
5	PURPLE	15	BLUE
6	BROWN BROWN/WHITE	16	GRAY GRAY/BLACK
7	RED/WHITE	17	GREEN/BLACK
8	ORANGE/WHITE	18	WHITE
9	GREEN/WHITE	19	RED/BLACK
10	PURPLE/WHITE	20	ORANGE/BLACK

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -  
240V AC/DC rated operating voltage  
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 20-pin terminal block for Click PLC AutomationDirect part # C0-16TB
- P2 CONNECTION -tinned pig-tail leads (all 24 leads are connected to P1, per cable pin-out diagram)
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-CO-CBL20-nP	
Rev: original	Date: 10/2009
Units: mm [inches]	
Scale: none	
ZIPLINK Click PLC Cable	