


TABLE A

PART NO	LENGTH
ZL-CO-CBL20	0.5m [1.6 ft]
ZL-CO-CBL20-1	1.0m [3.3 ft]
ZL-CO-CBL20-2	2.0m [6.6 ft]

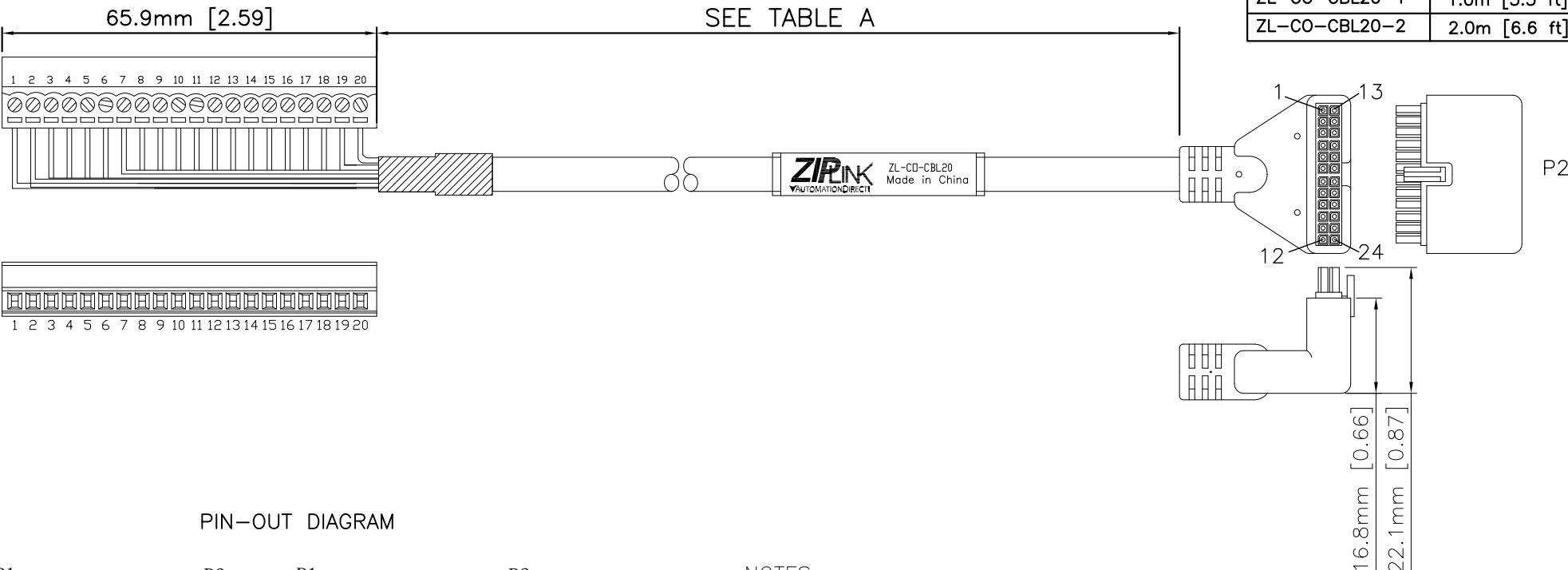

PIN-OUT DIAGRAM

P1	P2	P1	P2
1 BLACK	1	11 YELLOW	7
2 BLACK/WHITE	13	12 YELLOW/BLACK	19
3 RED	3	13 LIGHTGREEN	9
4 ORANGE	4	14 LIGHTBLUE	10
5 GREEN	5	15 PINK	11
6 VIOLET	6	16 BLUE	12
7 BROWN	2	17 GRAY	8
8 BROWN/WHITE	14	18 GRAY/BLACK	20
9 RED/WHITE	15	19 GREEN/BLACK	21
10 ORANGE/WHITE	16	20 WHITE	22
	17	21 RED/BLACK	23
	18	22 ORANGE/BLACK	24

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE - 240V AC/DC rated operating voltage, 265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 20-pin terminal block for Click PLC AutomationDirect part # C0-16TB
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-CO-CBL20-n	
Rev: A	Date: 08/2013
Units: mm [inches]	
Scale: none	
ZIPLINK Click PLC Cable	