


TABLE A

PART NO	LENGTH
ZL-CBL24-1P	1.0m (3.3ft)
ZL-CBL24-2P	2.0m (6.6ft)

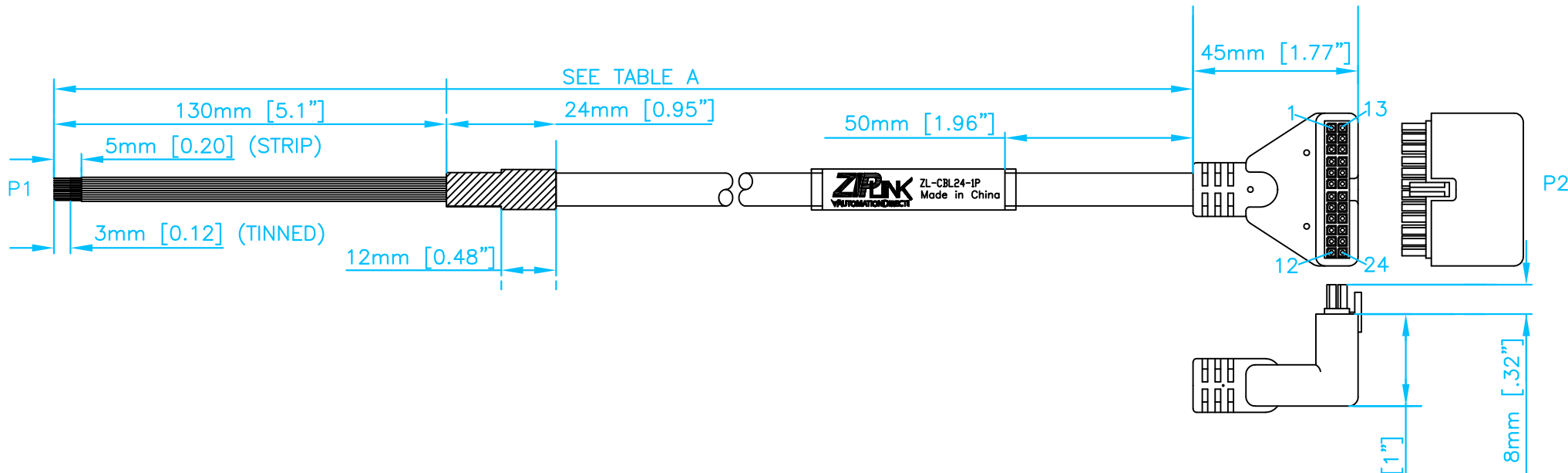

PIN-OUT DIAGRAM

P1	P2	P1	P2
BLACK	1	BLACK/WHITE	13
BROWN	2	BROWN/WHITE	14
RED	3	RED/WHITE	15
ORANGE	4	ORANGE/WHITE	16
GREEN	5	GREEN/WHITE	17
PURPLE	6	PURPLE/WHITE	18
YELLOW	7	YELLOW/BLACK	19
GRAY	8	GREY/BLACK	20
LIGHTGREEN	9	GREEN/BLACK	21
LIGHTBLUE	10	WHITE	22
PINK	11	RED/BLACK	23
BLUE	12	ORANGE/BLACK	24

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 24 tinned pig-tail leads
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-CBL24-nP	
Rev: original	Date: 07/2009
Units: mm [inches]	
Scale: .0397	
ZIPLINK Connector Module Cable	