


TABLE A

PART NO	LENGTH
ZL-CBL50-1P	1000mm [39.37"]
ZL-CBL50-2P	2000mm [78.74"]

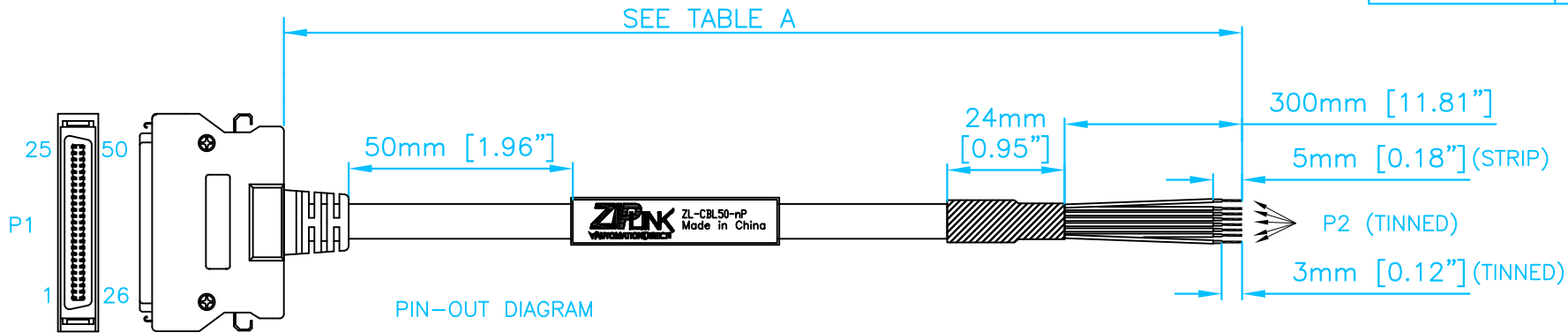


PIN-OUT DIAGRAM

P1	1	Yellow	P1	14	Gray/Green
	26	Yellow/Black		39	Gray/Yellow
	2	Red		15	White/Yellow
	27	Red/Black		40	White/Green
	3	Brown		16	Light Green/Red
	28	Brown/White		41	Green/Blue
	4	Light Blue		17	Light Blue/Blue
	29	Light Blue/Black		42	Light Blue/Red
	5	Light Blue/Green		18	Pink/Red
	30	Light Blue/Yellow		43	Pink/Blue
	6	Green		19	Gray/Red
	31	Green/Black		44	Gray/Blue
	7	Blue		20	Green/White
	32	Blue/White		45	Light Green/Blue
	8	White		21	Yellow/Red
	33	White/Black		46	Yellow/Blue
	9	Pink		22	Red/White
	34	Pink/Black		47	Red/Blue
	10	Violet		23	White/Red
	35	Violet/White		48	White/Blue
	11	Gray		24	Light Green
	36	Gray/Black		49	Light Green/Black
	12	Orange		25	Light Green/Yellow
	37	Orange/Black		50	Light Green/Green
	13	Pink/White			
	38	Pink/Yellow			

SHELL-BRAID+DRAIN SHELL

NOTES:

- CABLE - 50 conductor, 28 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- VOLTAGE -
AC/DC rated operating voltage 24V
AC/DC maximum voltage 30V
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR -
3M CONNECTOR P/N - 10150-6000EC MDR
3M HOOD P/N - 10350-3210-000
- MINIMUM BEND RADIUS - 64mm [2.52in]

ZL-CBL50-nP	
Rev: B	Date: 02/2011
Units: mm [inches]	
Scale: .03940	
ZIPLINK SureServo Cable	
 AUTOMATIONDIRECT .com	