


TABLE A

PART NO.	LENGTH
ZL-CBL50-1P	1.0m (3.3ft)
ZL-CBL50-2P	2.0m (6.6ft)

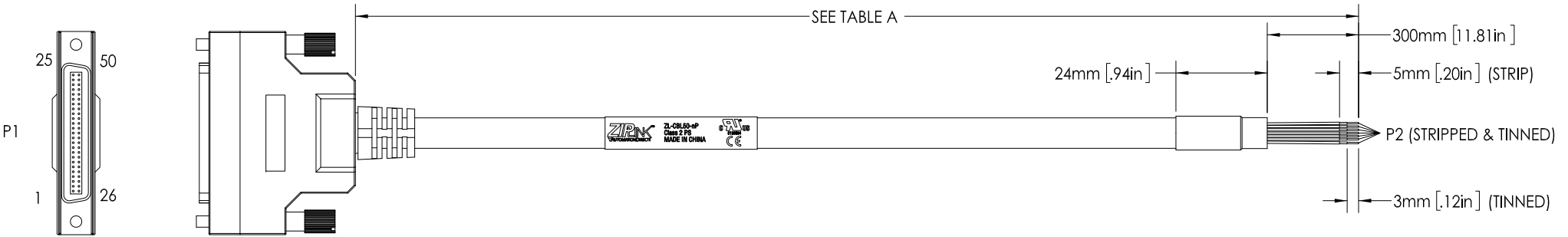

PIN-OUT DIAGRAM

P1	1	Black	P1	14	Pink/Blue
	26	Black/White		39	Pink/Green
	2	Brown		15	Light Blue
	27	Brown/White		40	Light Yellow
	3	Red		16	Light Blue/Black
	28	Red/White		41	Light Blue/Red
	4	Orange		17	Light Blue/Blue
	29	Orange/White		42	Light Blue/Green
	5	Yellow		18	Grey/Red
	30	Yellow/Black		43	Grey/Green
	6	Green		19	Blue/Black
	31	Green/White		44	Purple/Black
	7	Blue		20	Light Green/Black
	32	Blue/White		45	Light green/Red
	8	Purple		21	Light Green/Blue
	33	Purple/White		46	Light Green/Green
	9	Grey		22	Light Yellow/Black
	34	Grey/Black		47	Light Yellow/Red
	10	White		23	Light Yellow/Blue
	35	Orange/Black		48	Light Yellow/Green
	11	Pink		24	White/Black
	36	Red/Black		49	White/Red
	12	Light Green		25	White/Blue
	37	Green/Black		50	White/green
	13	Pink/Black			
	38	Pink/Red			

SHELL: BRAID+DRAIN SHELL

NOTES:

1. CABLE: 50 CONDUCTOR, 28 AWG, BLACK PVC JACKET INSULATION RATING 80°C (176°F), 30V
2. VOLTAGE
 - AC/DC RATED OPERATING VOLTAGE 24V
 - AC/DC MAXIMUM VOLTAGE 30V
3. OPERATING TEMPERATURE: 0-60°C (32-140°F)
4. P1 CONNECTOR:
 - HPCN-50M MALE PIN/5U" BLACK
 - NICKEL-SHELL PH:1.27MM
 - IDC-ASSEMBLY TYPE OD: 9.0MM (MMS50113)
5. MINIMUM BEND RADIUS: 64MM [2.52IN]

ZL-CBL50-nP	
Rev: D	Date: 11/9/2016
Units: mm [inches]	
Scale: 1:1	
ZIPLink High Density Cable	