


TABLE A

PART NO	LENGTH
ZL-D0-CBL13	0.5m [1.6 ft]
ZL-D0-CBL13-1	1.0m [3.3 ft]
ZL-D0-CBL13-2	2.0m [6.6 ft]

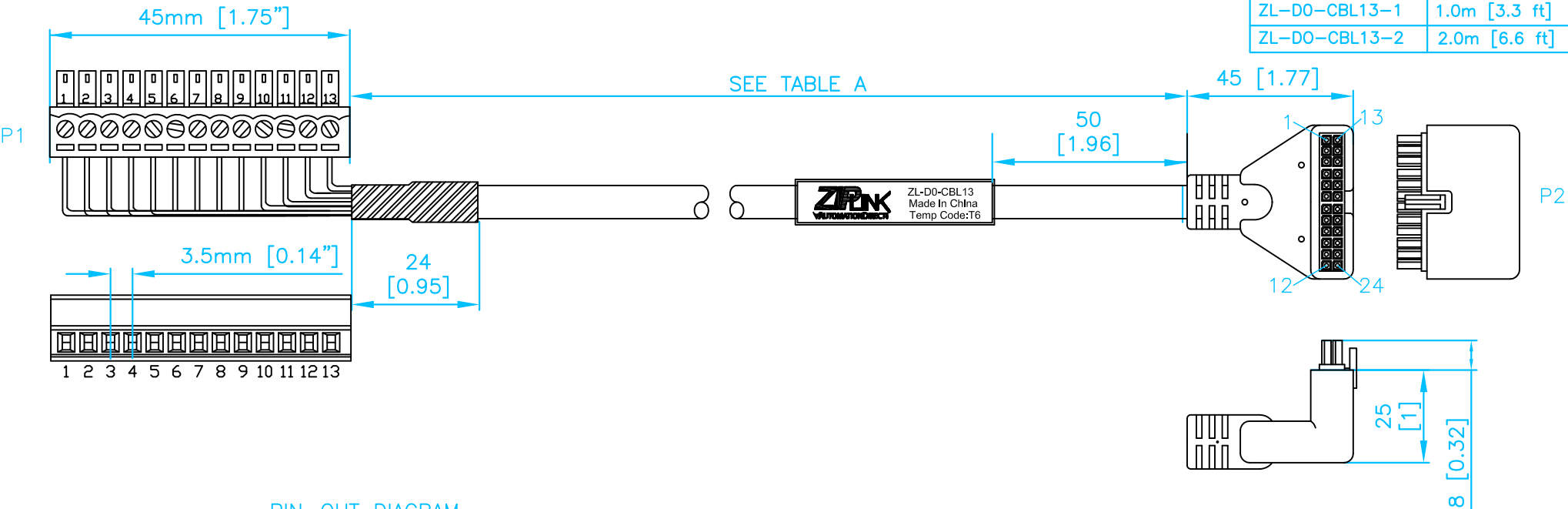

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	1	9	16
2	3	10	17
3	4	11	18
4	5	12	20
5	6	13	21
6	7		22
7	9		23
8	10		24
	11 CUT AND INSULATE		2
	12 CUT AND INSULATE		8
	14 CUT AND INSULATE		13
	15 CUT AND INSULATE		19

NOTES:

- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT – 2A per conductor, 40A maximum cable current
- VOLTAGE –  
240V AC/DC rated operating voltage  
265V AC/DC maximum voltage
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- 13 position terminal block for DL05/DL06 PLC  
Automation Direct Order # DO-ACC-4
- P2 CONNECTOR – 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-D0-CBL13-n	
Rev: original	Date: 07/2009
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL05/DL06 Cable	