


TABLE A

PART NO	LENGTH
ZL-D0-CBL8	0.5m [1.6 ft]
ZL-D0-CBL8-1	1.0m [3.3 ft]
ZL-D0-CBL8-2	2.0m [6.6 ft]

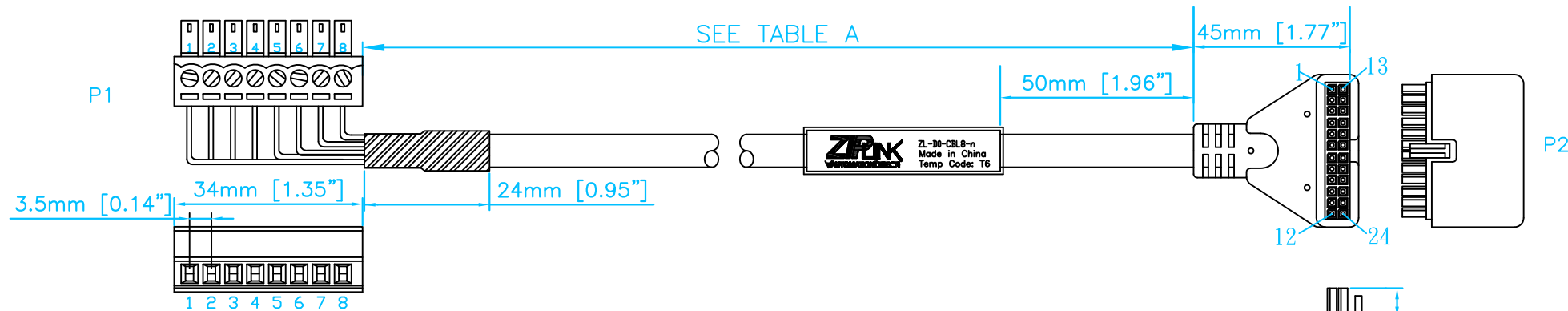

PIN-OUT DIAGRAM



NOTES:

- CABLE — 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT — 2A per conductor, 32A maximum cable current
- VOLTAGE — 240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE — 0–60°C (32–140°F)
- P1 CONNECTOR — 8 position terminal block for DL05/DL06 PLC Automation Direct Order # F0-IOCON
- P2 CONNECTOR — 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS — 65.6 mm [2.58 in]



ZL-D0-CBL8-n	
Rev: original	Date: 07/2009
Units: mm [inches]	
Scale: .03970	
ZIPLINK DL05/DL06 Cable	