


TABLE A

PART NO	LENGTH
ZL-D2-CBL10	0.5m [1.6 ft]
ZL-D2-CBL10-1	1.0m [3.3 ft]
ZL-D2-CBL10-2	2.0m [6.6 ft]

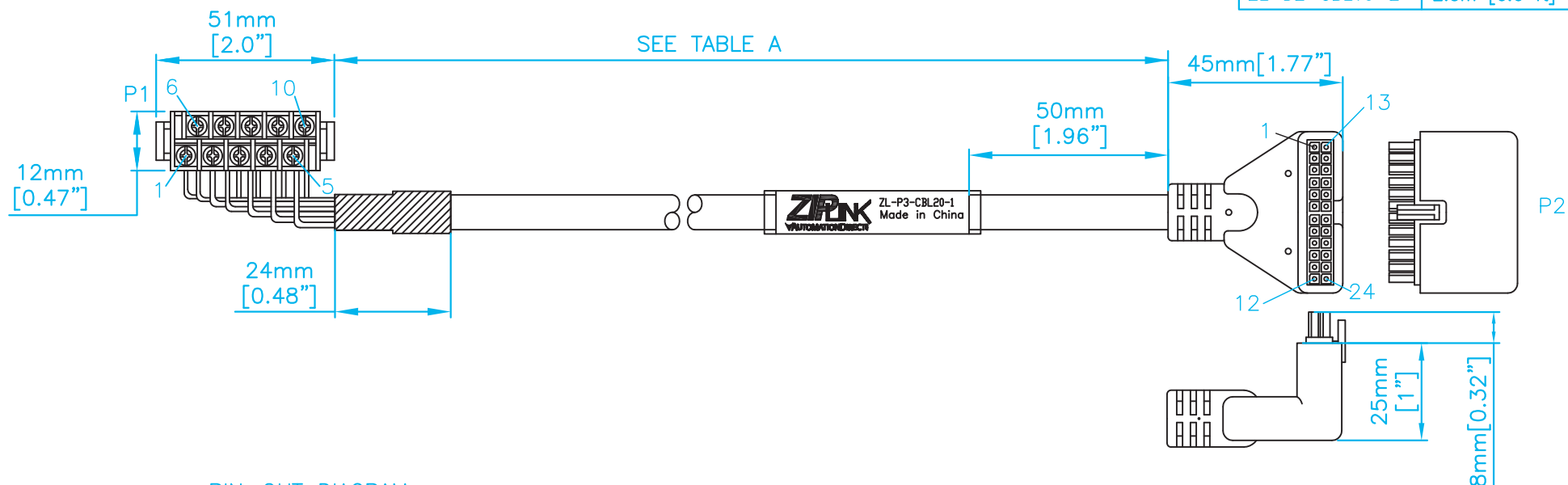

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	1	7	16
2	3	8	17
3	4	9	18
4	5	10	20
5	6		21
6	7		22
	9		23
	10		24
	11 CUT AND INSULATE		2
	12 CUT AND INSULATE		8
	14 CUT AND INSULATE		13
	15 CUT AND INSULATE		19

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 20A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 10 position terminal block for DL205 PLC, AutomationDirect part # D2-8IOCON
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-D2-CBL10-n	
Rev: B	Date: 01/2013
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL205 Cable	
