
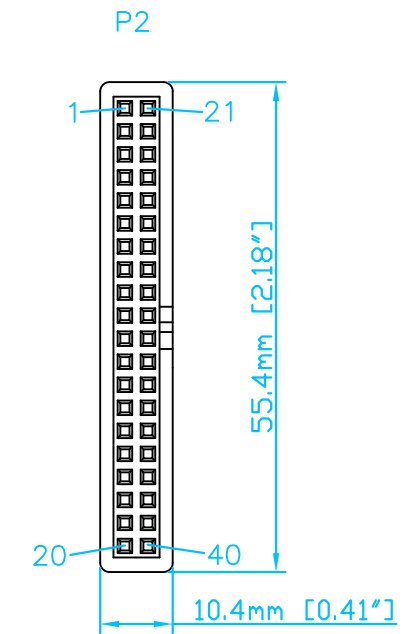



PART NO	LENGTH
ZL-D24-CBL40-X	0.5m [1.6 ft]
ZL-D24-CBL40-1X	1.0m [3.3 ft]
ZL-D24-CBL40-2X	2.0m [6.6 ft]

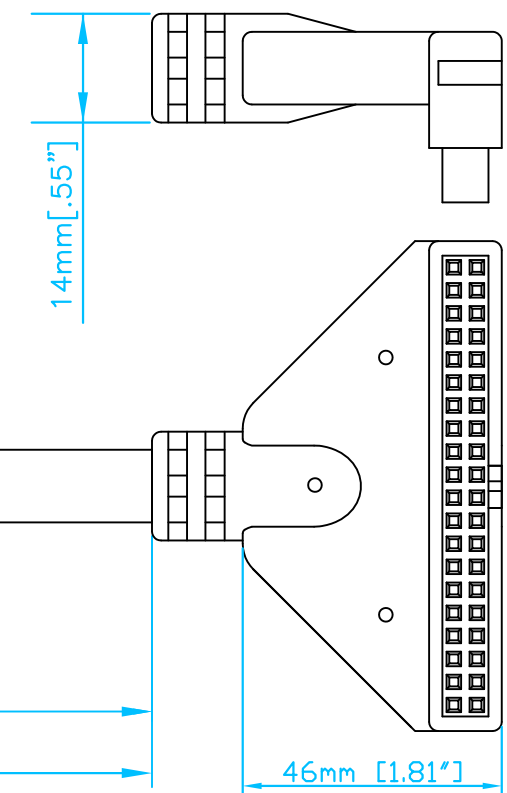

SEE TABLE A

50mm [1.97"]

PIN-OUT DIAGRAM

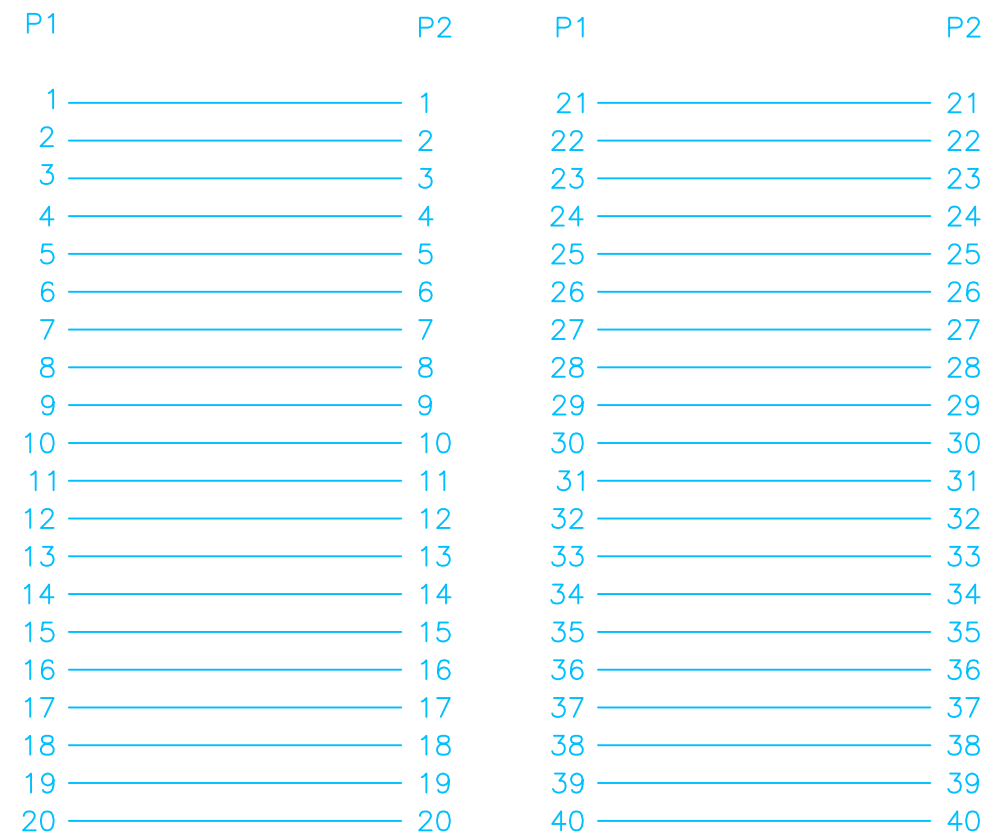

NOTES:

- CABLE - 40 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 0.5A per conductor, 32A maximum cable current
- VOLTAGE - 24V AC/DC rated operating voltage, 30V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - Fujitsu soldering type jack for FCN-360 series, AutomationDirect Order # ZL-D24-CON-X
- P2 CONNECTOR - Equivalent to 3M 34000 Series IDC Connector, Strain relief is required to latch to header
Example: Socket 3417-7640, Strain relief 3448-3040
- MINIMUM BEND RADIUS - 80mm [3.15"]

ZL-D24-CBL40-nX	
Rev: E6	Date: 09/2011
Units: mm [inches]	
Scale: .03940	
ZIPLINK Productivity 3000 Cable	