



PART NO	LENGTH
ZL-D4-CBL20-P	0.5m [1.6 ft]
ZL-D4-CBL20-1P	1.0m [3.3 ft]
ZL-D4-CBL20-2P	2.0m [6.6 ft]

TABLE A

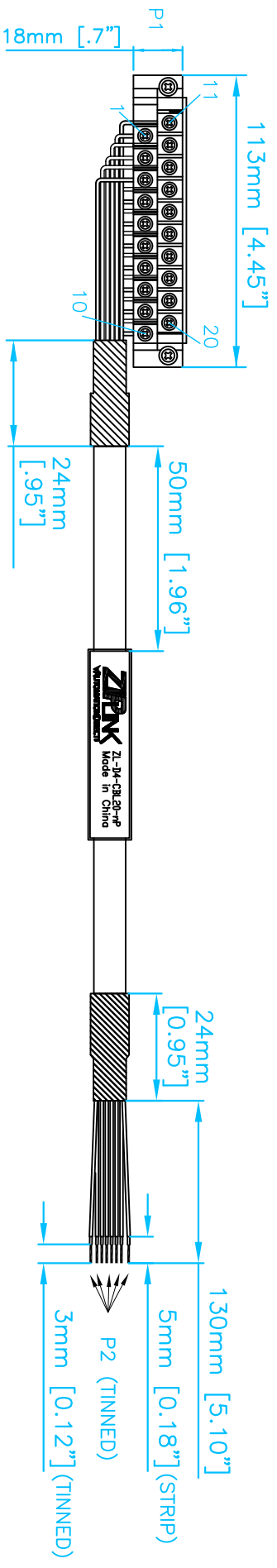

PIN-OUT DIAGRAM

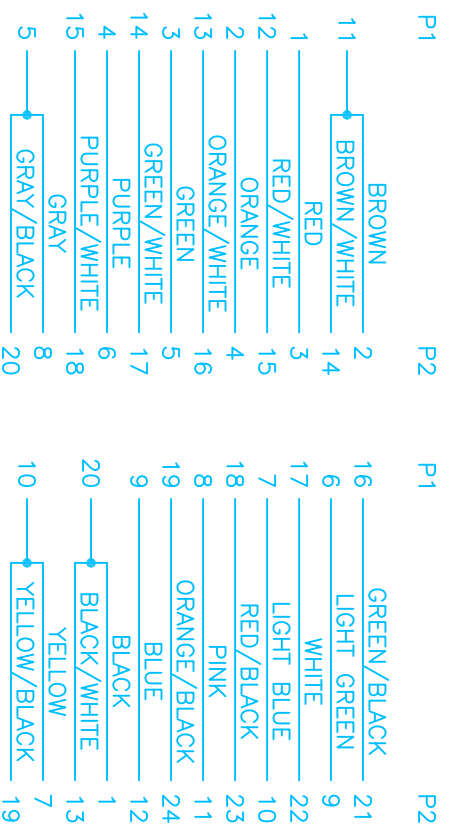

- NOTES:
- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
 - CURRENT – 2A per conductor, 32A maximum cable current
 - VOLTAGE – 240V AC/DC rated operating voltage
 - OPERATING TEMPERATURE – 0–60°C (32–140°F)
 - P1 CONNECTOR – 20 position terminal block for Direct Logic DL405 PLC, AutomationDirect part # D4-1610CON
 - MINIMUM BEND RADIUS – 65.6mm [2.58in]

ZL-D4-CBL20-nP	
Rev: B	Date: 02/2011
Units: mm [inches]	
Scale: .03940	
ZIPLINK DL405 PLC Cable	
