


TABLE A

PART NO	LENGTH
ZL-DB9F-CBL-2P	2m [6.56ft]
ZL-DB9F-CBL-5P	5m [16.40ft]

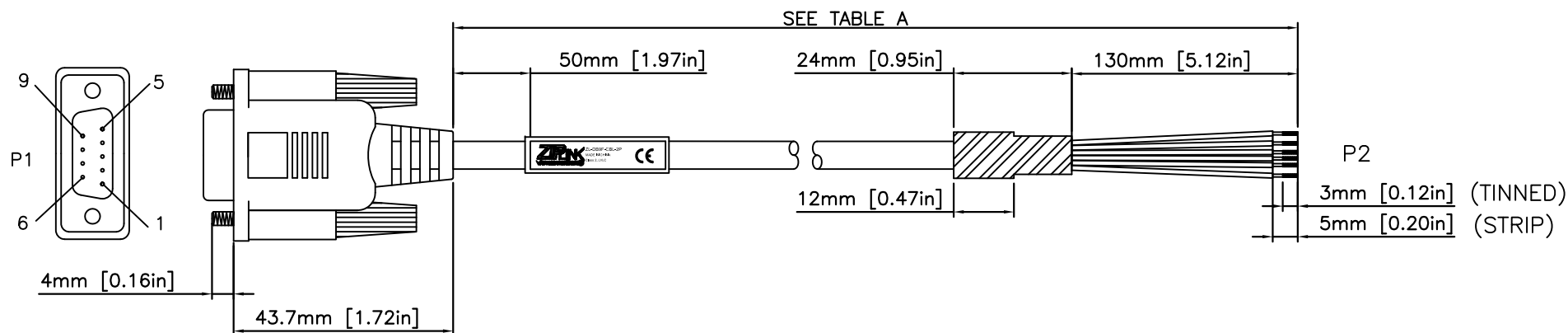

P1	PIN	OUT	P2
1	—	BLACK	
2	—	BROWN	
3	—	RED	
4	—	ORANGE	
5	—	YELLOW	
6	—	GREEN	
7	—	BLUE	
8	—	VIOLET	
9	—	GREY	

NOTES:

1. CABLE - 9 conductor, 28 AWG, UL2464, OD:5.0MM, PVC black jacket
2. VOLTAGE -
 DC rated operating voltage 24VDC
 DC maximum voltage 30VDC
 AC rated operating voltage 120VAC
 AC maximum voltage 150VAC
3. OPERATING TEMPERATURE - 0-60°C (32-140°F)
4. P2 CONNECTOR - DB-9F FEMALE BLACK PIN/GF SHELL-NICKEL PLATING
5. MINIMUM BEND RADIUS - 40mm [1.57in]

ZL-DB9F-CBL-nP	
Rev: A	Date: 01/2011
Units: mm [in]	
Scale: none	
ZIPLINK DB9F to Pigtail Cable	
