



TABLE A

| PART NO | LENGTH |
|---------------|---------------|
| ZL-P2-CBL18 | 0.5m [1.6 ft] |
| ZL-P2-CBL18-1 | 1.0m [3.3 ft] |
| ZL-P2-CBL18-2 | 2.0m [6.6 ft] |

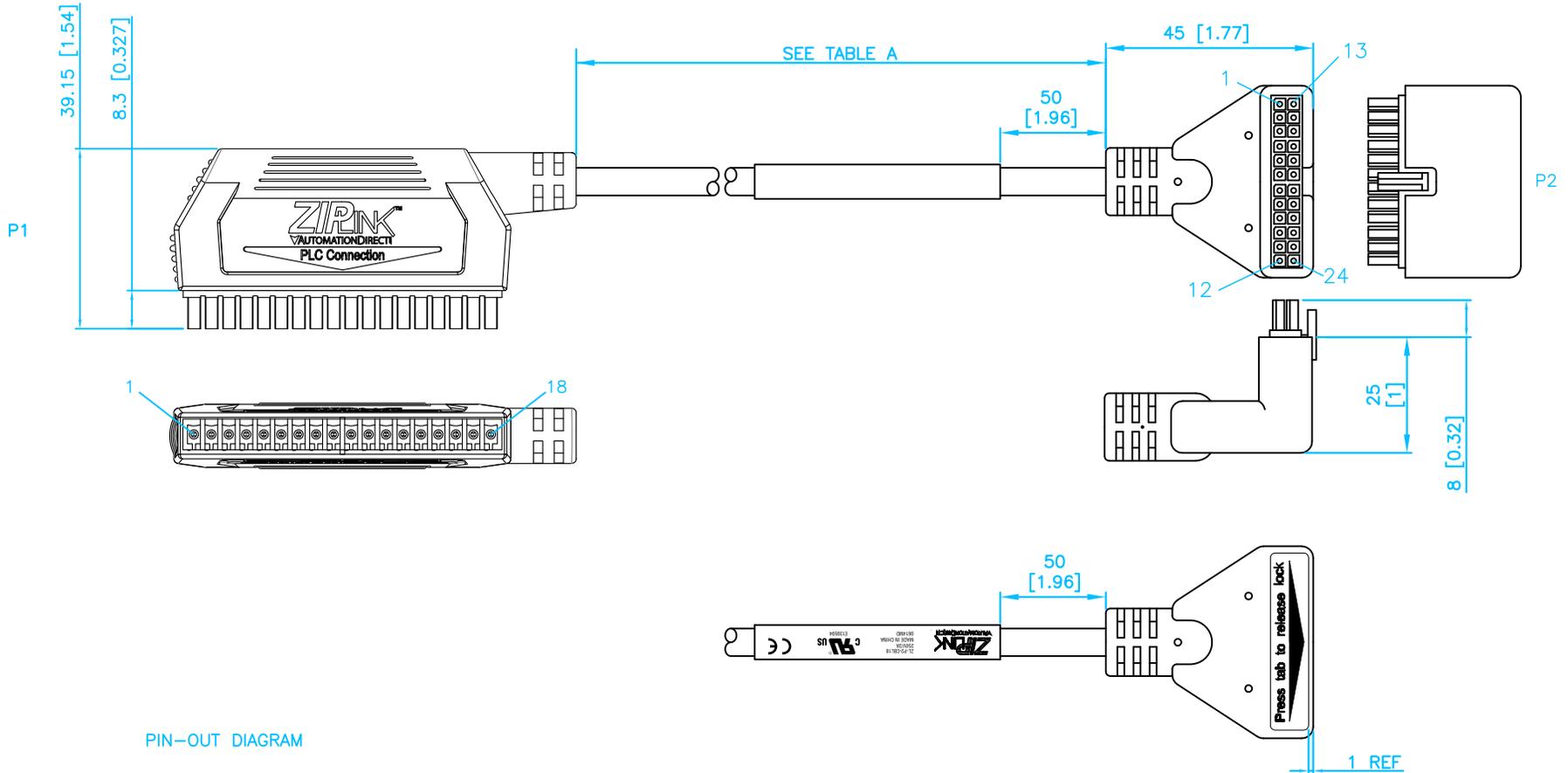

PIN-OUT DIAGRAM

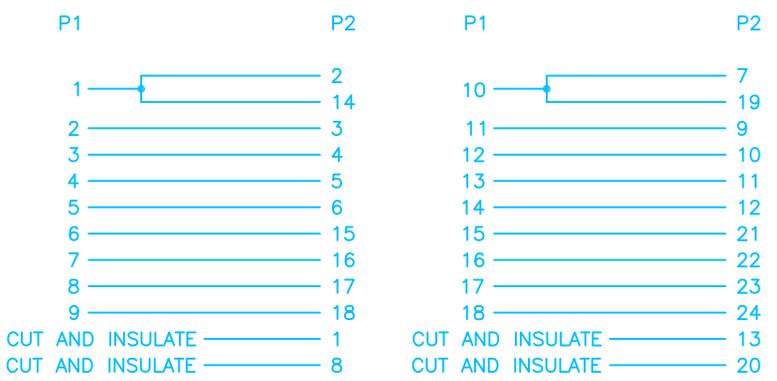

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 18 position overmolded terminal block for Productivity 2000 PLC
- P2 CONNECTOR - 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

| | |
|--|---------------|
| ZL-P2-CBL18-n | |
| Rev: XB | Date: 07/2013 |
| Units: mm [inches] | |
| Scale: none | |
| ZIPLINK Productivity 2000 PLC Cable | |
| AUTOMATIONDIRECT.com | |