
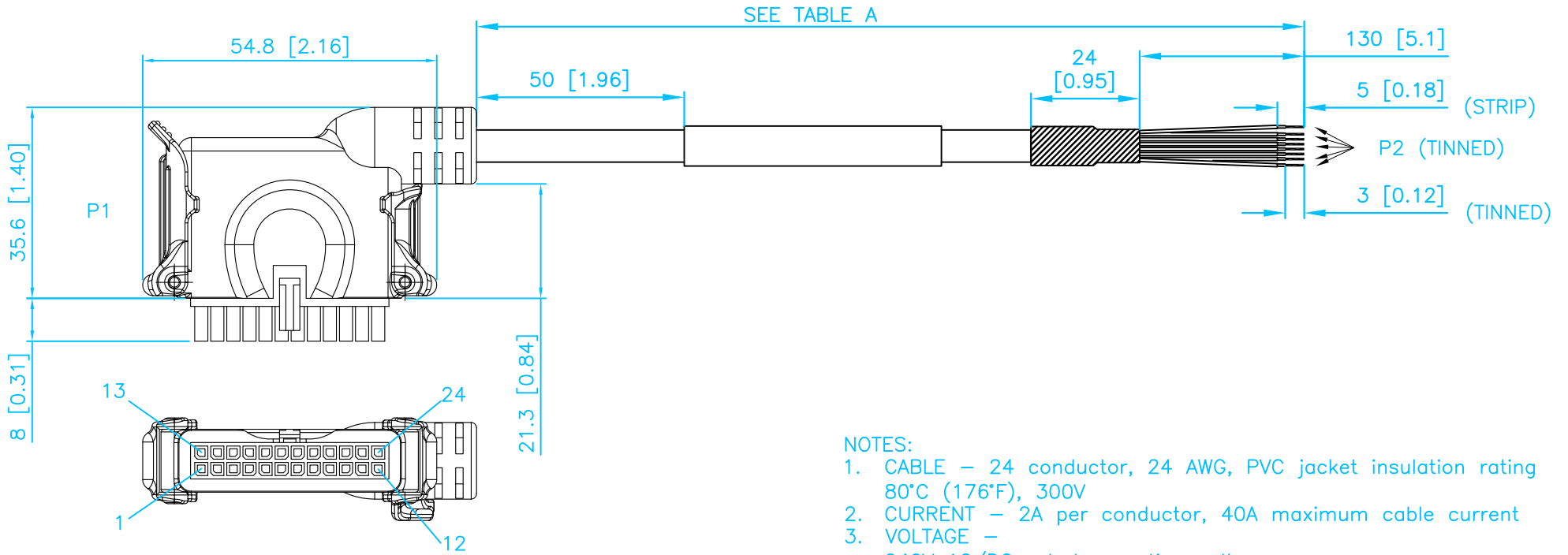


TABLE A

PART NO	LENGTH
ZL-P2-CBL24-1P	1.0m [3.3 ft]
ZL-P2-CBL24-2P	2.0m [6.6 ft]

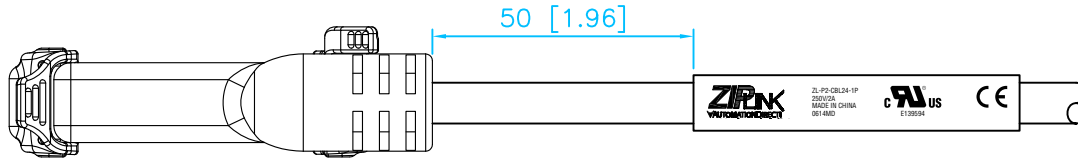

PIN-OUT DIAGRAM

P1	P2	P1	P2
1	BLUE	13	ORANGE/BLACK
2	PINK	14	RED/BLACK
3	LIGHT BLUE	15	WHITE
4	LIGHT GREEN	16	GREEN/BLACK
5	GRAY	17	GRAY/BLACK
6	YELLOW	18	YELLOW/BLACK
7	PURPLE	19	PURPLE/WHITE
8	GREEN	20	GREEN/WHITE
9	ORANGE	21	ORANGE/WHITE
10	RED	22	RED/WHITE
11	BROWN	23	BROWN/WHITE
12	BLACK	24	BLACK/WHITE

NOTES:

- CABLE - 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT - 2A per conductor, 40A maximum cable current
- VOLTAGE -
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE - 0-60°C (32-140°F)
- P1 CONNECTOR - 18-pin terminal block for Productivity 2000, AutomationDirect part # P2-RTB
- P2 CONNECTION - 24 tinned pig-tail leads (only 20 leads are connected to P1, per cable pin-out diagram)
- MINIMUM BEND RADIUS - 65.6 mm [2.58 in]

ZL-P2-CBL24-xP	
Rev: XB	Date: 7/2013
Units: mm [inches]	
Scale: none	
ZIPLINK Productivity 2000 Cable	