


TABLE A

PART NO	LENGTH
ZL-P3-CBL20-L	0.5m [1.6 ft]
ZL-P3-CBL20-1L	1.0m [3.3 ft]
ZL-P3-CBL20-2L	2.0m [6.6 ft]

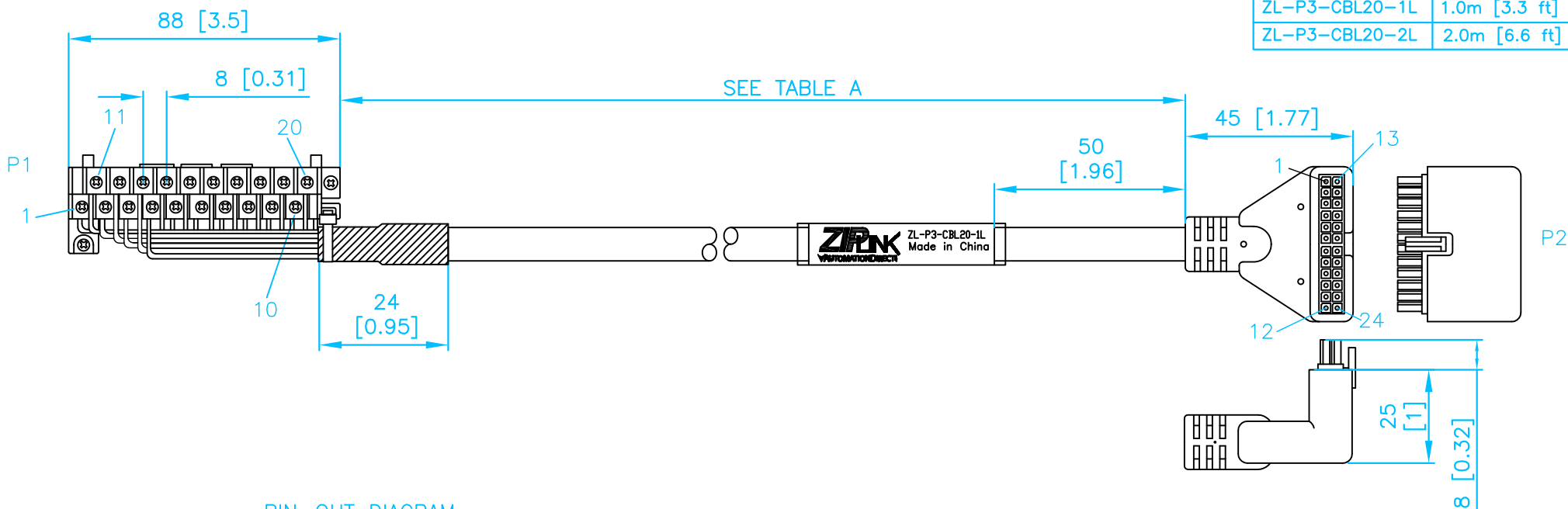

PIN-OUT DIAGRAM

P1	P2	P1	P2
		16	9
		7	10
1	13	17	11
11	3	8	12
2	4	9	21
12	5	19	22
3	6	10	23
4	15	20	24
14	16		
5	17	13	2
15	18		
6	7	18	8
	19		20

NOTES:

- CABLE – 24 conductor, 24 AWG, PVC jacket insulation rating 80°C (176°F), 300V
- CURRENT – 2A per conductor, 32A maximum cable current
- VOLTAGE –
240V AC/DC rated operating voltage
265V AC/DC maximum voltage
- OPERATING TEMPERATURE – 0–60°C (32–140°F)
- P1 CONNECTOR – 20-pin terminal block for Productivity 3000, AutomationDirect part # P3-RTB
- P2 CONNECTOR – 24-pin receptacle equivalent to Molex Micro-Fit3.0 part # 43025-2400
- MINIMUM BEND RADIUS – 65.6 mm [2.58 in]

ZL-P3-CBL20-xL	
Rev: original	Date: 06/2009
Units: mm [inches]	
Scale: none	
ZIPLINK Productivity 3000 Cable	
