



TABLE A

PART NO.	LENGTH
ZL-SVC-CBL50	0.5m (1.7ft)
ZL-SVC-CBL50-1	1.0m (3.3ft)
ZL-SVC-CBL50-2	2.0m (6.6ft)

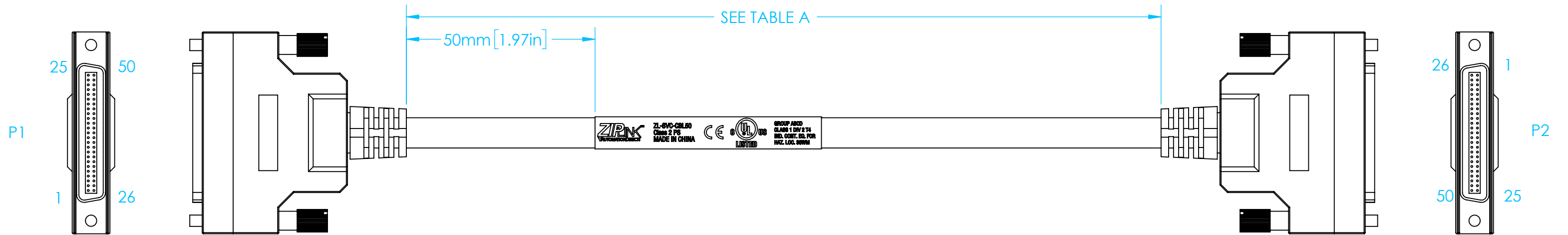

PIN-OUT DIAGRAM

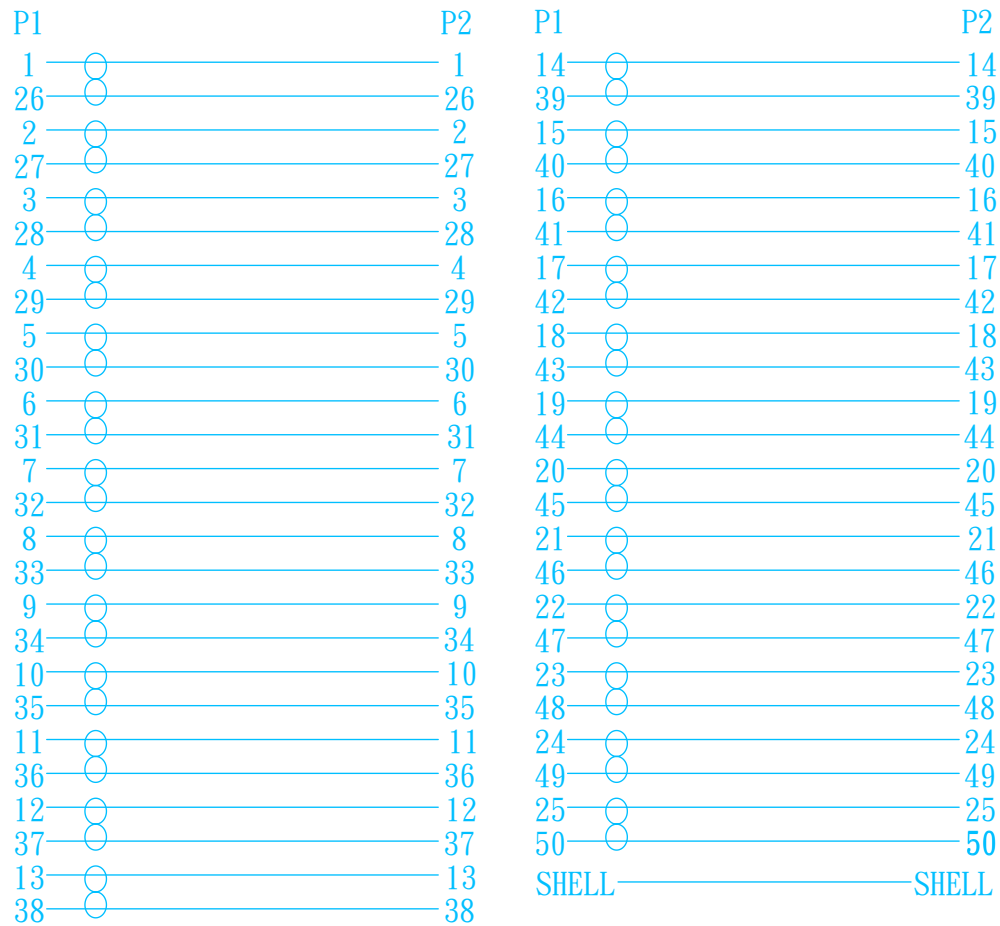

NOTES:

- CABLE: 50 CONDUCTOR, 28 AWG, BLACK PVC JACKET INSULATION RATING 80°C (176°F), 30V
- VOLTAGE
  - AC/DC RATED OPERATING VOLTAGE 24V
  - AC/DC MAXIMUM VOLTAGE 30V
- OPERATING TEMPERATURE: 0-60°C (32-140°F)
- P1 AND P2 CONNECTOR:
  - HPCN-50M MALE PIN/5U" BLACK
  - NICKEL-SHELL PH:1.27MM
  - IDC-ASSEMBLY TYPE OD: 9.0MM (FMC50MML/A693)
- MINIMUM BEND RADIUS: 64MM [2.52IN]

ZL-SVC-CBL50-n	
Rev: F	Date: 11/9/2016
Units: mm [inches]	
Scale: 1:1	
ZIPLink SureServo Cable	