



TABLE A	
PART NO	LENGTH
SR44-485RJ45-CBL-2	2.0M [6.6FT]

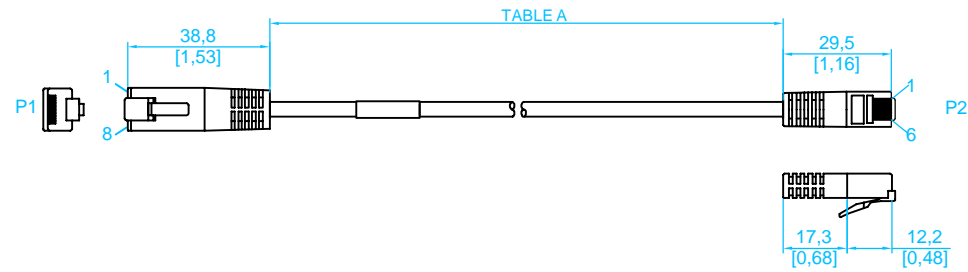

NOTES:

1. UL20276 28AWG\*2P + AEB  
OD: 5.0mm, JACKET BLACK COLOR
2. RJ45 8P8C MODULAR PLUG  
CONTACT: BRASS, GOLD FLASH
3. RJ12 6P6C MODULAR PLUG  
CONTACT: BRASS, GOLD FLASH
4. MINIMUM BEND RADIUS: 40mm [1.57"]
5. OPERATING TEMPERATURE: 0-60°C (32-140°F)

PIN OUT

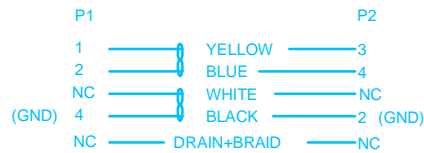

SR44-485RJ45-CBL-2	
Rev: original	Date: 06/2010
Units: mm [inches]	
Scale: none	
ZIPLINK SOFT STARTER CABLE	