


ITEM	UL RECOGNIZED COMPONENTS	Qty
1	Vinyl Insulating Ring Terminals 22-16 AWG (ZMVV), K S Terminals Inc. (E96029), cat. no. RVBL1-4 or equivalent	1
2	Heat Shrink Tubing (YDPU2) Rated 600V, 125°C	1
3	Cable (AVLV2) 12AWGx3, 16AWGx1, 18AWGx2 600V, 105°C UL2501 (BLACK)	See Table A
4	Cable Receptacle (ECBT2) Amphenol Corp (E115497) cat. no. 97, MS 3106A-20-18S or equivalent	1

PART NUMBER	LENGTH
SVC-PHM-010	3.0m [10 f-t]
SVC-PHM-020	6.1m [20 f-t]
SVC-PHM-030	9.1m [30 f-t]
SVC-PHM-060	18.3m [60 f-t]

TABLE A

A UVV wires are 12AWG. GND wire is 16AWG. 2 Brake wires are 18 AWG.

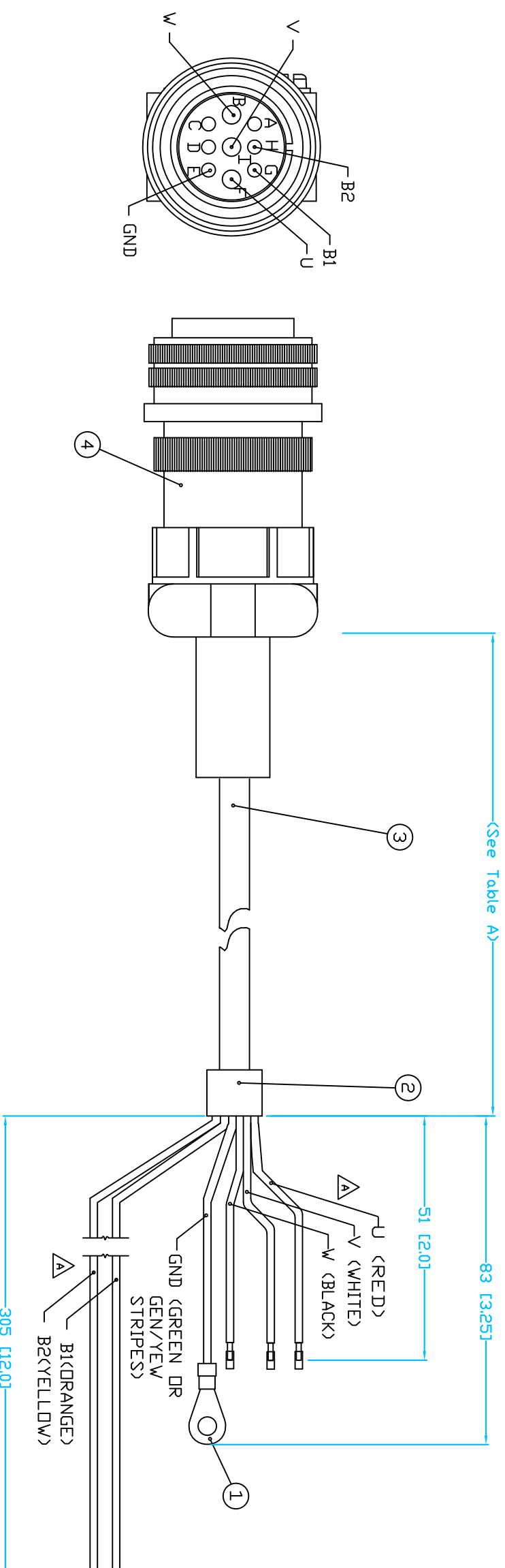

- SPECIFICATIONS:
1. CABLE – 6 conductor, 12 AWGx3, 16 AWGx1, 18 AWGx2, PVC jacket insulation rating 105°C (176°F), 600V, UL2501
 2. CURRENT – 6.8A Rated Motor current, 18.7A Maximum Motor current. Rated Brake current 850mA at 24VDC
 3. VOLTAGE – 600 VAC maximum motor voltage
 4. OPERATING TEMPERATURE – 0–55°C (32–140°F)
 5. MINIMUM BEND RADIUS – 130 mm [5.1 in]

SVC-PHM-n	
Rev: original	Date: 05/2010
Units: mm [inches]	
Scale: none	
SURE SERVO POWER CABLE	
AUTOMATIONDIRECT	